


- Plate Type Rubber Casters
- Plate Type Urethane Casters
- Plate Type Nylon Casters
- Plate Type Resin Casters
- Screwed Rubber Casters
- Screwed Urethane Casters
- Screwed Nylon Casters
- Screwed Resin Casters
- Nuts, Spanners
- Stem Casters
- Stainless Steel Casters
- Angle Casters
- Corner Casters
- Dual Wheel Casters
- Sound Reducing Casters
- ESD-Safe Casters
- Shock Absorbing Casters
- Casters for Specific Environment
- Pneumatic/No-Puncture Caster
- Low Level Casters
- Heavy-Duty Casters
- Casting Casters
- Stoppers



Stock 38,650 Items

**Plate Type Noise Reduction Caster (elastomer wheel)**

For Trolleys, see p. 8-938 to 940

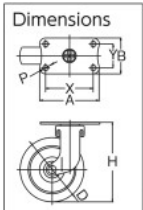

**Features**

- Since cover is attached to the wheel part, it is a structure wherein dust will not easily enter. (wheel diameter 100mm type only)
- Since radial bearing is used in the wheel part, the starting resistance is reduced and the sound is quiet.
- The material is harder-to-generate marks on the floor than rubber wheels.
- The traveling sound is quieter than the nylon trolley.

**Materials**

- Metal Fitting: Steel
- Metal Fitting Surface Treatment: Trivalent Chrome Plated Finishing
- Wheel: Elastomer

**Origin**

- Japan



**Flexible** Specs • Flexible Type

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN)	Allowable Weight (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
359-9574	TYEF-75ELB	¥ 555	¥ 600	35	35.7	75	20	93	70 x 42	56 x 28	6.5	50	220
359-9591	TYSFHG-100SEL	¥ 1,083	¥ 1,170	65	66.3	100	28	122	100 x 58	82 x 40	8.8	24	500

**Flexible with stopper** Specs • Flexible Type (with stopper)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN)	Allowable Weight (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
389-9527	TYEF-75ELBDS	¥ 778	¥ 840	35	35.7	75	20	93	70 x 42	56 x 28	6.5	50	220
389-9667	TYSFHG-100SELDS	¥ 1,306	¥ 1,410	60	61.2	100	28	122	100 x 58	82 x 40	8.8	24	500

**Fixed** Specs • Fixed Type

Order Unit: 1 Piece


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN)	Allowable Weight (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
359-9582	TYER-75ELB	¥ 370	¥ 400	35	35.7	75	20	93	70 x 42	56 x 28	6.5	50	155
359-9604	TYSR-100SEL	¥ 778	¥ 840	65	66.3	100	28	122	100 x 58	82 x 40	8.8	24	400

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 793 Items

**Plate Type Noise Reduction Caster (PP wheel elastomer tire)**

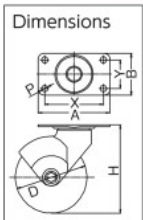

**Features**

- Reduces noise generation when turning.

**Specs**

- Plate Type

**Materials**

- Main body: Made of resin
- Plate part: Trivalent chromium chemical conversion treatment
- Wheel: PP wheel, elastomer wound wheel (with radial ball bearing)

**Origin**

- China

**Flexible** Specs • Flexible Type

Order Unit: 1 Piece

HAMMER CASTER Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN)	Allowable Weight (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
444-4591	740M-CLB100-BAR01	¥ 997	-	50	51	100	27	123	100 x 58	82 x 40	8.8	40	405

**Fixed** Specs • Fixed Type

Order Unit: 1 Piece


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN)	Allowable Weight (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
444-4612	740MR-CLB100-BAR01	¥ 893	-	50	51	100	27	123	100 x 58	82 x 40	8.8	40	362

URL <http://www.hammer-caster.co.jp/>



Stock 793 Items

**Threaded Type Noise Reduction Caster (PP wheel rubber tire)**

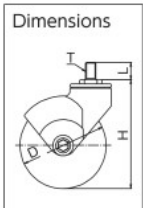

**Features**

- Radial ball bearing is used in the turning part, wheel bearing part, lightweight and silent reduction was achieved by using resin body as the main body.

**Materials**

- Main body: Made of resin
- Threaded Part: Trivalent Chromium Chemical Conversion Treatment
- Wheel: PP Wheel, Rubber Wound Wheel (with radial ball bearing)

**Origin**

- China

**Flexible** Specs • Flexible Type

Order Unit: 1 Piece

HAMMER CASTER Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN)	Allowable Weight (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (g)
444-4582	740MA-FR100-BAR01	¥ 814	-	50	51	100	30	126	20	M12	P1.75	40	459

**Flexible with stopper** Specs • Flexible Type (with stopper)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN)	Allowable Weight (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (g)
444-4566	735MA-FR100-BAR01	¥ 1,256	-	50	51	100	30	126	20	M12	P1.75	40	482

URL <http://www.hammer-caster.co.jp/>