

Threaded Type Noise-reducing Casters (elastomer wheel)

Stock 80Items

2-767

Prices displayed include 8% tax.

TRUSCO
 Stock 38,650 Items

Threaded Type Noise Reduction Caster (elastomer wheel)




- Features** •The traveling sound is quiet and there is no slip mark on the floor.
Materials •Metal Fitting: Steel
 •Wheel: Silent Elastomer
Origin •Japan

Two Stage Stopper
 By stepping on the pedal
 ① Stopper Free
 ② Turn Fixed
 ③ All Stopper
 The above three states can be used properly.
 ① Stopper Free Condition ② When Turning Fixed ③ All Stopper



TYST-75SEL

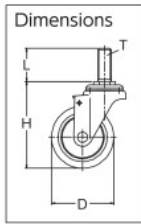

Flexible Specs •Flexible Type


Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)								
484-7539	TYST-75SEL	¥2,388	¥2,580	60	61.2	75	27	104	40	M16	2	20	420
484-7521	TYST-100SEL	¥2,675	¥2,890	60	61.2	100	28	132	40	M16	2	20	540

TRUSCO NAKAYAMA CORPORATION



TYST-75SEL-2S

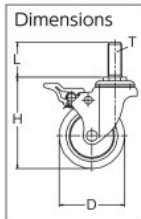

Flexible with stopper Features •Stopper free, turn fixed and all stoppers can be selected by stepping on the pedal.
 Specs •Flexible Type (with 2 step stopper)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)								
769-1017	TYST-75SEL-2S	¥3,250	¥3,510	60	61.2	75	27	104	40	M16	2	20	500
769-1009	TYST-100SEL-2S	¥3,536	¥3,820	60	61.2	100	28	132	40	M16	2	20	600

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO
 Stock 38,650 Items


Threaded Type Noise Reduction Caster (elastomer wheel)



- Features** •Since radial bearing is used in the wheel part, the starting resistance is reduced and the sound is quiet.
 •The material is harder-to-generate marks on the floor than rubber wheels.
 •The traveling sound is quieter than the nylon trolley.
Materials •Metal Fitting: Steel •Metal Fitting Surface Treatment: Trivalent Chrome Plated Finishing
 •Wheel: Elastomer Origin •Japan



TYEFT-75ELB

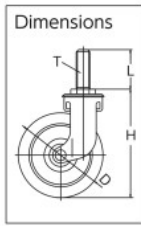

Flexible Specs •Flexible Type


Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)								
389-9535	TYEFT-75ELB	¥768	¥830	35	35.7	75	20	96	35	M12	1.75	50	220
389-9675	TYSFHT-100SEL	¥1,278	¥1,380	60	61.2	100	28	125	40	M16	2.00	24	490

TRUSCO NAKAYAMA CORPORATION



TYEFT-75ELBDS

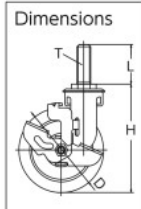

Flexible with stopper Specs •Flexible Type (with stopper)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)								
389-9543	TYEFT-75ELBDS	¥1,111	¥1,200	35	35.7	75	20	96	35	M12	1.75	50	275
389-9683	TYSFHT-100SELDS	¥1,657	¥1,790	60	61.2	100	28	125	40	M16	2.00	24	560

Contact us: 0120-509-849 <http://www.orange-book.com/>

HAMMER CASTER
 Stock 793 Items


Threaded Type Noise Reduction Caster (PP wheel elastomer tire)



- Features** •Radial ball bearing is used in the turning part, wheel bearing part, lightweight and silent reduction was achieved by using resin body as the main body.
Materials •Main body: Made of resin
 •Threaded Part: Trivalent Chromium Chemical Conversion Treatment
 •Wheel: PP wheel, elastomer tire (with radial ball bearing)
Origin •China



740MA-CLB100-BAR01

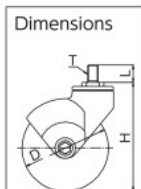

Flexible Specs •Flexible Type


Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)								
444-4574	740MA-CLB100-BAR01	¥814	-	50	51	100	27	126	20	M12	P1.75	40	352

HAMMER CASTER Co.Ltd.



735MA-CLB100-BAR01

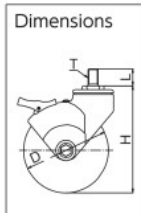

Flexible with stopper Specs •Flexible Type (with stopper)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight		Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (g)
				(daN)	(kgf)								
444-4558	735MA-CLB100-BAR01	¥1,256	-	50	51	100	27	126	20	M12	P1.75	40	373

URL <http://www.hammer-caster.co.jp/>

Casters

Plate Type Rubber Casters

Plate Type Urethane Casters

Plate Type Nylon Casters

Plate Type Resin Casters

Screwed Rubber Casters

Screwed Urethane Casters

Screwed Nylon Casters

Screwed Resin Casters

Nuts, Spanners

Stem Casters

Stainless Steel Casters

Angle Casters

Corner Casters

Dual Wheel Casters

Sound Reducing Casters

ESD-Safe Casters

Shock Absorbing Casters

Casters for Specific Environment

Pneumatic/No-Puncture Caster

Low Level Casters

Heavy-Duty Casters

Casting Casters

Stoppers