

Prices displayed include 8% tax.


TRUSCO Stock 38,650 Items

Saucer



Features •Optimum as a substitute of a caster stopper and to prevent floor damages.
Origin •Japan

Color	Materials
Black	Nylon
Black (79φ)	Polypropylene
Transparent	Polycarbonate

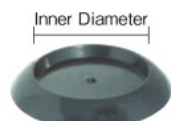

TUK600-BK (black)



TUK600-TM (transparent)



Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Color	Outer Diameter (mm)	Inner Diameter (mm)	SPQ (piece)	Weight (g)
765-8931	TUK600-BK	¥102	¥110	Black	60.0	39.8	100	9.6
765-8958	TUK600-TM	¥102	¥110	Transparent	60.0	39.8	100	9.5
765-8974	TUK630-BK	¥111	¥120	Black	64.0	43.5	100	11.0
765-8991	TUK630-TM	¥111	¥120	Transparent	64.0	43.5	100	11.5
765-9016	TUK715-BK	¥120	¥130	Black	71.5	47.0	100	16.1
765-9032	TUK715-TM	¥120	¥130	Transparent	71.5	47.0	100	16.3
855-2626	TUK790-BK	¥139	¥150	Black	79.0	54.0	100	13.8

10 pieces contained type

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Color	Outer Diameter (mm)	Inner Diameter (mm)	SPQ (bag)	Weight (g/bag)
765-8940	TUK600-BK-10	¥917	¥990	Black	60.0	39.8	10	96.7
765-8966	TUK600-TM-10	¥917	¥990	Transparent	60.0	39.8	10	95.5
765-8982	TUK630-BK-10	¥954	¥1,030	Black	64.0	43.5	10	110.0
765-9008	TUK630-TM-10	¥954	¥1,030	Transparent	64.0	43.5	10	112.0
765-9024	TUK715-BK-10	¥1,065	¥1,150	Black	71.5	47.0	10	162.0
765-9041	TUK715-TM-10	¥1,065	¥1,150	Transparent	71.5	47.0	10	162.5
855-2627	TUK790-BK-10	¥1,231	¥1,330	Black	79.0	54.0	10	138.0

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Saucer



Features •Optimum as a substitute of a caster stopper and to prevent floor damages.
•With anti-slip rubber sheet on the bottom.

Materials •Rubber sheet: ETP (black)
Origin •Japan

Color	Materials
Black	Nylon
Black (79φ)	Polypropylene
Transparent	Polycarbonate



TUR600-BK (black)



TUR600-TM (transparent)

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Color	Outer Diameter (mm)	Inner Diameter (mm)	SPQ (piece)	Weight (g)
765-9059	TUR600-BK	¥222	¥240	Black	60.0	39.8	100	12.2
765-9067	TUR600-TM	¥222	¥240	Transparent	60.0	39.8	100	12.0
765-9075	TUR630-BK	¥231	¥250	Black	64.0	43.5	100	14.0
765-9083	TUR630-TM	¥231	¥250	Transparent	64.0	43.5	100	14.5
765-9091	TUR715-BK	¥241	¥260	Black	71.5	47.0	100	19.1
765-9105	TUR715-TM	¥241	¥260	Transparent	71.5	47.0	100	19.3
855-2628	TUR790-BK	¥259	¥280	Black	79.0	54.0	100	17.0

Contact us:0120-509-849 <http://www.orange-book.com/>

HIKARI Stock 1,144 Items


"Caster Stop" (for dual caster)



Features •A wheel stopper convenient to fix casters, prevent vibration and noise, and protect floors.
•As it is made of elastomer, color staining is hard-to-occur.

Materials •Elastomer resin
Origin •Taiwan

Warning
•Please use on a horizontal place after confirming existence of wobbling.

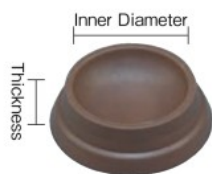

KGH-65 (brown)



KGH-66 (black)

Order Unit: 1 Bag

HIKARI Co.Ltd.

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Color	Diameter x Thickness (mm)	Inner Diameter (mm)	Compatible Caster	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
387-4231	KGH-52	¥519	-	Brown	51 x 16	34	30mm double wheel caster	4	10	84
387-4249	KGH-53	¥519	-	Black	51 x 16	34	30mm double wheel caster	4	10	84
387-4257	KGH-65	¥623	-	Brown	64 x 18	45	40mm double wheel caster	4	10	135
387-4265	KGH-66	¥623	-	Black	64 x 18	45	40mm double wheel caster	4	10	135
387-4273	KGH-77	¥734	-	Brown	80 x 24	55	50mm double wheel caster	4	10	225
387-4281	KGH-78	¥734	-	Black	80 x 24	55	50mm double wheel caster	4	10	225

Contact us:06-6764-1531 <http://www.osaka-hikari.co.jp/>

HIKARI Stock 1,144 Items

Flat rubber



Features •Optimum for protecting round base legs, non-slip, caster top.
Materials •Natural Rubber Origin •China



BE-0-652 (flat rubber black/round)

Order Unit: 1 Piece

HIKARI Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Diameter x Thickness (mm)	Inner Diameter (mm)	SPQ (piece)	Weight (g)
365-4460	BE-0-402	¥139	¥150	55 x 11.3	42	10	23
365-4478	BE-0-652	¥370	¥400	65 x 16.5	65	10	67

Contact us:06-6764-1531 <http://www.osaka-hikari.co.jp/>