

Prices displayed include 8% tax.

For wire ropes, see p. 2-907 to 911


NIKKO  Stock 15 Items

## Wire Clip



WCP-9

- Features •Wire can be processed on site.  
 Use •For connecting a wire rope and items.  
 Materials •Main body: Malleable cast iron •U bolt/nut: Steel (SS400)  
 •Surface Treatment: Unichrome Plated Finishing  
 Origin •China

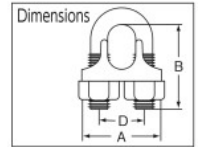

Order Unit: 1 Bag (Price revision date: Aug. 2015) NIKKO STEEL WIRE ROPE M.F.G. Co.Ltd

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Applicable Rope Diameter (mm)	B (mm)	D (mm)	A (mm)	Screw Diameter	Qty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
117-5840	WCP-3	¥208	—	3	20.0	11.0	22.0	W3/16	2	50	30
117-5858	WCP-6	¥262	—	6	31.5	17.0	31.5	W5/16	2	50	104
117-5866	WCP-9	¥324	—	9	41.8	22.5	42.8	W3/8	2	50	200

URL <http://www.nikkoseiko.co.jp/>

MIZUMOTO MACHINE  Stock 529 Items


## Stamped Wire Rope Clip



- Features •Wire can be processed on site.  
 Use •For wire rope terminal processing.  
 Materials •Stainless Steel (SUS304) Origin •China



B-2350

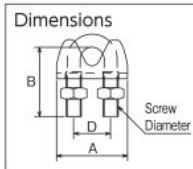

Order Unit: 1 Piece (Price revision date: Jan. 2016) MIZUMOTO MACHINE MFG.Co.Ltd

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Applicable Rope Diameter (mm)	B (mm)	D (mm)	A (mm)	Screw Diameter	SPQ (piece)	Weight (g)
397-7218	B-2349	¥238	¥280	3	17.4	8.0	14	M3	20	4
397-7226	B-2350	¥255	¥300	4	18.5	10.0	19	M4	20	9
397-7234	B-2351	¥271	¥320	5	21.6	11.5	22	M5	20	15
397-7242	B-2352	¥382	¥450	6	28.7	14.0	26	M6	20	26
397-7251	B-2353	¥492	¥580	8	33.9	17.0	31	M8	20	54


Contact us:079-246-2501 <http://www.mizumoto-mm.co.jp/>

TRUSCO  Stock 38,650 Items

## Single Clip



TSWR series

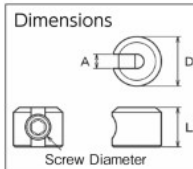

- Features •It is attached to a single wire.  
 Use •For wire rope terminal processing.  
 Materials •Stainless Steel (SUS304) Origin •Taiwan

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Applicable Rope Diameter (mm)	D (mm)	L (mm)	A (mm)	Screw Diameter	Wrench size	SPQ (piece)	Weight (g)
856-0803	TSWR-1	¥1,185	¥1,280	1.0	6.5	5.5	1.3	M3	1.5	20	1
856-0804	TSWR-2	¥1,185	¥1,280	1.5-2.0	10.0	8.0	2.3	M4	2.0	20	4
856-0805	TSWR-4	¥1,527	¥1,650	3.0-4.0	15.0	12.0	4.3	M8	4.0	20	13
856-0806	TSWR-6	¥1,713	¥1,850	5.0-6.0	20.0	15.0	6.3	M10	5.0	20	27

Contact us:0120-509-849 <http://www.orange-book.com/>


TRUSCO  Stock 38,650 Items

## "Single Wire Clip"



 TSWC-3

- Features •Wire can be processed on site.  
 Use •For wire rope terminal processing.  
 Materials •Stainless Steel (SUS304)  
 Origin •China



TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Applicable Rope Diameter (mm)	L (mm)	W (mm)	Screw Diameter	Qty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
409-9702	TSWC-1.5	¥379	¥410	1.5	15	11.5	M4	2	20	8
409-9711	TSWC-2	¥389	¥420	2.0	17	15.0	M4	2	20	12
409-9729	TSWC-3	¥417	¥450	3.0	20	17.5	M5	2	20	20

Contact us:0120-509-849 <http://www.orange-book.com/>


MIZUMOTO MACHINE  Stock 529 Items

## "Double Clip"



B-2142

- Features •It is used for fixing at the crossing part that stainless wires are stretched in a lattice form.  
 Use •For fixing wire.  
 Materials •Stainless Steel (SUS304)  
 Origin •Taiwan

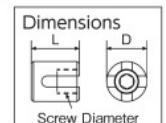

MIZUMOTO MACHINE MFG.Co.Ltd

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Applicable Rope Diameter (mm)	D (mm)	L (mm)	Screw Diameter	Wrench size	SPQ (piece)	Weight (g)
378-9586	B-2187	¥1,749	¥2,060	1	7.5	7.5	M4	2	20	2
378-9501	B-2142	¥1,749	¥2,060	2	12.0	13.0	M6	3	20	8
378-9519	B-2143	¥1,842	¥2,170	3	14.0	15.0	M8	4	20	12
378-9527	B-2144	¥1,934	¥2,280	4	16.0	19.0	M10	5	20	18

Contact us:079-246-2501 <http://www.mizumoto-mm.co.jp/>