

# U-shape Bolts

The number next to the logo mark indicates items in stock for each brand.

Hardware

TRUSCO



Stock 38,650 Items

## U-shape Bolt



- Features** • A metal fitting for fixing to the wall/floor/ground.  
**Use** • As a terminal metal fitting for chain, wire and rope.  
**Materials** • **Stainless Steel (SUS304)**  
**Accessories** • Oval plate  
 • Round Washer: 2 sheets  
 • Hexagon Nut: 2 pieces  
**Origin** • Taiwan



TUB-5




Example

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	D (mm)	L1 (mm)	L2 (mm)	L3 (mm)	P (mm)	Screw Diameter	Working Load (kN)	SPQ (piece)	Weight (g)
328-8293	TUB-4	¥ 620	¥ 670	4	58	21	30	30	M4 x 0.7	0.20	20	17
328-8307	TUB-5	¥ 676	¥ 730	5	73	25	40	35	M5 x 0.8	0.29	20	31
328-8315	TUB-6	¥ 796	¥ 860	6	84	29	45	35	M6 x 1.0	0.49	20	51
328-8323	TUB-8	¥1,166	¥1,260	8	92	32	50	35	M8 x 1.25	0.78	15	94
328-8331	TUB-10	¥1,981	¥2,140	10	120	45	55	50	M10 x 1.5	1.47	10	201

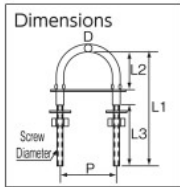

Contact us: 0120-509-849 <http://www.orange-book.com/>

Door Closers

Door Stoppers

Hinges

Slide Bolt Latches

Catches

Handles

TRUSCO



Stock 38,650 Items

## U-shape Bolt A Type



- Features** • A metal fitting for fixing to the wall/floor/ground.  
**Use** • As a terminal metal fitting for chain, wire and rope.  
**Materials** • **Stainless Steel (SUS304)**  
**Origin** • Japan



TUBA-7025

Item No.	Accessories
TUBA-5025/TUBA-7030/TUBA-9040/TUBA-9045/TUBA-10556	Hexagon nut/round washer (2 pieces for each) Oval plate (1 piece for each)
TUBA-7025	Hexagon nut/oval washer (2 pieces for each)
TUBA-10045	Hexagon nut/round washer (2 pieces for each)

Order Unit: 1 Piece

(Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	D (mm)	L (mm)	L1 (mm)	W (mm)	Screw Diameter	Working Load (kN)	SPQ (piece)	Weight (g)
380-3686	TUBA-5025	¥1,111	¥1,200	10	50	25	34	M8 x 1.25	0.78	20	85
380-3694	TUBA-7025	¥1,824	¥1,970	10	70	25	50	M8 x 1.25	0.78	10	124
380-3708	TUBA-7030	¥1,166	¥1,260	10	70	30	35	M8 x 1.25	0.78	10	105
380-3716	TUBA-9040	¥1,500	¥1,620	10	90	40	40	M8 x 1.25	0.78	10	122
380-3724	TUBA-9045	¥1,278	¥1,380	10	90	45	35	M8 x 1.25	0.78	10	121
380-3678	TUBA-10556	¥1,389	¥1,500	10	105	56	35	M8 x 1.25	0.78	10	119
380-3660	TUBA-10045	¥2,157	¥2,330	10	100	45	65	M10 x 1.5	1.47	10	167

Contact us: 0120-509-849 <http://www.orange-book.com/>

Metal Fittings for Handling

Suspension Metal Fittings

Shelf Peg Metal Fittings

Joint Fittings

Steel Wires

Wire Nets

MIZUMOTO MACHINE



Stock 529 Items

## Oval Plate for U-shaped Bolt



- Features** • A plate that matches the pitch of the U-shaped bolt and U-shaped bolt A type.  
**Use** • For assembly with U-shaped bolts.  
**Materials** • **Stainless Steel (SUS304)**  
**Origin** • Taiwan




B-2322

(Price revision date: Jan, 2016) MIZUMOTO MACHINE MFG.Co.Ltd

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	L1 (mm)	L2 (mm)	W (mm)	d (mm)	t (mm)	Applicable U-shape bolt	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
378-9781	B-2322	¥238	¥280	40	30	10	4.7	1.0	TUB-4	2	20	4
378-9799	B-2323	¥255	¥300	47	35	12	5.4	1.0	TUB-5	2	20	8
378-9802	B-2324	¥271	¥320	50	35	15	6.5	1.5	TUB-6	2	20	14
378-9811	B-2325	¥356	¥420	48	32	16	8.8	1.5	-	2	20	14
378-9829	B-2326	¥374	¥440	51	34	16	8.8	1.5	TUBA-5025	2	20	14
378-9837	B-2327	¥374	¥440	51	35	16	8.8	1.5	TUB-8, TUBA-7030/9045/10556	2	20	14
378-9845	B-2328	¥407	¥480	56	40	16	8.8	1.5	TUBA-9040	2	20	16
378-9853	B-2329	¥442	¥520	66	50	16	8.8	1.5	TUBA-7025	2	20	20
378-9870	B-2330	¥577	¥680	70	50	20	11.0	2.0	TUB-10	2	20	34
378-9888	B-2331	¥713	¥840	84	60	24	12.8	2.5	-	2	20	62

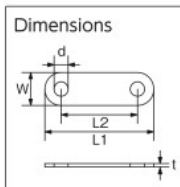

Contact us: 079-246-2501 <http://www.mizumoto-mm.co.jp/>