

Prices displayed include 8% tax.

PEGUET



Stock 152 Items

## Ring Catch "Quick Link Large Open"



Hardware

- Features
- With a smooth nut, you can easily open and close, and you can connect firmly with ropes and the like.
  - The opening opens widely.
- Use
- As joint metal fittings, for attaching chains and the like.
- Specs
- Type: Large open type
- Origin
- France

Materials •Steel •Surface Treatment: Zinc Plated



MRGOZ08.0 (steel) (with ring)

Order Unit: 1 Piece

PEGUET

Order Code	Item No.	Price (per piece)	MSRP (per piece)	D (mm)	S (mm)	L (mm)	E (mm)	B1 (mm)	Working Load (kg)	SPQ (piece)	Weight (g)
819-1959	MRGOZ02.5	¥ 330	-	2.5	7.0	28.0	3.5	7.0	30	100	4
819-1960	MRGOZ03.0	¥ 287	-	3.0	8.5	33.5	4.0	8.5	45	100	7
819-1961	MRGOZ03.5	¥ 298	-	3.5	10.0	39.0	5.0	10.0	90	100	10
819-1962	MRGOZ04.0	¥ 320	-	4.0	11.5	45.0	6.0	11.5	160	100	15
819-1963	MRGOZ05.0	¥ 381	-	5.0	13.0	52.0	7.0	13.0	250	100	25
819-1964	MRGOZ06.0	¥ 449	-	6.0	14.5	58.5	9.0	14.5	350	100	41
819-1965	MRGOZ07.0	¥ 508	-	7.0	16.0	65.0	10.0	16.0	500	100	60
819-1966	MRGOZ08.0	¥ 638	-	8.0	17.5	72.0	11.0	17.5	650	100	91
819-1967	MRGOZ09.0	¥ 767	-	9.0	19.0	77.0	12.0	19.0	800	100	118
819-1968	MRGOZ10.0	¥ 853	-	10.0	20.5	85.5	13.0	20.5	1000	100	157
819-1969	MRGOZ12.0	¥1,327	-	12.0	23.5	100.0	15.0	23.5	1250	100	268
819-1970	MRGOZ14.0	¥1,926	-	14.0	26.5	114.0	17.0	26.5	2000	100	420
819-1971	MRGOZ16.0	¥2,775	-	16.0	29.5	129.0	19.0	29.5	2500	100	630
819-1972	MRGOZ18.0	¥4,440	-	18.0	62.5	140.5	22.0	32.5	3000	100	879
819-1973	MRGOZ20.0	¥6,204	-	20.0	35.5	158.5	24.0	34.5	3600	100	1220

Materials •Stainless Steel (AISI316L)

Order Unit: 1 Piece


Order Code	Item No.	Price (per piece)	MSRP (per piece)	D (mm)	S (mm)	L (mm)	E (mm)	B1 (mm)	Working Load (kg)	SPQ (piece)	Weight (g)
819-1974	MRGOI02.5	¥ 820	-	2.5	7.0	28.0	3.5	7.0	90	100	4
819-1975	MRGOI03.0	¥ 727	-	3.0	8.5	33.5	4.0	8.5	145	100	7
819-1976	MRGOI03.5	¥ 746	-	3.5	10.0	39.0	5.0	10.0	200	100	11
819-1977	MRGOI04.0	¥ 886	-	4.0	11.5	45.0	6.0	11.5	250	100	15
819-1978	MRGOI05.0	¥ 1,048	-	5.0	13.0	52.0	7.0	13.0	400	100	20
819-1979	MRGOI06.0	¥ 1,364	-	6.0	14.5	58.5	9.0	14.5	580	100	42
819-1980	MRGOI07.0	¥ 1,804	-	7.0	16.0	65.0	10.0	16.0	800	100	62
819-1981	MRGOI08.0	¥ 2,376	-	8.0	17.5	72.0	11.0	17.5	980	100	93
819-1982	MRGOI09.0	¥ 2,772	-	9.0	19.0	77.0	12.0	19.0	1250	100	121
819-1983	MRGOI10.0	¥ 3,258	-	10.0	20.5	85.5	13.0	20.5	1600	100	161
819-1984	MRGOI12.0	¥ 5,249	-	12.0	23.5	100.0	15.0	23.5	2200	100	275
819-1985	MRGOI14.0	¥ 8,114	-	14.0	26.5	114.0	17.0	26.5	3100	100	431
819-1986	MRGOI16.0	¥12,059	-	16.0	29.5	129.0	19.0	29.5	4000	100	646

Materials •Aluminum

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	D (mm)	S (mm)	L (mm)	E (mm)	B1 (mm)	Working Load (kg)	SPQ (piece)	Weight (g)
819-1987	MRGOZIC07.0	¥ 918	-	7	16.0	65.0	10	16.0	200	100	22
819-1988	MRGOZIC10.0	¥1,865	-	10	20.5	85.5	13	20.5	400	100	56

URL <http://www.orange-book.com/>

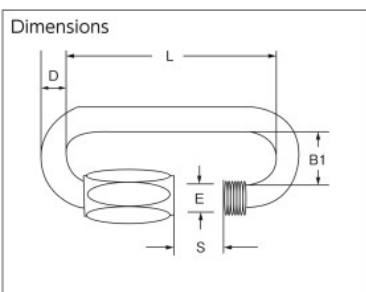

PEGUET



Stock 152 Items

## Ring Catch "Quick Link Delta"



- Features
- With a smooth nut, you can easily open and close, and you can connect firmly with ropes and the like.
- Use
- As joint metal fittings, for attaching chains and the like.
- Specs
- Type: Delta type
- Materials
- Steel •Surface Treatment: Zinc Plated
- Origin
- France



MRDZ16.0 (with ring)

Order Unit: 1 Piece

PEGUET

Order Code	Item No.	Price (per piece)	MSRP (per piece)	D (mm)	S (mm)	L (mm)	E (mm)	W (mm)	Working Load (kg)	SPQ (piece)	Weight (g)
819-1989	MRDZ02.5	¥ 386	-	2.5	3.5	22	3.5	22.0	25	100	3
819-1990	MRDZ03.0	¥ 327	-	3.0	4.0	24	4.0	29.0	40	100	6
819-1991	MRDZ03.5	¥ 330	-	3.5	5.0	29	5.0	31.0	70	100	9
819-1992	MRDZ04.0	¥ 370	-	4.0	5.5	32	6.0	35.5	100	100	14
819-1993	MRDZ05.0	¥ 418	-	5.0	6.5	38	7.0	40.0	150	100	23
819-1994	MRDZ06.0	¥ 478	-	6.0	7.5	44	9.0	47.0	250	100	39
819-1995	MRDZ07.0	¥ 558	-	7.0	8.5	49	10.0	51.0	400	100	58
819-1996	MRDZ08.0	¥ 660	-	8.0	10.0	57	11.0	56.0	550	100	88
819-1997	MRDZ09.0	¥ 796	-	9.0	11.0	60	12.0	60.0	700	100	115
819-1998	MRDZ10.0	¥ 886	-	10.0	12.0	67	13.0	66.0	900	100	153
819-1999	MRDZ12.0	¥1,415	-	12.0	15.0	80	15.0	75.0	1100	100	256
819-2000	MRDZ14.0	¥2,006	-	14.0	17.0	95	17.0	85.0	1800	100	404
819-2001	MRDZ16.0	¥2,809	-	16.0	19.0	106	19.0	93.0	2200	100	612
819-2002	MRDZ18.0	¥6,249	-	18.0	23.0	119	22.0	102.0	2600	100	845
819-2003	MRDZ20.0	¥8,376	-	20.0	24.0	136	24.0	112.0	3000	100	1185

URL <http://www.orange-book.com/>

