

The number next to the logo mark indicates items in stock for each brand.

TRUSCO



Stock 38,650 Items

Spring Hook



TSH-10

- Features • Standard spring hook.
 Use • Suitable for connection of chain/wire/rope, etc., and joint of terminal metal fittings.
 Materials • **Steel**
 • **Surface Treatment: Unichrome**
 Origin • China




Example

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	D (mm)	L (mm)	W (mm)	A (mm)	E (mm)	Working Load (kN)	SPQ (piece)	Weight (g)
275-7991	TSH-05	¥213	¥230	5	50.0	14	7.0	7.0	0.4	30	15.3
275-8008	TSH-06	¥249	¥270	6	60.0	17	8.5	7.5	0.5	30	25.7
275-8016	TSH-07	¥314	¥340	7	72.0	19	10.5	8.5	0.6	30	41.7
275-8024	TSH-08	¥379	¥410	8	81.5	23	11.0	11.0	0.7	20	62.0
275-8032	TSH-10	¥482	¥520	10	101.0	29	14.0	13.0	0.9	20	121.0

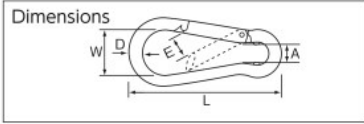

Contact us: 0120-509-849 <http://www.orange-book.com/>

MIZUMOTO MACHINE



Stock 529 Items

Open Hook B Type



B-885 (with ring)

- Features • Since it is the outward opening structure with a ring.
 Use • Suitable for connection of chain/wire/rope, etc., and joint of terminal metal fittings.
 Materials • **Stainless Steel (SUS304)**
 Origin • China




Example

Order Unit: 1 Piece

MIZUMOTO MACHINE MFG.Co.Ltd

Order Code	Item No.	Price (per piece)	MSRP (per piece)	D (mm)	L (mm)	W (mm)	S (mm)	d1 (mm)	d2 (mm)	Working Load (kN)	SPQ (piece)	Weight (g)
211-6189	B-885	¥ 814	¥ 960	5	55	26	15	6.0	8.0	0.69	20	21
211-6197	B-886	¥1,001	¥1,180	6	63	30	16	7.0	9.5	0.98	20	32
211-6201	B-887	¥1,408	¥1,660	8	84	41	23	9.5	12.5	1.47	20	72
211-6219	B-888	¥2,020	¥2,380	10	102	51	27	10.5	16.0	1.96	10	138

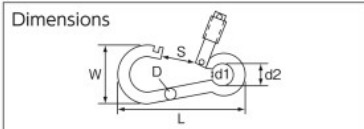

Contact us: 079-246-2501 <http://www.mizumoto-mm.co.jp/>

MIZUMOTO MACHINE



Stock 529 Items

Spring Hook BD type




B-1941

- Features • A spring hook.
 • Since a longer side is loaded when loading, it has the structure that a hook is hard to be loaded.
 Use • Suitable for connection of chain/wire/rope, etc., and joint of terminal metal fittings.
 Materials • **Stainless Steel (SUS304)**
 Origin • China

Order Unit: 1 Piece

MIZUMOTO MACHINE MFG.Co.Ltd

Order Code	Item No.	Price (per piece)	MSRP (per piece)	D (mm)	L (mm)	W (mm)	S (mm)	d1 (mm)	d2 (mm)	Working Load (kN)	SPQ (piece)	Weight (g)
378-9144	B-1938	¥ 577	¥ 680	5	50	30	9	6.0	8	0.59	20	17
378-9152	B-1939	¥ 705	¥ 830	6	60	34	9	7.0	9	0.78	20	29
378-9161	B-1940	¥1,001	¥1,180	8	80	45	12	8.5	12	1.18	20	69
378-9179	B-1941	¥1,595	¥1,880	10	100	55	15	11.5	16	1.47	10	135

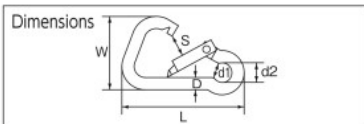

Contact us: 079-246-2501 <http://www.mizumoto-mm.co.jp/>

TRUSCO



Stock 38,650 Items

D Hook




TDF-6

- Features • With its large opening part, it is an easy-to-use joint bracket.
 • It can be opened/closed by laying (pushing) the mechanical spring-like ring part.
 Use • For a connecting brackets for wires, chains, ropes, etc.
 Materials • **Stainless Steel (SUS304)**
 Origin • China

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	D1 (mm)	D2 (mm)	L (mm)	W (mm)	S (mm)	R (mm)	t (mm)	Working Load (kN)	SPQ (piece)	Weight (g)
300-8690	TDF-4	¥ 528	¥ 570	4.6	4	42.0	23	9	3.5	3.0	0.20	20	8
300-8703	TDF-5	¥ 620	¥ 670	5.4	5	52.5	30	13	5.0	4.0	0.29	20	16
300-8711	TDF-6	¥ 759	¥ 820	7.0	6	64.0	34	14	5.5	4.5	0.69	20	29
300-8720	TDF-8	¥1,000	¥1,080	8.7	8	80.0	45	18	7.5	6.4	0.98	20	64
300-8738	TDF-10	¥1,527	¥1,650	11.5	10	105.0	58	25	10.0	7.2	1.47	10	133

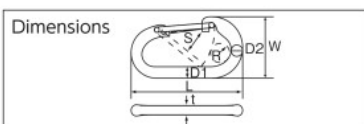

Contact us: 0120-509-849 <http://www.orange-book.com/>