

Rope Stopper Brackets

The number next to the logo mark indicates items in stock for each brand.


Hardware

TRUSCO



Stock 38,650 Items

Heteromorphic Rope Stopper (round type)

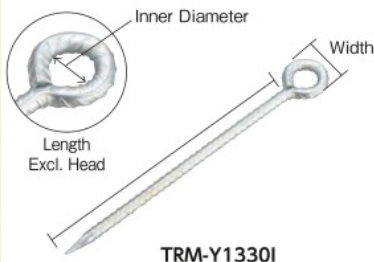

TRM-Y1330I

- Features**
- The pull-out strength has been improved with a variant type.
 - Optimum for pulling ropes and wires, etc. to the ground.
 - Various tents, tarp setting, gardening, compartment rope installation, and the like.
- Use**
- Materials** •Steel •Surface Treatment: Unichrome
- Origin** •China

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Diameter (mm)	Width (mm)	Inner Diameter (mm)	Length Excl. Head (mm)	SPQ (piece)	Weight (kg)
275-3448	TRM-Y1330I	¥ 593	¥ 640	13	52	26	300	50	0.34
275-3456	TRM-Y1340I	¥ 806	¥ 870	13	52	26	400	25	0.45
275-3464	TRM-Y1350I	¥ 962	¥ 1,040	13	52	26	500	20	0.56
275-3472	TRM-Y1360I	¥ 1,047	¥ 1,130	13	52	26	600	20	0.67
275-3481	TRM-Y1390I	¥ 1,278	¥ 1,380	13	52	26	900	10	1.00
275-3499	TRM-Y13120I	¥ 1,574	¥ 1,700	13	52	26	1200	10	1.27
275-3502	TRM-Y13150I	¥ 1,916	¥ 2,070	13	52	26	1500	10	1.56
275-3511	TRM-Y13180I	¥ 2,879	¥ 3,110	13	52	26	1800	5	1.90


Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO



Stock 38,650 Items

Color Heteromorphic Rope Stopper (round type)

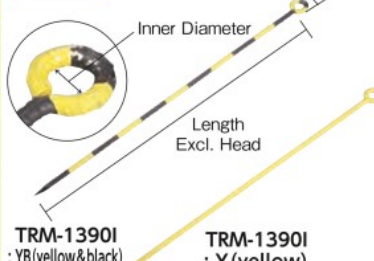

TRM-1390I : YB (yellow & black)

TRM-1390I : Y (yellow)

- Features**
- With colors, noticeable.
 - Optimum for pulling ropes and wires, etc. to the ground.
- Specs**
- Diameter: 13mm, width: 55mm, inner diameter: 27mm
- Materials** •Steel •Surface treatment: Coating
- Origin** •China

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Options (Color)	Price (per piece)	MSRP (per piece)	Color	Length Excl. Head (mm)	SPQ (piece)	Weight (kg)
275-5173	TRM-1390I	YB	¥ 1,389	¥ 1,500	Yellow & Black	900	10	1.00
275-5181	TRM-1390I	BR	¥ 1,371	¥ 1,480	Brown	900	10	1.00
275-5190	TRM-1390I	WV	¥ 1,371	¥ 1,480	White	900	10	1.00
275-5203	TRM-1390I	Y	¥ 1,371	¥ 1,480	Yellow	900	10	1.00
275-5211	TRM-13150I	YB	¥ 1,916	¥ 2,070	Yellow & Black	1500	10	1.56
275-5220	TRM-13150I	BR	¥ 1,898	¥ 2,050	Brown	1500	10	1.56
275-5238	TRM-13150I	WV	¥ 1,898	¥ 2,050	White	1500	10	1.56
275-5246	TRM-13150I	Y	¥ 1,898	¥ 2,050	Yellow	1500	10	1.56

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO



Stock 38,650 Items

Anchor Pin



TPA-150

TPA-200

- Features**
- Head hook secures net, seat, rope tightly.
 - Head striking surface is large and its work is accurate and easy.
- Use**
- Fix the net, sheet and the like to the ground.
 - For fixing the ropes and the like to the ground.
- Materials** •Plastic
- Origin** •Japan

Example



Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Rope Used Diameter (mm)	SPQ (piece)	Weight (g)
275-3707	TPA-100	¥65	¥ 70	102	6 to 8	600	5.00
275-3715	TPA-150	¥69	¥ 75	152	6 to 8	500	7.80
275-3723	TPA-200	¥97	¥ 105	207	6 to 8	200	24.85


Contact us:0120-509-849 <http://www.orange-book.com/>

YUTAKA



Stock 1,604 Items

Hammering Stick I Type

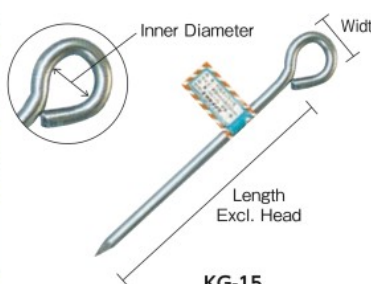

KG-15

- Features**
- A bracket that is hammered when fixing a rope, a net, etc., to the ground, etc.
- Use**
- Fixing a rope, a net, etc., to the ground.
- Materials** •Steel •Surface Treatment: Plated Finishing
- Origin** •Japan

Order Unit: 1 Piece

YUTAKA MAKE Co.Ltd

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Diameter (mm)	Width (mm)	Inner Diameter (mm)	Length Excl. Head (mm)	SPQ (piece)	Weight (g)
794-6023	KG-15	¥204	-	8	33	18	160	100	91
794-6031	KG-16	¥216	-	8	33	18	210	100	111
794-6040	KG-17	¥224	-	8	33	18	260	100	130

Contact us:072-441-2220 <http://www.yutakamake.co.jp/>