

Suspension Brackets (screw-in type)

Stock 223Items

2-977


Prices displayed include 8% tax.

TRUSCO
 Stock 38,650 Items

Lamp Sling



Use •Screw into the wooden backing and used it as a hanging and fixing brackets.
 Materials •Brass (C2700W)
 Origin •Japan

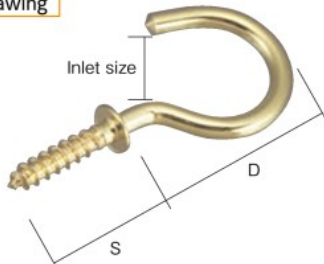

TYT-B13



Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm)		Inlet Size (mm)	Wire Diameter (mm)	Load Capacity (kg)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
				S	D						
275-7443	TYT-B13	¥426	¥460	8.5	13	4.0	2.0	0.8	50	10	60
275-7451	TYT-B16	¥426	¥460	9.5	16	5.0	2.2	1.0	40	10	60
275-7460	TYT-B20	¥426	¥460	11.0	20	8.5	2.4	1.5	30	10	60
275-7478	TYT-B22	¥426	¥460	11.0	22	9.0	2.4	1.5	27	10	60
275-7486	TYT-B25	¥426	¥460	14.0	25	9.5	2.8	2.5	20	10	60
275-7494	TYT-B28	¥426	¥460	16.0	28	11.0	3.1	3.0	15	10	60
275-7508	TYT-B32	¥426	¥460	17.0	32	13.5	3.5	3.5	12	10	70
275-7516	TYT-B35	¥426	¥460	18.0	35	14.0	3.8	4.0	9	10	70
275-7524	TYT-B38	¥426	¥460	18.0	38	15.0	3.8	4.0	8	10	70
275-7532	TYT-B45	¥426	¥460	21.0	45	20.0	4.2	4.5	5	10	70
275-7541	TYT-B50	¥426	¥460	23.0	50	19.5	4.8	6.0	3	10	70


Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO
 Stock 38,650 Items

Screw Hook



Use •Screw into the wooden backing wall and used it as a hanging and fixing brackets.
 Materials •Brass (C2700W)
 Origin •Japan

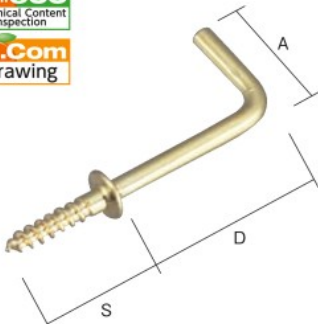

TYK-B13



Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm)			Wire Diameter (mm)	Load Capacity (kg)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
				S	D	A					
275-7338	TYK-B13	¥426	¥460	8.5	13	7.5	2.0	0.8	55	10	70
275-7346	TYK-B16	¥426	¥460	9.5	16	10.5	2.2	1.0	45	10	70
275-7354	TYK-B20	¥426	¥460	11.0	20	12.5	2.4	1.5	35	10	70
275-7362	TYK-B22	¥426	¥460	11.0	22	14.0	2.4	1.5	30	10	70
275-7371	TYK-B25	¥426	¥460	14.0	25	14.5	2.8	2.5	22	10	70
275-7389	TYK-B28	¥426	¥460	16.0	28	16.0	3.1	3.0	16	10	70
275-7397	TYK-B32	¥426	¥460	17.0	32	20.0	3.5	3.5	13	10	70
275-7401	TYK-B35	¥426	¥460	18.0	35	21.0	3.8	4.0	10	10	70
275-7419	TYK-B38	¥426	¥460	18.0	38	22.0	3.8	4.0	9	10	70
275-7427	TYK-B45	¥426	¥460	21.0	45	26.0	4.2	4.5	6	10	70
275-7435	TYK-B50	¥426	¥460	23.0	50	27.5	4.8	6.0	4	10	70


Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO
 Stock 38,650 Items

Heaton



Use •Screw into the wooden backing wall and used it as a hanging and fixing brackets.
 Materials •Brass (C2700W)
 Origin •Japan

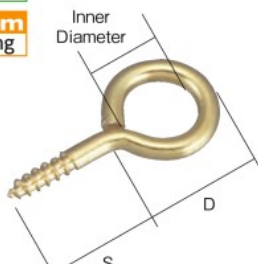

THT-B000



Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Nominal Dimension	Dimension (mm)		Wire Diameter (mm)	Inner Diameter (mm)	Load Capacity (kg)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
					S	D						
275-7222	THT-B000	¥426	¥460	000	7.5	7.0	1.4	3.7	0.2	60	10	60
275-7231	THT-B00	¥426	¥460	00	8.0	7.0	1.6	3.8	0.3	60	10	60
275-7249	THT-B0	¥426	¥460	0	10.5	9.5	1.8	5.7	0.5	55	10	60
275-7257	THT-B2	¥426	¥460	2	12.5	10.5	2.0	6.5	0.8	50	10	60
275-7265	THT-B4	¥426	¥460	4	13.5	12.5	2.2	8.1	1.0	40	10	60
275-7273	THT-B6	¥426	¥460	6	15.5	14.5	2.8	8.9	2.0	25	10	60
275-7281	THT-B8	¥426	¥460	8	20.0	16.5	3.1	9.8	2.5	16	10	60
275-7290	THT-B10	¥426	¥460	10	22.5	19.5	3.8	11.4	3.0	10	10	60
275-7303	THT-B12	¥426	¥460	12	23.0	22.0	4.2	12.6	3.5	7	10	60
275-7311	THT-B14	¥426	¥460	14	25.0	24.0	4.8	13.9	4.0	5	10	60
275-7320	THT-B16	¥426	¥460	16	26.0	29.0	5.8	18.4	5.0	3	10	60

Contact us:0120-509-849 <http://www.orange-book.com/>

Hardware

Door Closers

Door Stoppers

Hinges

Slide Bolt Latches

Catches

Handles

Keys

Chains

Wire Ropes

Metal Fittings for Handling

Suspension Metal Fittings

Shelf Peg Metal Fittings

Joint Fittings

Steel Wires

Wire Nets

Inspection Doors, Air Inlet/Outlets

Handrails, Slopes

Corrugated Plates

Plastic Materials

Metal Materials

Construction Materials

Sash Rollers

Door Hangers