


TRUSCO **Stock 38,650 Items**

"Joint Metal Fitting 19 Type J"

Com **eco** Chemical Content Inspection **Com** Drawing

- Features • A simple and versatile combination.
 Use • Connecting metal fitting.
 • Car parts mounting metal fitting.
 Origin • Japan

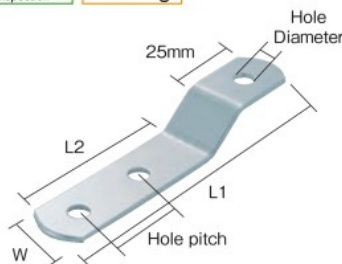

TK19-J3C (steel)



TK19-J3B (steel (black coating finishing))

Item No.	Hole Pitch (mm)
TK19-J2C	-
TK19-J3C·TK19-J4C	25
TK19-J2B	-
TK19-J3B·TK19-J4B	25
TK19-J2S	-
TK19-J3S·TK19-J4S	25

Steel Materials • Steel • Surface Treatment: Chrome Plated Finishing

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1571	TK19-J2C	¥166	¥180	2	19	72	34.5	6.5	2	10	20
283-1589	TK19-J3C	¥194	¥210	2	19	97	59.5	6.5	3	10	27
287-9085	TK19-J4C	¥222	¥240	2	19	122	84.5	6.5	4	10	34

Steel (black coating finishing) Materials • Steel • Surface Treatment: Black Coated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
482-0509	TK19-J2B	¥166	¥180	2	19	72	34.5	6.5	2	10	20
482-0517	TK19-J3B	¥194	¥210	2	19	97	59.5	6.5	3	10	27
482-0525	TK19-J4B	¥222	¥240	2	19	122	84.5	6.5	4	10	34

Stainless Steel Materials • Stainless Steel (SUS304)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1686	TK19-J2S	¥249	¥270	2	19	72	34.5	6.5	2	10	19
283-1694	TK19-J3S	¥259	¥280	2	19	97	59.5	6.5	3	10	26
283-1708	TK19-J4S	¥287	¥310	2	19	122	84.5	6.5	4	10	32


Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

"Joint Metal Fitting 19 Type Z"

Com **eco** Chemical Content Inspection **Com** Drawing

- Features • A simple and versatile combination.
 Use • Connecting metal fitting.
 • Car parts mounting metal fitting.
 Origin • Japan

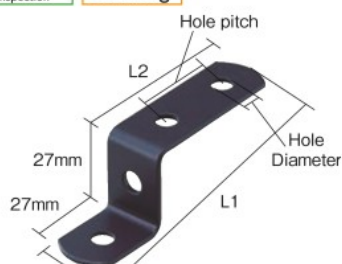

TK19-Z4B (steel (black coating finishing))



TK19-Z4S (stainless steel)

Item No.	Hole Pitch (mm)
TK19-Z3C	-
TK19-Z4C to TK19-Z6C	25
TK19-Z3B	-
TK19-Z4B to TK19-Z6B	25
TK19-Z3S	-
TK19-Z4S to TK19-Z6S	25

Steel Materials • Steel • Surface Treatment: Chrome Plated Finishing

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1287	TK19-Z3C	¥194	¥210	2	19	52	27	6.5	3	10	20
283-1295	TK19-Z4C	¥213	¥230	2	19	77	52	6.5	4	10	27
283-1309	TK19-Z5C	¥241	¥260	2	19	102	77	6.5	5	10	33
283-1317	TK19-Z6C	¥231	¥250	2	19	127	102	6.5	6	10	40

Steel (black coating finishing) Materials • Steel • Surface Treatment: Black Coated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
482-0746	TK19-Z3B	¥194	¥210	2	19	52	27	6.5	3	10	20
482-0754	TK19-Z4B	¥213	¥230	2	19	77	52	6.5	4	10	27
482-0762	TK19-Z5B	¥241	¥260	2	19	102	77	6.5	5	10	33
482-0771	TK19-Z6B	¥231	¥250	2	19	127	102	6.5	6	10	40

Stainless Steel Materials • Stainless Steel (SUS304)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1325	TK19-Z3S	¥287	¥310	2	19	52	27	6.5	3	10	19
283-1333	TK19-Z4S	¥296	¥320	2	19	77	52	6.5	4	10	25
283-1341	TK19-Z5S	¥342	¥370	2	19	102	77	6.5	5	10	32
283-1350	TK19-Z6S	¥399	¥430	2	19	127	102	6.5	6	10	38

Contact us: 0120-509-849 <http://www.orange-book.com/>