

Door Closers

Door Stoppers

Hinges

Slide Bolt Latches

Catches

Handles

Keys

Chains

Wire Ropes

Metal Fittings for Handling

Suspension Metal Fittings

Shelf Peg Metal Fittings

Joint Fittings

Steel Wires

Wire Nets

Inspection Doors, Air Inlet/Outlets

Handrails, Slopes

Corrugated Plates

Plastic Materials

Metal Materials

Construction Materials


Sash Rollers

Door Hangers



Stock 38,650 Items

"Joint Metal Fitting 24 Type L Flat"

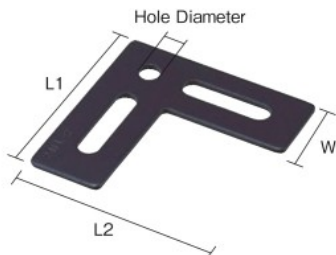

TK24-FL2B (steel (black coating finishing))

- Features**
- Easy and fine adjustment is possible even after temporarily attaching in advance when installing equipment.
 - Extensible adjustments are possible with a single screwdriver.
 - A simple and versatile combination.
- Use**
- Connecting metal fitting.
 - Car parts mounting metal fitting.
- Specs**
- Long Hole Diameter: 7 x 30mm
- Origin**
- Japan

Steel Materials •Steel
•Surface Treatment: Chrome Plated Finishing

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1481	TK24-FL2C	¥249	¥270	2.3	24	65	65	6.5	3	20	38
283-1490	TK24-FL3C	¥296	¥320	2.3	24	100	65	6.5	4	20	48

Steel (black coating finishing) Materials •Steel
•Surface Treatment: Black Coated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
482-0801	TK24-FL2B	¥249	¥270	2.3	24	65	65	6.5	3	20	38
482-0819	TK24-FL3B	¥296	¥320	2.3	24	100	65	6.5	4	20	48



TK24-FL3S (stainless steel)

Stainless Steel Materials •Stainless Steel (SUS304)

Order Unit: 1 Piece


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1643	TK24-FL2S	¥342	¥370	2.0	24	65	65	6.5	3	20	32
283-1651	TK24-FL3S	¥454	¥490	2.0	24	100	65	6.5	4	20	41

Contact us:0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

"Joint Metal Fitting 24 Type T Flat"

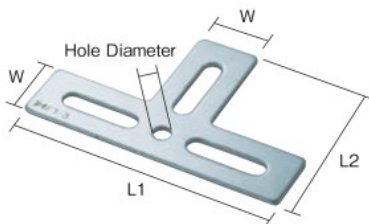

TK24-FT3C (steel)

- Features**
- Easy and fine adjustment is possible even after temporarily attaching in advance when installing equipment.
 - Extensible adjustments are possible with a single screwdriver.
 - A simple and versatile combination.
- Use**
- Connecting metal fitting.
 - Car parts mounting metal fitting.
- Specs**
- Long Hole Diameter: 7 x 30mm
- Origin**
- Japan

Steel Materials •Steel
•Surface Treatment: Chrome Plated Finishing

Order Unit: 1 Piece


TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1503	TK24-FT3C	¥324	¥350	2.3	24	100	65	6.5	4	20	49

Steel (black coating finishing) Materials •Steel
•Surface Treatment: Black Coated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
482-0827	TK24-FT3B	¥324	¥350	2.3	24	100	65	6.5	4	20	49

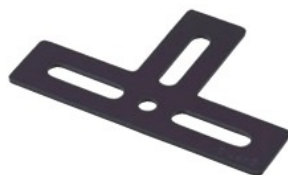

TK24-FT3B (steel (black coating finishing))

Stainless Steel Materials •Stainless Steel (SUS304)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Board Thickness (mm)	Width W (mm)	Length L1 (mm)	Length L2 (mm)	Hole Diameter (mm)	Hole Number	SPQ (piece)	Weight (g)
283-1660	TK24-FT3S	¥518	¥560	2.0	24	100	65	6.5	4	20	43

Contact us:0120-509-849 <http://www.orange-book.com/>