

Prices displayed include 8% tax.

TRUSCO Stock 38,650 Items

Urethane Coil Hose



φ28mm Small Roll Coil

G1/4 Universal Internal Thread

Features

- Excellent in flexibility, elasticity, oil resistance, chemical resistance, wear resistance, heat resistance, and operability.

Specs


- Working Fluid: Air •Fluid Temperature: -5 to 60°C •Working Pressure: 0.8MPa
- Hose Inner Diameter x Outer Diameter: 5 x 8mm
- Coupling Joint: With G1/4 Universal Internal Thread, G1/4 Internal Thread
- Square Indexing Direction: L Type/L Type

Materials

- Polyurethane


Origin

- Japan

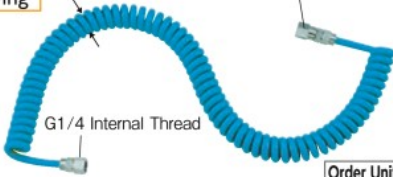

CH-400

Square Indexing Direction

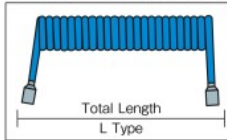

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coil Diameter (mm)	Color	Operating Range (m)	Total Length (mm)	Coil Length (mm)	SPQ (piece)	Weight (g)
231-5378	CH-300	¥3,092	¥3,340	28	Blue	1.4	400	300	10	120
231-5386	CH-400	¥3,833	¥4,140	28	Blue	1.9	500	400	10	150
231-5394	CH-600	¥5,638	¥6,090	28	Blue	2.9	700	600	10	210
231-5408	CH-750	¥6,258	¥6,760	28	Blue	3.4	850	750	10	250

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Urethane Coil Hose



φ28mm Small Roll Coil

G1/4 Internal Thread

Features

- Excellent in flexibility, elasticity, oil resistance, chemical resistance, wear resistance, heat resistance, and operability.

Specs

- Working Fluid: Air •Fluid Temperature: -5 to 60°C •Working Pressure: 0.8MPa
- Hose Inner Diameter x Outer Diameter: 5 x 8mm
- Coupling Joint: With G1/4 Universal Internal Thread, G1/4 Internal Thread
- Square Direction: L Type/Straight Type

Materials

- Polyurethane


Origin

- Japan



CH-300-30

Square Indexing Direction

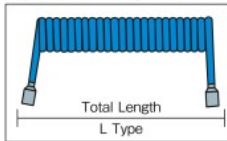

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coil Diameter (mm)	Color	Operating Range (m)	Total Length (mm)	Coil Length (mm)	SPQ (piece)	Weight (g)
231-5416	CH-300-15	¥4,064	¥4,390	28	Blue	2.9	1900	300	10	190
231-5424	CH-300-30	¥4,832	¥5,220	28	Blue	4.4	3400	300	10	240

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Urethane Coil Hose



φ28mm Small Roll Coil

G1/4 Internal Thread

Features


- Excellent in flexibility, elasticity, oil resistance, chemical resistance, wear resistance, heat resistance, and operability.

Specs

- Working Fluid: Air •Fluid Temperature: -5 to 60°C •Working Pressure: 0.8MPa
- Hose Inner Diameter x Outer Diameter: 5 x 8mm
- Coupling Joint: With G1/4 Universal Internal Thread, G1/4 Internal Thread
- Square Indexing Direction: Straight Type/Straight Type

Materials


- Polyurethane Origin •Japan

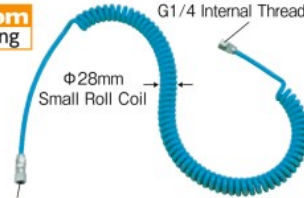

CHA-600

G1/4 Universal Internal Thread

Square Indexing Direction

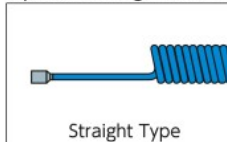

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coil Diameter (mm)	Color	Operating Range (m)	Total Length (mm)	Coil Length (mm)	SPQ (piece)	Weight (g)
231-5432	CHA-300	¥3,175	¥3,430	28	Blue	1.4	500	300	10	160
231-5441	CHA-400	¥3,943	¥4,260	28	Blue	1.9	700	400	10	190
231-5459	CHA-500	¥4,564	¥4,930	28	Blue	2.4	830	500	10	220
231-5467	CHA-600	¥5,638	¥6,090	28	Blue	2.9	930	600	10	250
231-5475	CHA-700	¥5,860	¥6,330	28	Blue	3.4	1030	700	10	280
231-5483	CHA-800	¥6,341	¥6,850	28	Blue	3.8	1130	800	10	310

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Urethane Coil Hose



G1/4 Universal Internal Thread

Features

- Hard to be folded and it has excellent wear resistance.
- Excellent in flexibility, elasticity, retractility. Moreover, it is tough.
- Since the hand part is straight, hand hose is not necessary.

Specs


- Working Fluid: Air •Fluid Temperature: -5 to 60°C
- Working Pressure: 0.8MPa •Hose Inner Diameter x Outer Diameter: 5 x 8mm
- Coupling Joint: With R1/4 external Thread, G1/4 external Thread, G1/4 Universal external Thread

Materials


- Polyurethane

Origin

- China

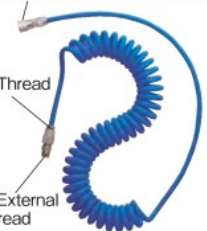

TUNA-3

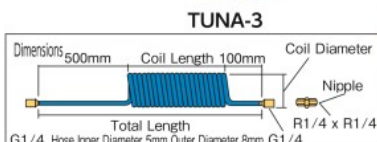

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coil Diameter (mm)	Color	Operating Range (m)	Total Length (mm)	Coil Length (mm)	SPQ (piece)	Weight (g)
279-5744	TUNA-3	¥1,972	¥2,130	42	Blue	2.0	780	180	10	190
279-5752	TUNA-5	¥2,213	¥2,390	42	Blue	4.0	1000	400	10	280
279-5761	TUNA-7	¥2,499	¥2,700	42	Blue	6.0	1230	630	10	370
279-5779	TUNA-10	¥2,740	¥2,960	42	Blue	8.0	1400	800	10	460

Contact us:0120-509-849 <http://www.orange-book.com/>