

Prices displayed include 8% tax.


TRUSCO

Stock
38,650 Items

Coil Hose Blow Gun Set

RoHS

Com
Drawing



Features

- Gun and hose are set and they can be as is. (equipped with coupling plug)
- Easy flow rate adjustment with lever operation at hand.
- Versatile type that can supply either air up or down.
- Hard to be folded and it has excellent wear resistance.
- For dust work.

Use Specs

- Coil Hose: 5 x 8mm (inner diameter x outer diameter)
- Max Working Pressure: 0.8MPa
- Nozzle length: 90mm

Origin

- Japan

TCBS


TRUSCO

Stock
38,650 Items

Urethane Coil Hose for Replacement

RoHS

Com
Drawing

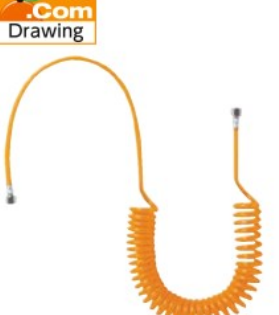

Features

- Elasticity is strong and usability is excellent.
- Erosion deterioration due to moisture and mold at high temperature and humidity is small.

Specs

- Coil Hose: 5 x 8mm (inner diameter x outer diameter)
- Max Air Pressure: 0.7MPa

Origin

- Japan

SC-SN

Order Unit: 1 Set TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	Nozzle Opening Diameter (mm)	Max Working Dimension (m)	SPQ (set)	Weight (g/set)
497-4417	TCBS-3	¥4,439	¥4,795	3.6	2.4	10	300
497-4425	TCBS-5	¥4,962	¥5,360	3.6	4.0	10	390
497-4433	TCBS-7	¥6,184	¥6,680	3.6	5.6	10	480

Contact us: 0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Hose Mounting Port	Max Working Dimension (m)	SPQ (piece)	Weight (g)
762-0870	SC-3SN	¥1,981	¥2,140	G1/4	2	10	150
762-0888	SC-5SN	¥2,546	¥2,750	G1/4	4	10	220
762-0896	SC-7SN	¥3,055	¥3,300	G1/4	6	10	290
762-0861	SC-10SN	¥3,564	¥3,850	G1/4	8	5	400

Contact us: 0120-509-849 <http://www.orange-book.com/>


TRUSCO

Stock
38,650 Items

Replacement Spring Urethane Coiled Hose

RoHS

Com
Drawing



Features

- Elasticity is strong and usability is excellent.
- Erosion deterioration due to moisture and mold at high temperature and humidity is small.


Specs

- Coil Hose: 5 x 8mm (inner diameter x outer diameter)
- Max Air Pressure: 0.7MPa

Origin

- Japan

Example

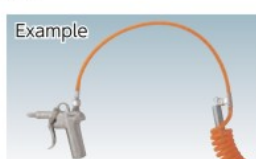

SC-3S


KURITA

Stock
47 Items

Air Gun Set

RoHS

Com
Drawing



Features

- This is a set item of plug for air gun, coil hose and coil hose.
- Since this set is equipped with the plug compatible with High Coupler series, piping can be performed with one touch.

Specs

- Coil Hose: 5 x 8mm (inner diameter x outer diameter)
- Max Air Pressure: 0.7MPa
- Max working pressure: 4.3m

Origin

- Japan

AG500LS

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Hose Mounting Port	Max Working Dimension (m)	SPQ (piece)	Weight (g)
231-4649	SC-3S	¥2,083	¥2,250	G1/4	2	10	280
231-4657	SC-5S	¥2,667	¥2,880	G1/4	4	10	400
231-4665	SC-7S	¥3,250	¥3,510	G1/4	6	10	530
231-4673	SC-10S	¥3,813	¥4,120	G1/4	8	5	690

Contact us: 0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Set KURITA SEISAKUSHO

Order Code	Item No.	Price (per set)	MSRP (per set)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	Weight (g/set)
556-7963	AG500LS	¥5,676	¥5,660	22	2	G1/8	393

Contact us: 03-5638-8261 <http://www.cup-kurita.co.jp/>

KINKI

Stock
102 Items

Screw Air Hose/Duster Gun Set

RoHS

Com
eco
Chemical Content Inspection



Features

- Gun and hose are set and they can be as is.
- Air flow rate can be adjusted with nozzle.

Specs

- Coil Hose: 5 x 8mm (inner diameter x outer diameter)
- Max Air Pressure: 0.8MPa
- Nozzle length: 24mm
- Nozzle Mounting Port: G1/8

Origin

- Japan

Example



K-601R-05S


KINKI

Stock
102 Items

Screw Air Hose for Replacement

RoHS

Com
eco
Chemical Content Inspection



Features

- Elasticity is strong and usability is excellent.


Specs

- Coil Hose: 5 x 8mm (inner diameter x outer diameter)
- Max Air Pressure: 0.8MPa

Origin

- Japan

Example



KS-5

Order Unit: 1 Set (Price revision date: Apr, 2015) KINKI SEISAKUSHO

Order Code	Item No.	Price (per set)	MSRP (per set)	Nozzle Opening Diameter (mm)	Max Working Dimension (m)	SPQ (set)	Weight (g/set)
108-2213	K-601R-03S	¥4,767	¥5,150	2	2	10	468
108-2272	K-601R-05S	¥5,601	¥6,050	2	4	10	604
108-2281	K-601R-07S	¥6,295	¥6,800	2	6	5	742
108-2299	K-601R-10S	¥7,128	¥7,700	2	8	5	886

Contact us: 06-6700-2601 <http://www.kinki-seisakusho.co.jp/>

Order Unit: 1 Piece (Price revision date: Apr, 2015) KINKI SEISAKUSHO

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Hose Mounting Port	Max Working Dimension (m)	SPQ (piece)	Weight (g)
108-2302	KS-3	¥2,592	¥2,800	G1/4	2	10	186
108-2311	KS-5	¥3,194	¥3,450	G1/4	4	10	270
108-2329	KS-7	¥3,888	¥4,200	G1/4	6	5	354
108-2337	KS-10	¥4,443	¥4,800	G1/4	8	5	505

Contact us: 06-6700-2601 <http://www.kinki-seisakusho.co.jp/>

Pneumatic Tools

Air Impact Wrenches

Air Ratchet Wrenches

Air Screwdrivers

Air Drills

Air Micro Grinders

Air Grinders

Air Files

Air Sanders

Air Belt Sanders

Air Chisels

Air Hammers

Air Saws

Air Bevelers

Air Nippers

Air Dusters

Air Guns

Air Blast Machines