

# Air Duster Nozzles

Air Impact Wrenches

Air Ratchet Wrenches

Air Screwdrivers

Air Drills

Air Micro Grinders

Air Grinders

Air Files

Air Sanders

Air Belt Sanders

Air Chisels

Air Hammers

Air Saws

Air Bevelers

Air Nippers

Air Dusters

Air Guns

Air Blast Machines

**KINKI** Stock 102 Items

## Bent Nozzle (with tip rubber)

- Features**
- Prevents scratches on the workpiece at the working tip.
- Origin**
- Japan



Order Unit: 1 Piece (Price revision date: Apr, 2015) KINKI SEISAKUSYO

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	SPQ (piece)	Weight (g)
411-0307	KN-35BTR	¥2,777	¥3,000	350	2.5	G1/8	10	98
413-3692	KN-77BTR	¥3,888	¥4,200	770	2.5	G1/8	10	174

Contact us: 06-6700-2601 <http://www.kinki-seisakusho.co.jp/>

The number next to the logo mark indicates items in stock for each brand.

**TRUSCO** Stock 38,650 Items

## Air Duster Extension Nozzle



- Features**
- Length of the nozzle pipe can be adjusted freely.
  - This nozzle is safe because the protective cap is attached to the tip of the nozzle.
- Origin**
- Japan



Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	SPQ (piece)	Weight (g)
228-0736	TD-18-FLN10	¥1,203	¥1,300	35 to 75	2	G1/8	10	31
228-0744	TD-18-FLN20X	¥1,537	¥1,660	100 to 150	2	G1/8	10	42
228-0752	TD-18-FLN40X	¥2,046	¥2,210	230 to 380	2	G1/8	10	95
228-0761	TD-18-FLN40	¥2,203	¥2,380	190 to 400	2	G1/8	10	95

Contact us: 0120-509-849 <http://www.orange-book.com/>

**TRUSCO** Stock 38,650 Items

## Air Duster Extension Pipe



- Features**
- Air duster on hand can be expandable nozzle type.
  - The length of the extension pipe can be freely adjusted between 305 to 525mm.
  - Various air duster nozzles (thread diameter G1/8) can be mounted at the tip, greatly expanding the applications.
- Origin**
- Japan



**KINKI** Stock 102 Items

## Air Duster Nozzles



- Features**
- Nozzle that can expand the length. Possible from 650mm to 1550mm.
  - Since the tip is stainless steel, it has durability.
- Origin**
- Japan



Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	SPQ (piece)	Weight (g)
329-4676	TD-18-SEP	¥2,685	¥2,900	305 to 525	10	108

Contact us: 0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Piece (Price revision date: Apr, 2015) KINKI SEISAKUSYO

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	SPQ (piece)	Weight (g)
356-8717	K-601-SLN	¥9,257	¥10,000	650 to 1550	3	G1/8	1	460


Contact us: 06-6700-2601 <http://www.kinki-seisakusho.co.jp/>

**TRUSCO** Stock 38,650 Items

## Air Volume Adjusting Long Nozzle



- Features**
- Air volume can be adjusted with the tip of the nozzle.
- Origin**
- Japan

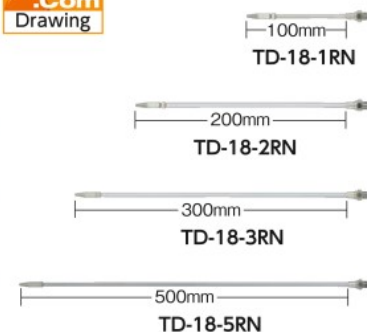

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	SPQ (piece)	Weight (g)
285-4201	TD-18-1RN	¥2,213	¥2,390	100	2	G1/8	20	32
285-4210	TD-18-2RN	¥2,555	¥2,760	200	2	G1/8	20	46
285-4228	TD-18-3RN	¥3,295	¥3,560	300	2	G1/8	20	60
285-4236	TD-18-5RN	¥4,805	¥5,190	500	2	G1/8	20	74

Contact us: 0120-509-849 <http://www.orange-book.com/>

**TRUSCO** Stock 38,650 Items

## Airflow Adjustment Nozzle



- Features**
- Air flow rate can be adjusted at the base of the nozzle.
  - The airflow rate adjustment range is 5 to 100%.
- Origin**
- Japan



Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	SPQ (piece)	Weight (g)
232-1807	TD-18-RN	¥537	¥580	27	2	G1/8	10	21

Contact us: 0120-509-849 <http://www.orange-book.com/>