

Tipped Saws (for building materials)

Stock 510 Items

5-777

Prices displayed include 8% tax.

TRUSCO
Stock 38,650 Items

"Tipped Saw for Sheet Metal"

Regrinding OK

Com Drawing



TGSMS-125

- Features
- A tipped saw for construction sheet metal work.
 - Employs a tip that is unlikely to chip and has excellent in wear resistance.
- Use
- For cutting of galvalume steel plate, metal siding, galvanized iron, tin plate, square wave, color corrugated plate.
- Materials
- Base Metal: Tool Steel
 - Tip: Carbide
- Origin
- Japan

Order Unit: 1 Sheet

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Cutting Performance (mm) Steel	Outer Diameter x Blade Thickness x Hole Diameter (mm)	Number of Blades	Max Working Rotation Speed (rpm)	SPQ (sheet)	Weight (g)
768-3502	TGSMS-100	¥4,805	¥5,190	1.2	100 x 1.0 x 20.0	36	13000	10	60
768-3511	TGSMS-125	¥5,369	¥5,800	1.2	125 x 1.2 x 20.0	46	9600	10	110

Contact us:0120-509-849 <http://www.orange-book.com/>

MOTOYUKI
GLOBAL SAW
Stock 249 Items

Tipped Saw "Global Saw BANKIN TATSUJIN"

New! Regrinding OK



GTS-NA-100

- Features
- Configured with fine teeth to create clean cuts without catching, rattling, or deforming the cutting material.
 - With a high-precision cut restricting guard, an appropriate feed amount into the cutting amount is obtained and this suppresses chipping of the blade tip.
- Use
- For cutting of galvanized steel sheets, square corrugated and square spans, metal siding, roof tile bars, metal drain spouts, corrugated sheets, and tin sheets.
- Materials
- Base Metal: Tool Steel
 - Tip: Cermet
- Origin
- Japan

Warning
• Cannot be used with disk grinders.

Order Unit: 1 Sheet


MOTOYUKI Co.Ltd

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Cutting Performance (mm) Steel	Outer Diameter x Blade Thickness x Hole Diameter (mm)	Number of Blades	Max Working Rotation Speed (rpm)	SPQ (sheet)	Weight (g)
836-1917	GTS-NA-100	¥8,023	¥10,400	1.2	100 x 1.2 x 20	48	13000	10	40
836-1918	GTS-NA-125	¥8,486	¥11,000	1.2	125 x 1.2 x 20	60	9600	10	80

Contact us:0120-278-423 <http://www.motoyuki.co.jp/>

MOTOYUKI
GLOBAL SAW
Stock 249 Items


Diamond Tipped Saw "Global Saw GAIHEKI TATSUJIN" (for ceramic siding boards)

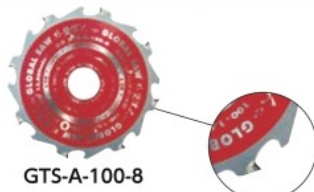

GTS-A-100-8



GTS-A-100-10

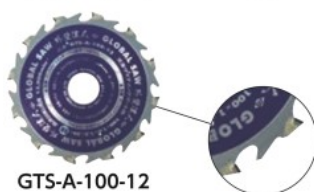

GTS-A-100-12

- Features
- Realized high durability with super hard polycrystalline diamonds.
 - Cutting speed is fast with a thin blade design.
 - Low noise slit employed to reduce noise and vibration when cutting.
- Use
- Ceramic siding boards, press molded cement boards, calcium silicate boards, plaster boards, lath boards, etc.
- Materials
- Base Metal: Tool Steel
 - Tip: Diamond
- Origin
- Japan

Video



Order Unit: 1 Sheet

MOTOYUKI Co.Ltd


Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Outer Diameter x Blade Thickness x Hole Diameter (mm)	Number of Blades	Max Working Rotation Speed (rpm)	SPQ (sheet)	Weight (g)
827-5686	GTS-A-80-8	¥6,094	¥7,900	80 x 1.6 x 20.0	8	15000	10	100
827-5687	GTS-A-100-8	¥6,094	¥7,900	100 x 1.6 x 20.0	8	13000	10	120
827-5690	GTS-A-100-10	¥7,637	¥9,900	100 x 1.6 x 20.0	10	13000	10	120
827-5692	GTS-A-100-12	¥9,180	¥11,900	100 x 1.6 x 20.0	12	13000	10	120
827-5688	GTS-A-110-8	¥6,094	¥7,900	110 x 1.6 x 20.0	8	13000	10	140
827-5689	GTS-A-125-8	¥6,094	¥7,900	125 x 1.6 x 20.0	8	9600	10	160
827-5691	GTS-A-125-10	¥7,637	¥9,900	125 x 1.6 x 20.0	10	9600	10	160
827-5693	GTS-A-125-12	¥9,180	¥11,900	125 x 1.6 x 20.0	12	9600	10	160

Contact us:0120-278-423 <http://www.motoyuki.co.jp/>

MOTOYUKI
GLOBAL SAW
Stock 249 Items

Tipped Saw "Global Saw" (for thin iron sheets)

Regrinding OK

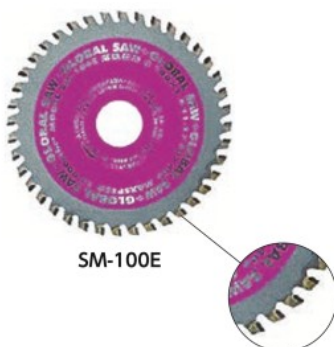

SM-100E

- Features
- For thin iron sheets.
 - Can be used with a wide range of applications such as for metal sidings, thin iron sheets, acrylic, plastic, resin, and plywood.
- Use
- For cutting thin iron sheets, metal sidings, galvanized iron, tin, aluminum sashes, corrugated sheets, PVC, acrylic, plastic, and plywood, etc.
- Materials
- Base Metal: Tool Steel
 - Tip: Carbide
- Origin
- Japan

Order Unit: 1 Sheet

(Price revision date: Apr, 2015) MOTOYUKI Co.Ltd

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Cutting Performance (mm) Steel	Outer Diameter x Blade Thickness x Hole Diameter (mm)	Number of Blades	Max Working Rotation Speed (rpm)	SPQ (sheet)	Weight (g)
379-3508	SM-80E	¥4,937	¥6,400	0.5	80 x 1.5 x 20.0	30	15000	10	80
379-3435	SM-100E	¥5,246	¥6,800	0.5	100 x 1.5 x 20.0	40	13000	10	100
379-3443	SM-110E	¥5,323	¥6,900	0.5	110 x 1.5 x 20.0	40	13000	10	110
379-3451	SM-125E	¥5,786	¥7,500	0.5	125 x 1.6 x 20.0	46	9600	10	120
379-3460	SM-160E	¥5,863	¥7,600	0.5	160 x 1.8 x 20.0	60	6000	10	130
379-3478	SM-180E	¥5,940	¥7,700	0.5	180 x 1.8 x 20.0	64	5500	10	150

Contact us:0120-278-423 <http://www.motoyuki.co.jp/>

Cutting Supplies

Cutting Wheels

Tip Saws

Diamond Cutters

Metal Saws

Band Saws

Machine Saws

Hand Hacksaws

Saw Blades

Air Saw Blades

Jig Saw Blades

! Please wear protective equipment to use safely.