

Prices displayed include 8% tax.

For Saber Saw Main Bodies, see p. 5-324 to 336

Please wear protective equipment to use safely.

TRUSCO Stock 38,650 Items

Saber Saw Blade



- Features**
- Outstanding sharpness.
 - Use **For cutting metal (plate, channel pipe).**
- Specs**
- Compatible Model Manufacturer: Compatible With All Manufacturers
- Materials**
- Blade Edge: Bimetal
 - Saw Blade: Spring Steel
- Origin**
- Taiwan



Estimated Unit Price per Sheet
¥265

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Number of Ridges	Total Length (mm)	Thickness (mm)	Effective Cutting Length (mm)	Cutting Performance (mm)		Q'ty Per Bag (sheet)	Weight (g/bag)
								Iron Pipe (outer diameter x thickness)	60 x 3.175		
389-5262	THS15024-5P	¥1,324	¥1,430	24	150	0.9	130			5	90

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Saber Saw Blade



- Features**
- By using high-speed steel, it improved the cutting performance and realize good blade retention.
 - In particular, it is widely used for indoor work because of little generation of dust and sparks.
 - Use **For cutting of metal pipes, channels, and angles, etc.**
- Specs**
- Thick Saw Blade Type
- Materials**
- High-speed steel
- Origin**
- Japan

Manufacturer	Compatible Model
ASADA	Pipe Saw 150/165S
HITACHI Koki	CR17Y
REX	Hyper Saw 150/150S

Estimated Unit Price per Sheet
¥1,273 to ¥2,000


TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Number of Ridges	Total Length (mm)	Thickness (mm)	Effective Cutting Length (mm)	Cutting Performance (mm)		Q'ty Per Bag (sheet)	Weight (g/bag)
								SGP Pipe (outer diameter x thickness)	48.6 x 3.5		
300-7197	THS21-140X8	¥2,546	¥2,750	8	140	1.6	113			2	82
300-7201	THS22-200X8	¥3,165	¥3,420	8	200	1.6	173			2	120
300-7219	THS23-290X8	¥3,999	¥4,320	8	290	1.6	263			2	178

Contact us:0120-509-849 <http://www.orange-book.com/>

BOSCH Stock 1,429 Items

Saber Saw Blade

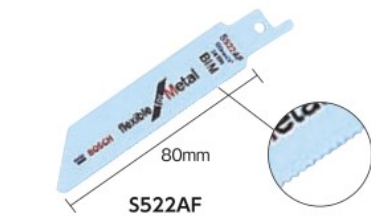

- Features**
- It is outstanding sharpness because it is processed with traditional quenching technology and advanced polishing technology.
 - Bimetal blade that does not snap, burn, and has long life.
 - Use **For cutting metals (soft steel, non-ferrous metals).**
- Specs**
- Compatible Model: BOSCH, Makita, HITACHI, RYOBI, ASADA, MCC
- Materials**
- Bimetal
- Origin**
- Switzerland

Estimated Unit Price per Sheet
¥437


Bosch

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Number of Ridges	Total Length (mm)	Thickness (mm)	Effective Cutting Length (mm)	Cutting Performance (mm)		Q'ty Per Bag (sheet)	Weight (g/bag)
								Soft Steel, Non-Ferrous	0.7 to 3		
733-5768	S522AF	¥2,187	¥2,700	24	100	0.9	80			5	62
733-5784	S522EF	¥2,187	¥2,700	18	100	0.9	80			5	62
733-5750	S422BF	¥2,187	¥2,700	14	100	0.9	80			5	35
733-5776	S522BF	¥2,187	¥2,700	14	100	0.9	80			5	61

Contact us:0120-345-762 <http://www.bosch.co.jp/>

BOSCH Stock 1,429 Items

Saber Saw Blade

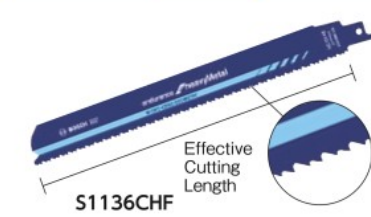

- Features**
- It is outstanding sharpness because it is processed with traditional quenching technology and advanced polishing technology.
 - Bimetal blade that does not snap, burn, and has long life.
 - Use **For cutting metals (soft steel, non-ferrous metals, stainless steel pipes, channels).**
- Specs**
- Compatible Model: BOSCH, Makita, HITACHI, RYOBI, ASADA, MCC
- Materials**
- Bimetal
- Origin**
- Switzerland

Estimated Unit Price per Sheet
¥778 to ¥1,085

Bosch

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Number of Ridges	Total Length (mm)	Thickness (mm)	Effective Cutting Length (mm)	Cutting Performance (mm)		Q'ty Per Bag (sheet)	Weight (g/bag)
								Soft Steel, Non-Ferrous	Stainless Steel Pipe Material		
378-6366	S936CHF	¥4,131	¥5,100	8+10	150	1.1	130	4 to 12	10 to 100	5	145
378-5599	S1126BEF	¥3,888	¥4,800	14+18	225	1.1	205	2 to 8	10 to 175	5	229
378-5602	S1126CHF	¥3,888	¥4,800	8+10	225	1.1	205	4 to 10	10 to 175	5	226
378-5629	S1136CHF	¥5,427	¥6,700	8+10	225	1.1	205	4 to 12	10 to 175	5	225

Contact us:0120-345-762 <http://www.bosch.co.jp/>