

Prices displayed include 8% tax.

TRUSCO Stock 38,650 Items

## "Nylon Mix Wheel" (shaft diameter 6mm)



FM4025-120 (outer diameter 40mm)



FM4025-180 (outer diameter 40mm)





FM4025-240 (outer diameter 40mm)



FM4025-320 (outer diameter 40mm)

- Features**
- Mixed type of nylon and paper (a abrasive grain).
  - Nylon abrasive, which is made by sticking intertwined nylon fiber with abrasive, is used.
  - Compared to the contact of paper abrasive cloths, with the nylon abrasive material, the intertwined fibers serve as a cushion and prevent excessive grinding of the material being processed.
- Use**
- Optimum for stainless steel, aluminum hairline work.
  - For scratches, burrs, bead removal of metal products.
  - For woodwork product wood polishing and polishing of coating.
  - Working Tool: Straight-type grinder.
  - Max Working Rotation Speed: 4000rpm
- Specs Origin**
- Japan

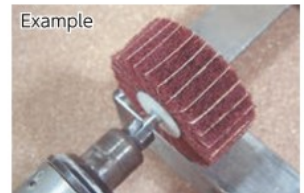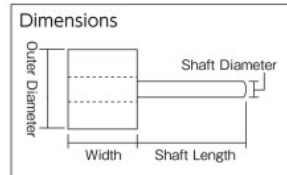

### Outer Diameter 30mm

Specs • Outer Diameter x W x Shaft Diameter x Shaft Length: 30 x 25 x 6 x 40mm

Estimated Unit Price per Piece **¥789**

Order Unit: 1 Box		TRUSCO NAKAYAMA CORPORATION							
Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Layers of Non-Woven Fabric (sheet)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)	
770-5077	FM3025-60	¥3,945	¥4,870	60	13	5	20	172	
770-5085	FM3025-80	¥3,945	¥4,870	80	14	5	20	172	
768-2794	FM3025-120	¥3,945	¥4,870	120	15	5	20	165	
768-2808	FM3025-180	¥3,945	¥4,870	180	16	5	20	165	
768-2816	FM3025-240	¥3,945	¥4,870	240	17	5	20	162	
768-2824	FM3025-320	¥3,945	¥4,870	320	18	5	20	157	
768-2832	FM3025-400	¥3,945	¥4,870	400	18	5	20	157	

### Outer Diameter 40mm

Specs • Outer Diameter x W x Shaft Diameter x Shaft Length: 40 x 25 x 6 x 40mm

Estimated Unit Price per Piece **¥789**

Order Unit: 1 Box											
Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Layers of Non-Woven Fabric (sheet)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)			
172-9993	FM4025-60	¥3,945	¥4,870	60	13	5	20	216			
173-0002	FM4025-80	¥3,945	¥4,870	80	14	5	20	216			
173-0011	FM4025-120	¥3,945	¥4,870	120	15	5	20	211			
173-0029	FM4025-180	¥3,945	¥4,870	180	16	5	20	203			
173-0037	FM4025-240	¥3,945	¥4,870	240	17	5	20	197			
173-0045	FM4025-320	¥3,945	¥4,870	320	18	5	20	199			
173-0053	FM4025-400	¥3,945	¥4,870	400	18	5	20	195			

### Outer Diameter 50mm

Specs • Outer Diameter x W x Shaft Diameter x Shaft Length: 50 x 25 x 6 x 40mm

Estimated Unit Price per Piece **¥799**

Order Unit: 1 Box									
Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Layers of Non-Woven Fabric (sheet)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)	
173-0061	FM5025-60	¥3,994	¥4,930	60	21	5	20	304	
173-0070	FM5025-80	¥3,994	¥4,930	80	23	5	20	316	
173-0088	FM5025-120	¥3,994	¥4,930	120	24	5	20	294	
173-0096	FM5025-180	¥3,994	¥4,930	180	26	5	20	293	
173-0100	FM5025-240	¥3,994	¥4,930	240	26	5	20	270	
173-0118	FM5025-320	¥3,994	¥4,930	320	28	5	20	274	
173-0126	FM5025-400	¥3,994	¥4,930	400	28	5	20	273	

### Outer Diameter 60mm

Specs • Outer Diameter x W x Shaft Diameter x Shaft Length: 60 x 25 x 6 x 40mm

Estimated Unit Price per Piece **¥932**

Order Unit: 1 Box											
Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Layers of Non-Woven Fabric (sheet)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)			
173-0134	FM6025-60	¥4,658	¥5,750	60	21	5	10	335			
173-0142	FM6025-80	¥4,658	¥5,750	80	23	5	10	347			
173-0151	FM6025-120	¥4,658	¥5,750	120	24	5	10	327			
173-0169	FM6025-180	¥4,658	¥5,750	180	26	5	10	317			
173-0177	FM6025-240	¥4,658	¥5,750	240	26	5	10	294			
173-0185	FM6025-320	¥4,658	¥5,750	320	28	5	10	300			
173-0193	FM6025-400	¥4,658	¥5,750	400	28	5	10	287			

### Outer Diameter 80mm

Specs • Outer Diameter x W x Shaft Diameter x Shaft Length: 80 x 25 x 6 x 40mm

Estimated Unit Price per Piece **¥1,037**

Order Unit: 1 Box									
Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Layers of Non-Woven Fabric (sheet)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)	
173-0207	FM8025-60	¥5,184	¥6,400	60	25	5	10	502	
173-0215	FM8025-80	¥5,184	¥6,400	80	28	5	10	524	
173-0223	FM8025-120	¥5,184	¥6,400	120	31	5	10	479	
173-0231	FM8025-180	¥5,184	¥6,400	180	33	5	10	466	
173-0240	FM8025-240	¥5,184	¥6,400	240	34	5	10	427	
173-0258	FM8025-320	¥5,184	¥6,400	320	35	5	10	447	
173-0266	FM8025-400	¥5,184	¥6,400	400	35	5	10	429	

### Outer Diameter 100mm

Specs • Outer Diameter x W x Shaft Diameter x Shaft Length: 100 x 25 x 6 x 40mm

Estimated Unit Price per Piece **¥1,321**

Order Unit: 1 Box											
Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Layers of Non-Woven Fabric (sheet)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)			
173-0274	FM1025-60	¥6,602	¥8,150	60	33	5	10	787			
173-0282	FM1025-80	¥6,602	¥8,150	80	37	5	10	763			
173-0291	FM1025-120	¥6,602	¥8,150	120	37	5	10	698			
173-0304	FM1025-180	¥6,602	¥8,150	180	38	5	10	686			
173-0312	FM1025-240	¥6,602	¥8,150	240	40	5	10	616			
173-0321	FM1025-320	¥6,602	¥8,150	320	42	5	10	634			
173-0339	FM1025-400	¥6,602	¥8,150	400	42	5	10	607			

Contact us: 0120-509-849 <http://www.orange-book.com/>

Grinding Wheels

Disk Papers

Papers for Double Action Sander

Nylon Discs

Urethane Discs

Felt Discs

Diamond Wheels

Grinding Wheels

Dressers

Flap Wheels

Nylon Wheel with Shaft

Shank Mounted Felt Wheels with Shaft

Bands

Shank Mounted Stones

Carbide Bars

Diamond Bars

CBN Bars

Files

Diamond Files

Grinding Stones

Abrasives

Sheet Sanding Papers

Abrasive Belts

Cup Brushes

Wheel Brushes with Shank

Hand Brushes