

Prices displayed include 8% tax.

TRUSCO



Stock 38,650 Items

Flame Retardant Processed Cotton Protective Equipment

Com Drawing



TBK-HZ (hood)



TBK-SMK (apron with sleeve)




TBK-MK (bibbed apron)



TBK-RH (split leg apron)




TBK-UK (arm cover)

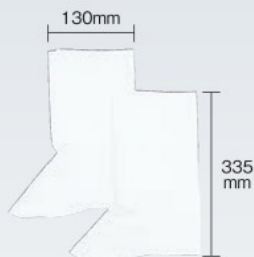

TBK-AK (foot cover)

- Features**
- Lighter than conventional pike fiber, and comfortable work can be done.
 - Fabric to which flame-resistant processing has been applied is used.
 - 100% cotton and comfortable to wear.
 - Since flame-retardant processing is applied, fire does not spread even when it catches fire.
 - The performance is less likely to deteriorate even when it is washed.
- Use**
- As protective equipment for welding work.
- Specs**
- Thickness: 0.64mm
- Materials**
- Cotton
- Origin**
- Japan

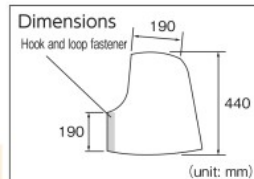


Warning
•Not incombustible.

Hood Specs •With velcro tape

Order Unit: 1 Sheet

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Size	SPQ (sheet)	Weight (g)
484-2839	TBK-HZ	¥6,480	¥7,000	Free	20	170

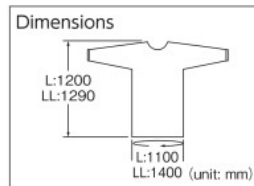

Apron with Sleeve Specs •With binding strings for neck and waist

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Size	SPQ (piece)	Weight (g)
484-2855	TBK-SMK-L	¥23,143	¥25,000	L	10	900
484-2863	TBK-SMK-LL	¥24,994	¥27,000	LL	10	1160

Bibbed Apron Specs •With binding strings for neck and waist


Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Length x Width (mm)	SPQ (piece)	Weight (g)
484-2847	TBK-MK	¥6,989	¥7,550	965 x 610	20	300
836-6925	TBK-MK-L	¥8,979	¥9,700	965 x 720	20	360

Split Leg Apron Specs •With binding strings for waist and legs

Order Unit: 1 Piece


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length x W (mm)	SPQ (piece)	Weight (g)
786-9100	TBK-RH	¥12,034	¥13,000	930 x 520	20	440

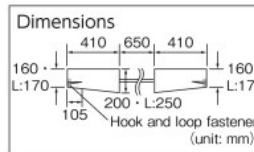

Arm Cover Specs •Wrist: 160mm •Upper width: 200mm
•With velcro tape

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Total Length (mm)	SPQ (set)	Weight (g/set)
484-2871	TBK-UK	¥4,953	¥5,350	410	20	170
836-6926	TBK-UK-L	¥6,387	¥6,900	410	20	220

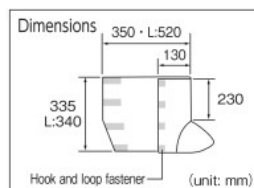

Foot Cover Specs •With velcro tape

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Total Length x W (mm)	SPQ (set)	Weight (g/set)
484-2821	TBK-AK	¥6,184	¥6,680	335 x 130	20	190
836-6924	TBK-AK-L	¥7,683	¥8,300	340 x 130	20	270

Contact us: 0120-509-849 <http://www.orange-book.com/>

Welding Machines

Engine Welders

Spot Welders

Plasma Cutting Machines

Welding Tables

Welding Rods

Accessories for Welding Equipment

Welding Scale Removers

Gas Torches

Gas Burners

Gas Cutting Equipments

Gas Regulators

Brazing Filler Metals

Welding Masks

Protective Eyewears for Welding

Protective Tools for Welding

Spatter Sheets

Protective Fences for Welding

Industrial Markers