

Valves

Screwed Type Pipe Fittings

High Pressure Joints

Welding Fittings

Flanges

Flexible Metal Hoses

Piping Joints for Minor Diameters

Sanitary Pipe Couplings

PVC Pipes

PVC Pipe Joints

PVC Valves

Joints for Water Piping

Protect Accessories for Plumbing

Support Accessories for Plumbing

Maintenance Accessories for Plumbing

Air Conditioning Materials

Valve·Pipe Identifying Goods

Spray Nozzles



Stock 38,650 Items


U Bolt for PC Pipes



TPCU-BT32A (chromate)



TPCU-BT25A-S (stainless steel)

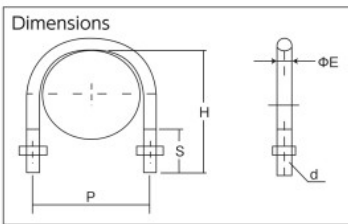

- Features**
- This is a typical product of U-shaped bracket.
 - It can also be used for horizontal piping and vertical piping.
- Use**
- PC tube pipe tightening fixtures.
- Accessories**
- 3/8 Nut 2 Pieces
- Origin**
- Japan



Chromate Features

- As a pipe support, it is the oldest standard product.

Materials

- Steel (SWCH)

Order Unit: 1 Piece (Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nominal Diameter (A)	Compatible Pipe Outer Diameter (mm)	P (mm)	S (mm)	H (mm)	E (mm)	d (mm)	SPQ (piece)	Weight (g)
285-9432	TPCU-BT15A	¥166	¥180	15	25.7	36	25	48	8.3	W3/8	10	72
285-9441	TPCU-BT20A	¥176	¥190	20	31.2	43	25	52	8.3	W3/8	10	77
285-9459	TPCU-BT25A	¥185	¥200	25	37.6	49	25	60	8.3	W3/8	10	87
285-9467	TPCU-BT32A	¥185	¥200	32	46.3	57	30	69	8.3	W3/8	10	96
285-9475	TPCU-BT40A	¥213	¥230	40	52.2	63	30	74	8.3	W3/8	10	102
285-9483	TPCU-BT50A	¥231	¥250	50	64.1	74	30	88	8.3	W3/8	10	116
285-9491	TPCU-BT65A	¥259	¥280	65	79.9	90	30	112	8.3	W3/8	10	140
285-9505	TPCU-BT80A	¥278	¥300	80	92.7	103	30	116	8.3	W3/8	10	145
285-9513	TPCU-BT100A	¥306	¥330	100	118.3	129	30	139	8.3	W3/8	10	171

Stainless Steel Materials

- Stainless Steel (SUS304)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nominal Diameter (A)	Compatible Pipe Outer Diameter (mm)	P (mm)	S (mm)	H (mm)	E (mm)	d (mm)	SPQ (piece)	Weight (g)
285-9521	TPCU-BT15A-S	¥463	¥500	15	25.7	36	25	48	8.3	W3/8	10	75
285-9530	TPCU-BT20A-S	¥482	¥520	20	31.2	43	25	52	8.3	W3/8	10	80
285-9548	TPCU-BT25A-S	¥546	¥590	25	37.6	49	25	60	8.3	W3/8	10	88
285-9556	TPCU-BT32A-S	¥611	¥660	32	46.3	57	30	69	8.3	W3/8	10	98
285-9564	TPCU-BT40A-S	¥630	¥680	40	52.2	63	30	74	8.3	W3/8	10	104
285-9572	TPCU-BT50A-S	¥676	¥730	50	64.1	74	30	88	8.3	W3/8	10	118
285-9581	TPCU-BT65A-S	¥824	¥890	65	79.9	90	30	112	8.3	W3/8	10	142
285-9599	TPCU-BT80A-S	¥833	¥900	80	92.7	103	30	116	8.3	W3/8	10	149
285-9602	TPCU-BT100A-S	¥972	¥1,050	100	118.3	129	30	139	8.3	W3/8	10	175

Contact us:0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items


U Bolt for SGP Pipe



TSGP2-BT15A (unichrome)



TSGP-BT100A-S (stainless steel)

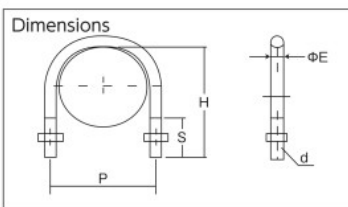

- Features**
- This is a typical product of U-shaped bracket.
- Use**
- SGP tube pipe tightening fixtures.
 - For horizontal piping and vertical piping.
- Accessories**
- 3/8 Nut 2 Pieces
- Origin**
- Japan



Unichrome Materials

- Steel (SWCH)

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nominal Diameter (A)	Compatible Pipe Outer Diameter (mm)	P (mm)	S (mm)	H (mm)	E (mm)	d (mm)	SPQ (piece)	Weight (g)
819-9870	TSGP2-BT15A	¥130	¥140	15	21.70	34	30	43	8.3	W3/8	10	50
819-9871	TSGP2-BT20A	¥148	¥160	20	27.20	40	30	51	8.3	W3/8	10	56
819-9872	TSGP2-BT25A	¥148	¥160	25	34.00	46	30	59	8.3	W3/8	10	64
819-9873	TSGP2-BT32A	¥158	¥170	32	42.70	56	30	68	8.3	W3/8	10	74
819-9874	TSGP2-BT40A	¥166	¥180	40	48.60	62	30	74	8.3	W3/8	10	80
819-9875	TSGP2-BT50A	¥176	¥190	50	60.50	74	30	85	8.3	W3/8	10	92
819-9876	TSGP2-BT65A	¥213	¥230	65	76.30	88	35	107	8.3	W3/8	10	114
819-9877	TSGP2-BT80A	¥231	¥250	80	89.10	101	35	117	8.3	W3/8	10	126
819-9869	TSGP2-BT100A	¥278	¥300	100	114.30	126	35	145	8.3	W3/8	10	155

Stainless Steel Materials

- Stainless Steel (SUS304)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nominal Diameter (A)	Compatible Pipe Outer Diameter (mm)	P (mm)	S (mm)	H (mm)	E (mm)	d (mm)	SPQ (piece)	Weight (g)
285-9700	TSGP-BT15A-S	¥399	¥430	15	21.70	34	25	46	8.3	W3/8	10	73
285-9718	TSGP-BT20A-S	¥407	¥440	20	27.20	40	25	50	8.3	W3/8	10	78
285-9726	TSGP-BT25A-S	¥444	¥480	25	34.00	46	25	54	8.3	W3/8	10	83
285-9734	TSGP-BT32A-S	¥490	¥530	32	42.70	56	30	64	8.3	W3/8	10	94
285-9742	TSGP-BT40A-S	¥546	¥590	40	48.60	62	30	74	8.3	W3/8	10	104
285-9751	TSGP-BT50A-S	¥602	¥650	50	60.50	74	30	85	8.3	W3/8	10	115
285-9769	TSGP-BT65A-S	¥703	¥760	65	76.30	88	30	107	8.3	W3/8	10	138
285-9777	TSGP-BT80A-S	¥759	¥820	80	89.10	101	30	117	8.3	W3/8	10	148
285-9785	TSGP-BT100A-S	¥897	¥970	100	114.30	126	30	145	8.3	W3/8	10	180

Contact us:0120-509-849 <http://www.orange-book.com/>