

Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items**


Perforated Angle for Piping Support (single hole type/50 type/5 pieces set)



- Features • Just by cutting at the site without welding, can install with bolts.
 Specs • Long hole: 13 x 40mm
 • Single hole type
 Origin • Japan



TKL5-S210-S

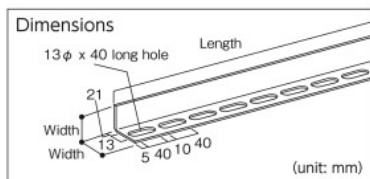

Stainless Steel Materials •Stainless Steel (SUS304)

Order Unit: 1 Set

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	W x L (mm)	Thickness (mm)	Q'ty Per Set (piece)	SPQ (set)	Weight (kg/set)
490-0103	TKL5-S210-S	¥64,800	¥70,000	50 x 2100	4.0	5	1	32
490-0111	TKL5-S240-S	¥74,057	¥80,000	50 x 2400	4.0	5	1	36

Steel Materials •Steel (SPHC)

•Surface Treatment: Unichrome Plated Finishing

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	W x L (mm)	Thickness (mm)	Q'ty Per Set (piece)	SPQ (set)	Weight (kg/set)
490-0120	TKL5-S210-U	¥19,070	¥20,600	50 x 2100	4.5	5	1	35
490-0138	TKL5-S240-U	¥21,106	¥22,800	50 x 2400	4.5	5	1	40

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**


Pipe Support Channel Bracket (75 type)



- Specs • Anchor Hole: 12 x 15mm
 Origin • Japan



TKC7-WB014-S

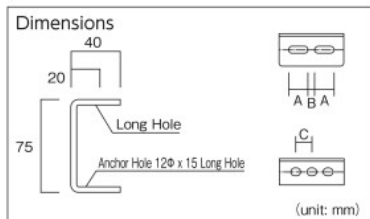

Stainless Steel Materials •Stainless Steel (SUS304)

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Length (mm)	Thickness (mm)	A (mm)	B (mm)	C (mm)	SPQ (piece)	Weight (kg)
287-2986	TKC7-WB010-S	¥1,389	¥1,500	100	4.0	30	10	25	50	0.4
287-2994	TKC7-WB014-S	¥1,851	¥2,000	140	4.0	45	16	35	50	0.6
287-3001	TKC7-WB020-S	¥2,546	¥2,750	200	4.0	45	16	50	30	0.9
287-3010	TKC7-WB027-S	¥3,471	¥3,750	270	4.0	50	10	70	30	1.2

Steel Materials •Steel (SPHC)

•Surface Treatment: Unichrome Plated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Length (mm)	Thickness (mm)	A (mm)	B (mm)	C (mm)	SPQ (piece)	Weight (kg)
287-2943	TKC7-WB010-U	¥407	¥440	100	4.5	30	10	25	50	0.5
287-2951	TKC7-WB014-U	¥509	¥550	140	4.5	45	16	35	50	0.7
287-2960	TKC7-WB020-U	¥723	¥780	200	4.5	45	16	50	30	1.0
287-2978	TKC7-WB027-U	¥972	¥1,050	270	4.5	50	10	70	30	1.3

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**


Pipe Support Channel Bracket (100 type)



- Specs • Anchor Hole: 12 x 15mm
 Origin • Japan



TKC1-WB010-S

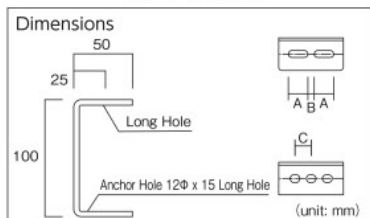

Stainless Steel Materials •Stainless Steel (SUS304)

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Length (mm)	Thickness (mm)	A (mm)	B (mm)	C (mm)	SPQ (piece)	Weight (kg)
287-2901	TKC1-WB010-S	¥1,722	¥1,860	100	4.0	30	10	25	40	0.6
287-2919	TKC1-WB014-S	¥2,314	¥2,500	140	4.0	45	16	35	30	0.8
287-2927	TKC1-WB020-S	¥3,240	¥3,500	200	4.0	45	16	50	20	1.2
287-2935	TKC1-WB027-S	¥4,406	¥4,760	270	4.0	50	10	70	20	1.6

Steel Materials •Steel (SPHC)

•Surface Treatment: Unichrome Plated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Length (mm)	Thickness (mm)	A (mm)	B (mm)	C (mm)	SPQ (piece)	Weight (kg)
287-2862	TKC1-WB010-U	¥509	¥550	100	4.5	30	10	25	40	0.6
287-2871	TKC1-WB014-U	¥648	¥700	140	4.5	45	16	35	30	0.9
287-2889	TKC1-WB020-U	¥852	¥920	200	4.5	45	16	50	20	1.3
287-2897	TKC1-WB027-U	¥1,074	¥1,160	270	4.5	50	10	70	20	1.8

Contact us:0120-509-849 <http://www.orange-book.com/>

Plumbing Products

Valves

Screwed Type Pipe Fittings

High Pressure Joints

Welding Fittings

Flanges

Flexible Metal Hoses

Piping Joints for Minor Diameters

Sanitary Pipe Couplings

PVC Pipes

PVC Pipe Joints

PVC Valves

Joints for Water Piping

Protect Accessories for Plumbing

Support Accessories for Plumbing

Maintenance Accessories for Plumbing

Air Conditioning Materials

Valve-Pipe Identifying Goods

Spray Nozzles