

Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items**


## Gravity Steel Roller Conveyor (VR-3812 model: roller diameter 38.1mm, thickness 1.2mm)

Made to Order **Heavy Caution**



- Features** • A highly versatile roller conveyor that is suitable for conveying light objects.  
**Materials** • Frame: Steel  
 • Roller: Carbon Steel Pipe for Machine Structures  
**Origin** • Japan

Roller Width (W) (mm)	Roller Load Capacity (kg/piece)
300	120
400	90
500	70
600	60

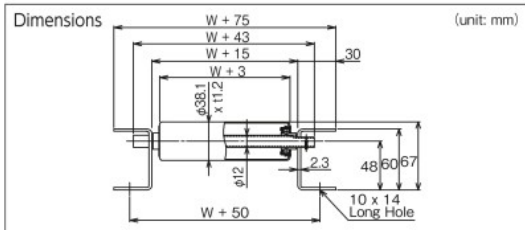

Item No. Example (order code 300-5640)

**VR-3812 - 300 - 50 - 1000**

Model Name    Display Roller Width (mm)    Display Pitch (mm)    Conveyor Length (mm)    Display

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands

TRUSCO NAKAYAMA CORPORATION

Roller Width (W) (mm)	Pitch (mm)	Conveyor Length (mm)							
		1000		1500		2000		3000	
		Order Code	Price (per piece)	Order Code	Price (per piece)	Order Code	Price (per piece)	Order Code	Price (per piece)
300	50	★300-5640	¥16,200	★300-5658	¥23,883	★300-5666	¥31,197	★300-5674	¥46,656
	75	★300-5445	¥12,219	★300-5453	¥18,144	★300-5461	¥23,143	★300-5470	¥34,251
	100	★300-5763	¥10,461	★300-5771	¥15,089	★300-5780	¥19,440	★300-5798	¥28,512
400	50	★300-5682	¥17,866	★300-5691	¥26,383	★300-5704	¥34,344	★300-5712	¥50,914
	75	★300-5488	¥13,238	★300-5496	¥19,718	★300-5500	¥25,087	★300-5518	¥37,491
	100	★300-5801	¥11,294	★300-5810	¥16,478	★300-5828	¥21,014	★300-5836	¥30,919
500	50	★300-5721	¥19,347	★300-5739	¥28,512	★300-5747	¥37,491	★300-5755	¥55,358
	75	★300-5526	¥14,349	★300-5534	¥21,291	★300-5542	¥27,123	★300-5551	¥40,454
	100	★300-5844	¥12,219	★300-5852	¥17,681	★300-5861	¥22,680	★300-5879	¥33,141
600	50	★855-5539	¥24,069	★855-5540	¥35,455	★855-5541	¥47,211	★855-5542	¥69,521
	75	★855-5543	¥17,218	★855-5544	¥26,198	★855-5545	¥33,696	★855-5546	¥51,099
	100	★855-5535	¥14,626	★855-5536	¥21,384	★855-5537	¥28,419	★855-5538	¥41,379


Contact us: 0120-509-849 <http://www.orange-book.com/>

### Straight conveyor

Roller width W (mm)		300	400	500	600
Pitch P (mm)	Side length L (mm)	Product weight (kg)			
50	1000	14.8	17.7	20.6	23.81
	1500	22.2	26.4	30.8	35.71
	2000	29.6	35.2	41.0	47.01
	3000	44.4	52.8	61.7	70.20
75	1000	11.3	13.3	15.2	17.20
	1500	16.9	15.3	22.6	26.27
	2000	22.6	26.6	30.4	33.78
	3000	33.9	39.9	45.6	51.31
100	1000	13.3	11.0	12.6	14.36
	1500	15.3	16.5	18.7	21.54
	2000	26.6	22.0	25.0	28.12
	3000	39.9	33.0	37.5	41.87

TRUSCO **Stock 38,650 Items**

## "Portable Stopper"

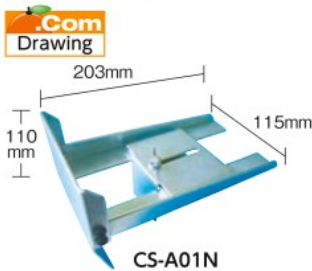

- Features** • Mounting is easy and it can be adjusted with one touch using a butterfly nut.  
 • It has a structure that sandwiches the roller so there is no risk of detaching even for small types.  
**Materials** • Steel  
 • Surface treatment: Trivalent unichrome-plated finishing  
**Origin** • Japan

### Compatible model list

Roller Diameter (mm)	Roller Pitch (mm)				
	30	50	75	100	150
φ 25.4	○	○	○	○	○
φ 31.8	-	○	○	○	○
φ 38.1	-	○	○	○	○
φ 42.7	-	○	○	○	○
φ 45.0	-	○	○	○	○
φ 48.6	-	-	○	○	○
φ 50.0	-	-	○	○	○
φ 57.0	-	-	○	○	○



Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	W x L x H (mm)	SPQ (piece)	Weight (kg)
503-7654	CS-A01N	¥7,313	¥7,900	115 x 203 x 110	1	1

Contact us: 0120-509-849 <http://www.orange-book.com/>