

Fully-Closed Type Factory Fans

Stock 84Items

9-877

Prices displayed include 8% tax.

TRUSCO Stock 38,650 Items

Fully-Closed Type Factory Fan (desktop type)

Repairing OK

Finished Goods



Quality Guaranteed 3 Years

Design Standard Use Period 6 Years

Com Drawing Air Flow 3 Stage

Right and Left Swivel 90°

- Features**
- Adopts fully closed type motor.
 - Carrying handle is convenient for carrying.
 - Built-in thermal protector for motor burning prevention.
 - Space saving/high quality.
- Use**
- To aeration of the factory and work site.
 - Compact type that can be placed on a desk or working table.
- Specs**
- Power Cord: 2m (with grounding)
 - Air Volume Adjustment: 3 Stages (high, medium, low) Type
- Origin**
- Taiwan

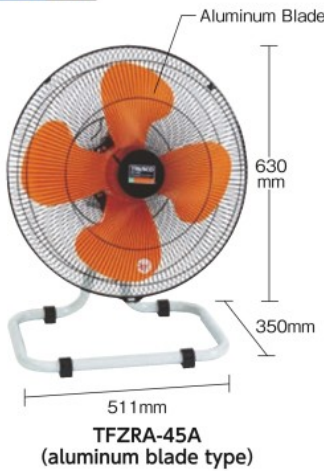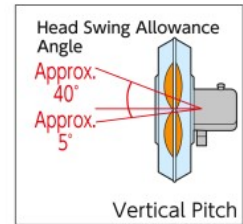

Standard Electric Consumption Rate	Item No.	Replacement Blade
3.1yen/h (50Hz)/4.3yen/h (60Hz)	TFZRA-45A	TFP-45-10A (aluminum)
	TFZR-45A	TF-45-10 (AS resin)

Warning

•"Warranty Period" is 3 years from the date of purchase. We will repair for free of charge within 3 years from the date of purchase in case of failure in normal use situation. "Design Standard Use Period" is the period from the point of manufacture, not the period from purchase. Please also be warning aware that it does not assume the obligation of free repair or free replacement. Guide on the design to the last, it is not the warranty period of the product.

Aluminum Blade Type

- Specs**
- Blade: 4 Sheets (aluminum)

Order Unit: 1 Piece

(Price revision date: Feb, 2015) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Power (V)	Electricity Consumption (W) (50/60Hz)	Blade Diameter (cm)	Weight (kg)
474-8981	TFZRA-45A	¥18,630	¥23,000	Single Phase 100	116/159	44	7.0

Resin Blade Type

- Specs**
- Blades: 4 Sheets (AS resin)

Order Unit: 1 Piece

(Price revision date: Feb, 2015)


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Power (V)	Electricity Consumption (W) (50/60Hz)	Blade Diameter (cm)	Weight (kg)
453-8820	TFZR-45A	¥18,630	¥23,000	Single Phase 100	116/159	45	7.0

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Parts for Fully-Closed Type Factory Fan

Origin •Taiwan

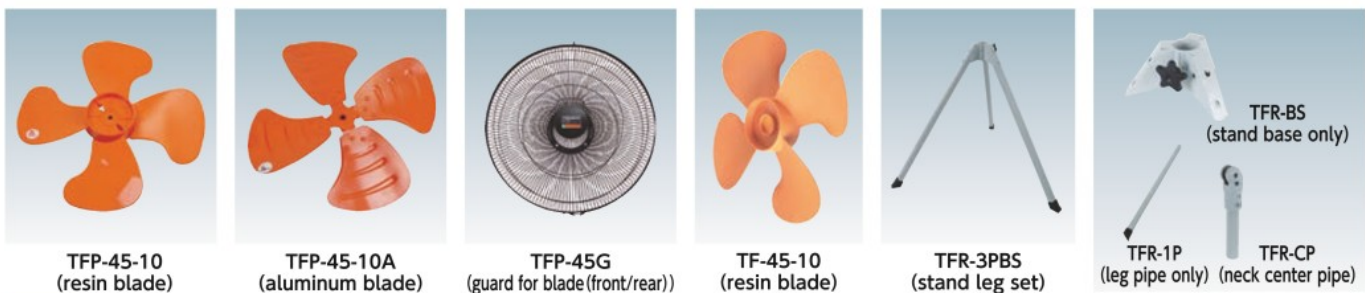

- Blade** Materials
- AS resin (TFP-45-10, TF-45-10)
 - Aluminum (TFP-45-10A)
 - Soft steel wire (TFP-45G)

Order Unit: 1 Piece

(Price revision date: Feb, 2015) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Item Name	Diameter (mm)	Hole Diameter (mm)	Compatible Model	SPQ (piece)	Weight (kg)
424-9976	TFP-45-10	¥3,451	¥4,260	Resin blade	450	10	TFZP series	1	0.75
424-9984	TFP-45-10A	¥4,487	¥5,540	Aluminum blade	440	10	TFZP series, TFZR series, TFZ series (main unit discontinued)	1	0.45
424-9992	TFP-45G	¥4,747	¥5,860	Guard for blades(front/rear)	510	-	TFZP series, TFZR series	1	1.50
233-3180	TF-45-10	¥3,103	¥3,830	Resin blade	450	10	TFZR series, TFZ series (main unit discontinued)	1	0.55

- Stand leg** Materials
- Steel

Warning

•Only the stand leg set (TFR-3PBS) is compatible with the TFZ series (main unit discontinued).

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Item Name	Compatible Model	SPQ (piece)	Weight (kg)
762-4891	TFR-3PBS	¥5,022	¥6,200	Stand leg set	TFZR series, TFZ series (main unit discontinued)	1	1.6
762-4905	TFR-BS	¥3,240	¥4,000	Stand base only	TFZR series	50	0.4
762-4883	TFR-1P	¥1,013	¥1,250	Leg pipe only (1 pipe)	TFZR series	30	0.4
762-4913	TFR-CP	¥1,256	¥1,550	Neck center pipe	TFZR series	50	0.3

Contact us:0120-509-849 <http://www.orange-book.com/>

Air Conditioners • Heaters

Spot Air Conditioners

Cool Air Blowers

Fans for Factories

Circulators

Air Conditioners

Mist Fans

Spraying Systems

Ice Dispensers

Water Coolers

Oil Stoves

Oil Tanks

Gas Stoves

Oil Heaters

Far Infrared Radiation Electricity Heaters

Electric Fan Heaters

Foot Heaters

Humidifiers

Dryers • Dehumidifiers

Air Cleaners

Ion Generators

Smoke Separating Machines

Deodorizers