

Prices displayed include 8% tax.

For Meeting Chairs, see p. 10-76 to 86

TRUSCO Stock 38,650 Items

## Folding Type Conference Table "Blow Table"

Finished Goods

Com Green Purchasing Chemical Content Inspection Com Drawing



TPET-1850N (with no lower shelf)



TPET-1850 (with lower shelf)

- Features**
- Lightweight and compact folding type table excellent in water resistance.
  - 55mm-thick. (Legs are stored inside the top board.)
  - An anti-dislocation feature is adopted for stacking. (25 units can be stacked.)
  - Excellent in water resistance.
- Materials**
- Top board: 55mm-thick, integrally-molded polyethylene resin (all resin)
- Origin**
- Leg: Steel, 26 mm square (powder coating)
  - China



Legs can be folded completely in the back of the top so they won't cause any obstruction when they are stacked.

Lightweight and compact design with 55mm-thick top board Anti-dislocation feature

Type with no lower shelf Specs • Lower Shelves None (Price revision date: Jan, 2015)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Top Board Color	W x D x H (mm)	Weight (kg)
★274-0427	TPET-1850N	¥20,736	¥22,400	New gray	1800 x 500 x 700	12.9

Type with lower shelf Specs • With Lower Shelves

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Top Board Color	W x D x H (mm)	Weight (kg)
★274-0419	TPET-1850	¥22,402	¥24,200	New gray	1800 x 500 x 700	15

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

## Folding Conference Table


Finished Goods

Com Drawing



TCT-1845:T (teak)

Top Board Color

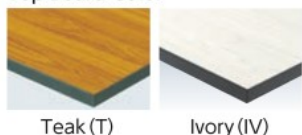

Teak (T)

Ivory (IV)

- Features**
- Hard PVC covered edge.
  - Being foldable can be stored saving space.
- Specs**
- With Lower Shelves
- Materials**
- Top board: 28mm-thick low pressure decorative melamine laminate/frame core flash/hard PVC covered edge
  - Leg: Steel, 26 mm square (powder coating) / equipped with adjuster
- Origin**
- China

Order Unit: 1 Piece (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Options (Color)	Price (per piece)	MSRP (per piece)	Top Board Color	W x D x H (mm)	Weight (kg)
276-9212	TCT-1845	T	¥14,914	¥16,110	Teak	1800 x 450 x 700	14.0
276-9221	TCT-1845	IV	¥14,914	¥16,110	Ivory	1800 x 450 x 700	14.0
276-9239	TCT-1860	T	¥16,283	¥17,590	Teak	1800 x 600 x 700	17.5
276-9247	TCT-1860	IV	¥16,283	¥17,590	Ivory	1800 x 600 x 700	17.5

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

## Folding Conference Table

Finished Goods

Com Green Purchasing Com Drawing




TS-1845:IV (ivory)

\*Please specify the color from ivory, rose and teak when ordering.

- Features**
- With softly rounded edge corners are also smoothed off.
  - Being foldable can be stored saving space.
- Specs**
- With Lower Shelves
- Materials**
- Top board: 28mm-thick decorative melamine laminate/frame core flash/rounded off edge
  - Leg: Steel 26mm Square (baking finishing) with adjuster
- Origin**
- Japan

Top Board Color

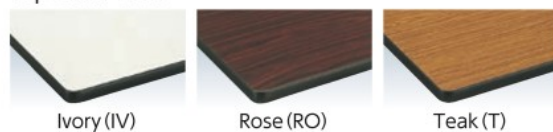

Ivory (IV)

Rose (RO)

Teak (T)

(Price revision date: Jan, 2016)

Item No. Example

Item No.	Example
TS-1545	: IV
Width	Depth
15: 1500	45: 450
18: 1800	60: 600
	Color
	IV: Ivory
	RO: Rose
	T: Teak

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands | TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Options (Color)	Price (per piece)	MSRP (per piece)	Top Board Color	W x D x H (mm)	Weight (kg)
★464-6576	TS-1545	IV	¥21,542	¥23,270	Ivory	1500 x 450 x 700	12.5
★464-6584	TS-1560	IV	¥25,948	¥28,030	Ivory	1500 x 600 x 700	16.0
★464-6592	TS-1845	IV	¥21,542	¥23,270	Ivory	1800 x 450 x 700	14.0
★464-6606	TS-1860	IV	¥25,948	¥28,030	Ivory	1800 x 600 x 700	17.5

Contact us: 0120-509-849 <http://www.orange-book.com/>