

Meeting Tables

For Meeting Chairs, see p. 10-76 to 86

The number next to the logo mark indicates items in stock for each brand.

Desks

PC Desks

Meeting Tables

Cafeteria Tables

Office Chairs

Meeting Chairs

Working Chairs

Anti-Static Stools

Benches

Umbrella Stands

Reception Room Furnitures

Hanger Racks

Partitions

Book Cabinets

Counters

Filing Cabinets

Catalog Cases

Map Cases

Letter Cases

Pamphlet Stands

File Wagons

Lockers

Shoes Boxes

Safes

Mailboxes

Key Boxes

Window Films

Interior Blinds

OA Floors

System Kitchens

Conference Table



 
*Please specify the color from white, new gray, rose and teak when ordering.

| Item No. | Example |
|--------------------------|--------------|
| TDS - 0990 T : RO | |
| Width | Depth |
| 09: 900 | 45: 450 |
| 12: 1200 | 60: 600 |
| 15: 1500 | 75: 750 |
| 18: 1800 | 90: 900 |
| Type | Color |
| T: With lower shelf | W: White |
| | NG: New gray |
| | RO: Rose |
| | T: Teak |



- Features** • Legs are non-retractable type with excellent stability, so ideal for fixed installation.
- Specs** • With Lower Shelves
- Materials** • Top board: 28mm-thick decorative melamine laminate/flash structure/elastomer edge
• Leg: Φ 31.8mm steel pipe (chrome plating) with adjuster
• Shelf: Φ 15.9mm steel pipe (baked coating)
- Origin** • Japan

Require 2Persons
20minutes



(Price revision date: Jan, 2016)

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands | TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Options (Color) | Price (per piece) | MSRP (per piece) | Top Board Color | W x D x H (mm) | Weight (kg) |
|------------|-----------|-----------------|-------------------|------------------|-----------------|------------------|-------------|
| ★464-6380 | TDS-0990T | RO | ¥38,038 | ¥41,090 | Rose | 900 x 900 x 700 | 19.6 |
| ★464-6401 | TDS-1260T | RO | ¥42,342 | ¥45,740 | Rose | 1200 x 600 x 700 | 17.2 |
| ★464-6428 | TDS-1275T | RO | ¥43,509 | ¥47,000 | Rose | 1200 x 750 x 700 | 19.8 |
| ★464-6444 | TDS-1560T | RO | ¥43,305 | ¥46,780 | Rose | 1500 x 600 x 700 | 19.8 |
| ★464-6461 | TDS-1575T | RO | ¥48,849 | ¥52,770 | Rose | 1500 x 750 x 700 | 24.2 |
| ★464-6487 | TDS-1590T | RO | ¥50,850 | ¥54,930 | Rose | 1500 x 900 x 700 | 27.4 |
| ★464-6509 | TDS-1845T | RO | ¥42,546 | ¥45,960 | Rose | 1800 x 450 x 700 | 18.4 |
| ★464-6525 | TDS-1860T | RO | ¥44,712 | ¥48,300 | Rose | 1800 x 600 x 700 | 22.2 |
| ★464-6541 | TDS-1875T | RO | ¥50,850 | ¥54,930 | Rose | 1800 x 750 x 700 | 27.2 |
| ★464-6568 | TDS-1890T | RO | ¥56,422 | ¥60,950 | Rose | 1800 x 900 x 700 | 31.2 |

Contact us: 0120-509-849 <http://www.orange-book.com/>

Conference Table




*Please specify the color from white, new gray, rose and teak when ordering.

| Item No. | Example |
|------------------------|---------|
| TDS - 0990 : NG | |
| Width | Depth |
| 09: 900 | 45: 450 |
| 12: 1200 | 60: 600 |
| 15: 1500 | 75: 750 |
| 18: 1800 | 90: 900 |
| Color | |
| W: White | |
| NG: New gray | |
| RO: Rose | |
| T: Teak | |



- Features** • Legs are non-retractable type with excellent stability, so ideal for fixed installation.
- Specs** • Lower Shelves None
- Materials** • Top board: 28mm-thick decorative melamine laminate/flash structure/elastomer edge
• Leg: Steel 31mm square (chrome plating) with adjuster
- Origin** • Japan

 Require 2Persons
20minutes




(Price revision date: Jan, 2016)

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands | TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Options (Color) | Price (per piece) | MSRP (per piece) | Top Board Color | W x D x H (mm) | Weight (kg) |
|------------|----------|-----------------|-------------------|------------------|-----------------|------------------|-------------|
| ★464-6371 | TDS-0990 | NG | ¥33,733 | ¥36,440 | New gray | 900 x 900 x 700 | 17.2 |
| ★464-6398 | TDS-1260 | NG | ¥37,639 | ¥40,660 | New gray | 1200 x 600 x 700 | 15.0 |
| ★464-6410 | TDS-1275 | NG | ¥38,805 | ¥41,920 | New gray | 1200 x 750 x 700 | 17.4 |
| ★464-6436 | TDS-1560 | NG | ¥38,398 | ¥41,480 | New gray | 1500 x 600 x 700 | 17.2 |
| ★464-6452 | TDS-1575 | NG | ¥44,712 | ¥48,300 | New gray | 1500 x 750 x 700 | 21.2 |
| ★464-6479 | TDS-1590 | NG | ¥46,147 | ¥49,850 | New gray | 1500 x 900 x 700 | 23.6 |
| ★464-6495 | TDS-1845 | NG | ¥37,140 | ¥40,120 | New gray | 1800 x 450 x 700 | 15.8 |
| ★464-6517 | TDS-1860 | NG | ¥39,603 | ¥42,780 | New gray | 1800 x 600 x 700 | 19.2 |
| ★464-6533 | TDS-1875 | NG | ¥47,379 | ¥51,180 | New gray | 1800 x 750 x 700 | 23.6 |
| ★464-6550 | TDS-1890 | NG | ¥49,813 | ¥53,810 | New gray | 1800 x 900 x 700 | 26.8 |


Contact us: 0120-509-849 <http://www.orange-book.com/>

Conference Table

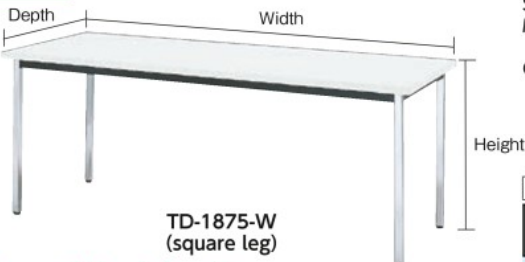

*Please specify the color from white, new gray, rose and teak when ordering.

| Item No. | Example |
|----------------------|---------|
| TD - 0990 - W | |
| Width | Depth |
| 09: 900 | 45: 450 |
| 12: 1200 | 60: 600 |
| 15: 1500 | 75: 750 |
| 18: 1800 | 90: 900 |
| Color | |
| W: White | |
| NG: New gray | |
| RO: Rose | |
| T: Teak | |

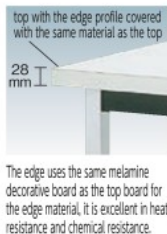

- Features** • Legs are non-retractable type with excellent stability, so ideal for fixed installation.
- Specs** • Lower Shelves None
- Materials** • Top Board: 28mm Decorative Melamine Laminate/Flash Structure/Co-winding
• Leg: Steel 31mm square (chrome plating) with adjuster
- Origin** • Japan

Require 2Persons
20minutes



(Price revision date: Jan, 2016)

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands | TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Top Board Color | W x D x H (mm) | Weight (kg) |
|------------|-----------|-------------------|------------------|-----------------|------------------|-------------|
| ★464-6274 | TD-0990-W | ¥31,937 | ¥34,500 | White | 900 x 900 x 700 | 17.2 |
| ★464-6282 | TD-1260-W | ¥32,335 | ¥34,930 | White | 1200 x 600 x 700 | 15.0 |
| ★464-6291 | TD-1275-W | ¥36,001 | ¥38,890 | White | 1200 x 750 x 700 | 17.4 |
| ★464-6304 | TD-1560-W | ¥33,094 | ¥35,750 | White | 1500 x 600 x 700 | 17.2 |
| ★464-6312 | TD-1575-W | ¥41,009 | ¥44,300 | White | 1500 x 750 x 700 | 21.2 |
| ★464-6321 | TD-1590-W | ¥43,444 | ¥46,930 | White | 1500 x 900 x 700 | 23.6 |
| ★464-6339 | TD-1845-W | ¥35,334 | ¥38,170 | White | 1800 x 450 x 700 | 15.8 |
| ★464-6347 | TD-1860-W | ¥35,103 | ¥37,920 | White | 1800 x 600 x 700 | 19.2 |
| ★464-6355 | TD-1875-W | ¥42,175 | ¥45,560 | White | 1800 x 750 x 700 | 23.6 |
| ★464-6363 | TD-1890-W | ¥45,508 | ¥49,160 | White | 1800 x 900 x 700 | 26.8 |

Contact us: 0120-509-849 <http://www.orange-book.com/>