

Working Chairs

Office Furniture

Desks

PC Desks

Meeting Tables

Cafeteria Tables

Office Chairs

Meeting Chairs

Working Chairs

Anti-Static Stools

Benches

Umbrella Stands

Reception Room Furnitures

Hanger Racks

Partitions

Book Cabinets

Counters

Filing Cabinets

Catalog Cases

Map Cases/Letter Cases

Pamphlet Stands

File Wagons

Lockers

Shoes Boxes

Safes

Mailboxes

Key Boxes

Window Films

Interior Blinds


OA Floors

System Kitchens

The number next to the logo mark indicates items in stock for each brand.

Chitose **Stock 49 Items** **Finished Goods**

アイリスチトセ



Features • Structure that is hard to fall down even when you step on the ring by mistake.

Materials • Seat: Blow molded item
• Leg: Φ 22.2mm steel pipe, powder coating


Origin • China

300mm
420mm
425mm

CRS-42PS-BL (blue)

Chitose **Stock 49 Items** **Finished Goods**

アイリスチトセ



Features • Structure that is hard to fall down even when you step on the ring by mistake.

Materials • Seat: Blow molded item
• Leg: Φ 22.2mm steel pipe, powder coating

Origin • China

300mm
460mm
425mm

CRS-46PS-BL (blue)

Coated Cloth Color

BL (blue) GR (green) OR (orange)

SPQ: 1 Piece

(Price revision date: Jun, 2016)

Coated Cloth Color

BL (blue) GR (green) OR (orange)

SPQ: 1 Piece

(Price revision date: Jun, 2016)

Order Unit: 1 Piece | Factory direct | Shipping not included | IRIS CHITOSE Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coated Cloth	Color	Seat Width x Seat Height (mm)	Weight (kg)
★772-3652	CRS-42PS-BL	¥6,124	¥6,300	PP resin	Blue	300 x 420	2.7
★772-3661	CRS-42PS-GR	¥6,124	¥6,300	PP resin	Green	300 x 420	2.7
★772-3679	CRS-42PS-OG	¥6,124	¥6,300	PP resin	Orange	300 x 420	2.7

Order Unit: 1 Piece | Factory direct | Shipping not included | IRIS CHITOSE Co.Ltd.


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coated Cloth	Color	Seat Width x Seat Height (mm)	Weight (kg)
★772-3687	CRS-46PS-BL	¥6,124	¥6,300	PP resin	Blue	300 x 460	2.9
★772-3695	CRS-46PS-GR	¥6,124	¥6,300	PP resin	Green	300 x 460	2.9
★772-3709	CRS-46PS-OR	¥6,124	¥6,300	PP resin	Orange	300 x 460	2.9

Contact us:079-568-4671 <http://www.irischitose.co.jp/>

Contact us:079-568-4671 <http://www.irischitose.co.jp/>

AICO **Stock 2 Items** **Finished Goods**

アイコ



Features • Stool stacking is also possible with a simple round chair.

Materials • Seat: Steel, hard board, urethane foam
• Leg: Φ 22.2mm steel pipe (powder coating)

Origin • Japan

360mm
445mm
525mm

RC-60 V3-BU (blue)


Coated Cloth Color

BU (blue) BK (black)

SPQ: 10 Pieces

TRUSCO **Stock 38,650 Items** **Finished Goods**

TRUSCO

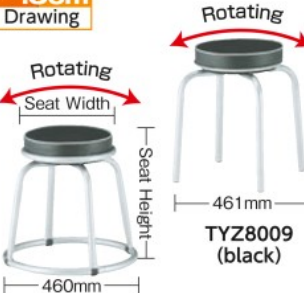

Features • Comfortable when doing light work since the seat rotates.

• Since the urethane is thick, makes it capable of relieving fatigue.

Specs • Stackable

Materials • Seat: Plywood/Urethane Foam
• Leg: Φ 25.4mm steel pipe (powder coating)

Origin • China

Rotating
Rotating
Seat Width
Seat Height
461mm
460mm

TY28009 (black)
TY2255-45H (black)

Order Unit: 1 Piece | (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece | (Price revision date: Jan, 2016) AICO Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coated Cloth	Color	Seat Width x Seat Height (mm)	Weight (kg)
320-1759	RC-60 V3-BU	¥6,920	¥6,900	Vinyl Leather Upholstery	Blue	360 x 445	2.8
320-1741	RC-60 V3-BK	¥6,920	¥6,900	Vinyl Leather Upholstery	Black	360 x 445	2.8

Order Unit: 1 Piece | (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coated Cloth	Seat Width x Seat Height (mm)	SPQ (piece)	Weight (kg)
276-9344	TY2255-24H	¥5,962	¥6,440	Vinyl Leather Upholstery	300 x 240	4	3.1
276-9352	TY2255-33H	¥6,119	¥6,610	Vinyl Leather Upholstery	300 x 330	4	3.3
276-9361	TY2255-45H	¥6,267	¥6,770	Vinyl Leather Upholstery	300 x 450	4	3.5
276-9336	TY28009	¥5,277	¥5,700	Vinyl Leather Upholstery	300 x 450	6	2.4

Contact us:052-871-4141 <http://www.aico-net.co.jp/>

Contact us:0120-509-849 <http://www.orange-book.com/>

NORITSUISU **Stock 18 Items** **Knock down**

ノリツスイ



Features • The built-in bearing enables smooth seat rotation when you are seated.

Materials • Seat: SPCC, hard fiberboard
• Leg: STKM-11A, polyethylene (PE), Φ 19.1 steel pipe (chrome plating)

Origin • Japan

340mm
465mm
425mm

T-691C DGL (dark gray)

TRUSCO **Stock 38,650 Items** **Finished Goods**

TRUSCO




Features • Work chair with rotate seat suitable for various working environment.

Specs • Adjustable Seat Function: Screw Type

Materials • Seat: Urethane
• Leg: Steel

Origin • Japan

Seat Width
Seat Height
430mm
545mm

L-60 (gray)
NF-25 V (black)

Coated Cloth Color

C DGL (dark gray) C (red)

Require 1 Persons
15 minutes

SPQ: 5 Pieces

SPQ: 1 Piece

Order Unit: 1 Piece | NORITSUISU

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coated Cloth	Color	Seat Width x Seat Height (mm)	Weight (kg)
334-2808	T-691C DGL	¥7,683	¥8,300	Vinyl Sheet Tension	Dark Gray	340 x 465	3.8
503-6496	T-691C	¥7,683	¥8,300	Vinyl Sheet Tension	Red	340 x 465	3.8

Order Unit: 1 Piece | (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coated Cloth	Color	Seat Width x Seat Height (mm)	Weight (kg)
503-5988	L-60	¥7,294	¥7,880	Vinyl Leather Upholstery	Gray	315 x 410 to 530	3.0
503-6062	NF-25V	¥11,858	¥12,810	Vinyl Leather Upholstery	Black	315 x 500 to 640	4.3

Contact us:0567-52-0511 <http://www.noritsuisu.co.jp/>

Contact us:0120-509-849 <http://www.orange-book.com/>