

The number next to the logo mark indicates items in stock for each brand.

Desks

PC Desks

Meeting Tables

Cafeteria Tables

Office Chairs

Meeting Chairs

Working Chairs

Anti-Static Stools

Benches

Umbrella Stands

Reception Room Furnitures

Hanger Racks

Partitions

Book Cabinets

Counters

Filing Cabinets

Catalog Cases

Map Cases/Letter Cases

Pamphlet Stands

File Wagons

Lockers

Shoes Boxes

Safes

Mailboxes

Key Boxes

Window Films

Interior Blinds

OA Floors

System Kitchens

**TRUSCO** **Stock 38,650 Items** **Steel Sliding Door Bookshelf (A4 type)** **Finished Goods** **Heavy Caution**

**Green Purchasing** **Chemical Content Inspection** **Com Drawing**

**Warning**  
•When using as a bottom placing type, please use the bases (FB40-G06, FB40-G06W).

Specs •Color: Neon Gray •Compatible Type Fall Prevention Metal Fittings: TK/NTK Type  
Materials •Steel Origin •Japan  
Width



Order Unit: 1 Piece | Factory direct | Freight: ¥2,000 | Excluding remote islands | **TRUSCO NAKAYAMA CORPORATION**

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	Equal Load Capacity (kg/stage)	W x D x H (mm)	Installation Type	Accessories	Shelf Board Pitch (mm)	Additional Shelf Board	Weight (kg)
★520-6651	FS40-G7W	¥51,192	¥55,300	200	60	1760 x 400 x 750	For both top/bottom placing	Cylinder lock, 2 shelf boards	30	N-33	43
★520-6693	FS40-G11	¥37,862	¥40,900	180	60	880 x 400 x 1110	For both top/bottom placing	Cylinder lock, 2 shelf boards	30	N-33	29
★520-6715	FS40-G11W	¥64,152	¥69,300	200	60	1760 x 400 x 1110	For both top/bottom placing	Cylinder lock, 4 shelf boards	30	N-33	59

Contact us:0120-509-849 <http://www.orange-book.com/>

**TRUSCO** **Stock 38,650 Items** **Lateral Cabinet** **Finished Goods** **Heavy Caution**

**Green Purchasing** **Chemical Content Inspection** **Com Drawing**



Features •With an all-lock key, all drawers can be locked with one key.  
Specs •Color: Neon Gray •Compatible Type Fall Prevention Metal Fittings: TK/NTK Type  
Materials •Steel  
Accessories •All-lock key •Partition panel  
Origin •Japan



When sliding drawer

Order Unit: 1 Piece | Factory direct | Freight: ¥2,000 | Excluding remote islands | **TRUSCO NAKAYAMA CORPORATION**

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	Equal Load Capacity (kg/stage)	W x D x H (mm)	Installation Type	Drawers Effective Internal Dimension (mm) W x D x H	Weight (kg)
★520-6723	FA40-G11	¥91,553	¥98,900	200	60	880 x 400 x 1110	Designated for bottom placing	800 x 324 x 292	62

Contact us:0120-509-849 <http://www.orange-book.com/>

**TRUSCO** **Stock 38,650 Items** **Bookshelf Base**

**Green Purchasing** **Chemical Content Inspection** **Com Drawing**

Specs •Color: Neon Gray •Compatible Type Fall Prevention Metal Fittings: TK/NTK Type  
Materials •Steel Origin •Japan



Base item No.	Compatible Body
FB40-G06	N303D, N303G, NP303, FO40-G7, FO40-G11, FH40-G7, FH40-G11, FJG40-G7, FJG40-G11, FS40-G7, FS40-G11, FR40-G326AP, FR40-G313AP
FB40-G06W	N306D, N306G, FS40-G7W, FS40-G7W, FJG40-G7W, FJG40-G7W

**TRUSCO NAKAYAMA CORPORATION**





Order Unit: 1 Piece | Factory direct | Freight: ¥1,500 | Excluding remote islands

Order Code	Item No.	Price (per piece)	MSRP (per piece)	W x D x H (mm)	Applicable Bookshelf Dimension (mm) W x D	Weight (kg)
★520-6774	FB40-G06	¥6,110	¥6,600	880 x 380 x 60	880 x 400	3
★520-6782	FB40-G06W	¥9,072	¥9,800	1760 x 380 x 60	1760 x 400	5

Contact us:0120-509-849 <http://www.orange-book.com/>

**TRUSCO** **Stock 38,650 Items** **Fall Prevention Metal Fitting (holding plate/floor fixing plate/connection plate)**

**Green Purchasing** **Chemical Content Inspection** **Com Drawing**

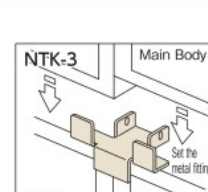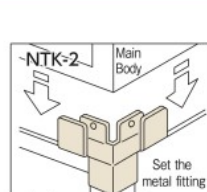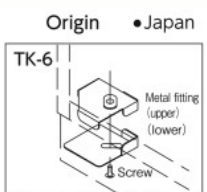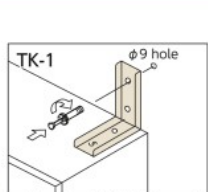

•Set content: Metal fittings x 2, screw anchor x 4  
•Set content: Metal fittings x 4, bolt x 4  
•Set content: Metal fittings x 4  
•Set content: Metal fittings x 2

Order Unit: 1 Set | Factory direct | Freight: ¥1,500 | Excluding remote islands | **TRUSCO NAKAYAMA CORPORATION**

Order Code	Item No.	Price (per set)	MSRP (per set)	Item Name	Weight (g)
★518-0074	TK-1	¥2,962	¥3,200	Top part holding plate	400
★518-0104	TK-6	¥2,222	¥2,400	Main body/base connection plate	300
★520-6456	NTK-2	¥5,184	¥5,600	Connection plate for intermediate 1 connection	200
★258-5421	NTK-3	¥3,703	¥4,000	Connection plate for intermediate 2 connection	300

Contact us:0120-509-849 <http://www.orange-book.com/>