

Standard Bookshelves (depth 515mm type)

10-163

Office Furniture

Prices displayed include 8% tax.

For Shelf Boards and Fall Prevention Metal Fittings, see p. 10-164 to 165

TRUSCO **Stock 38,650 Items**

Glass Sliding Door Bookshelf (A3 type)

Finished Goods **Heavy Caution**

eco Green Purchasing Chemical Content Inspection **.Com Drawing**

- Specs**
- Color: Neon Gray
 - Compatible Type Fall Prevention Metal Fittings: TK/NTK Type
- Materials**
- Main Body: Steel
 - Door: Glass, steel
- Origin**
- Japan

Warning

- When using as a bottom placing type, please use the following bases (FB52-G06, FB52-G06W).



FJG52-G7



FJG52-G7W



FJG52-G11



FJG52-G11W

Order Unit: 1 Piece | Factory direct | Freight: ¥2,000 | Excluding remote islands

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	Equal Load Capacity (kg/stage)	W x D x H (mm)	Installation Type	Accessories	Shelf Board Pitch (mm)	Additional Shelf Board	Weight (kg)
★520-6871	FJG52-G7	¥43,046	¥46,500	120	60	880 x 515 x 750	For both top/bottom placing	Cylinder lock, 1 shelf board	30	N-33W	25
★520-6880	FJG52-G7W	¥64,615	¥69,800	200	60	1760 x 515 x 750	For both top/bottom placing	Cylinder lock, 2 shelf boards	30	N-33W	51
★520-6910	FJG52-G11	¥51,285	¥55,400	180	60	880 x 515 x 1110	For both top/bottom placing	Cylinder lock, 2 shelf boards	30	N-33W	34
★520-6928	FJG52-G11W	¥87,110	¥94,100	200	60	1760 x 515 x 1110	For both top/bottom placing	Cylinder lock, 4 shelf boards	30	N-33W	70

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Bookshelf (A3 type)

Finished Goods **Heavy Caution**

eco Green Purchasing Chemical Content Inspection **.Com Drawing**



FO52-G19 (open bookshelf)



FH52-G19 (double door bookshelf)

- Specs**
- Color: Neon Gray
 - Compatible Type Fall Prevention Metal Fittings: TK/NTK Type
- Materials**
- Steel
- Origin**
- Japan

Order Unit: 1 Piece | Factory direct | Freight: ¥2,000 | Excluding remote islands

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	Equal Load Capacity (kg/stage)	W x D x H (mm)	Installation Type	Accessories	Shelf Board Pitch (mm)	Additional Shelf Board	Weight (kg)
★520-6944	FO52-G19	¥55,358	¥59,800	200	60	880 x 515 x 1860	Designated for bottom placing	Shelf board x 4	30	N-33W	40
★520-6936	FH52-G19	¥64,152	¥69,300	200	60	880 x 515 x 1860	Designated for bottom placing	Cylinder Lock, Shelf Board x 4	30	N-33W	53


Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Base

Finished Goods

eco Green Purchasing Chemical Content Inspection **.Com Drawing**

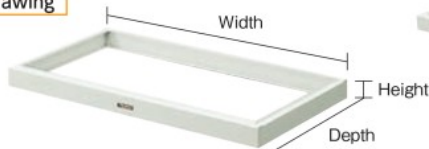

FB52-G06



FB52-G06W

- Specs**
- Color: Neon Gray
- Origin**
- Japan

Warning

- When using as a wall surface unit, please use a base.

Order Unit: 1 Piece | Factory direct | Freight: ¥1,500 | Excluding remote islands

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	W x D x H (mm)	Applicable Bookshelf Dimension (mm) W x D	Weight (kg)
★520-6812	FB52-G06	¥6,943	¥7,500	880 x 495 x 60	880 x 515	3.5
★520-6821	FB52-G06W	¥10,090	¥10,900	1760 x 495 x 60	1760 x 515	5.0

Contact us: 0120-509-849 <http://www.orange-book.com/>

- Desks
- PC Desks
- Meeting Tables
- Cafeteria Tables
- Office Chairs
- Meeting Chairs
- Working Chairs
- Anti-Static Stools
- Benches
- Umbrella Stands
- Reception Room Furnitures
- Hanger Racks
- Partitions
- Book Cabinets
- Counters
- Filing Cabinets
- Catalog Cases
- Map Cases·Letter Cases
- Pamphlet Stands
- File Wagons
- Lockers
- Shoes Boxes
- Safes
- Mailboxes
- Key Boxes
- Window Films
- Interior Blinds
- OA Floors
- System Kitchens