


# Cuffs for TOTAKU SD

material : soft-PVC

Item No.92109-

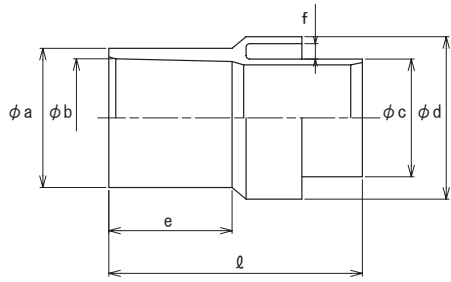

(mm)


Nominal diameter	a	b	c	d	e	f	ℓ
25	30.0	25.0	25.0	36.5	27	3.8	55
32	37.5	32.0	31.7	45.0	35	4.2	72
38	44.0	38.0	38.0	55.5	39	6.3	84
50	59.8	50.8	50.6	69.8	53	6.6	109
65	73.5	63.5	63.0	83.5	70	7.3	144
75	88.2	76.2	76.3	100.5	81	8.8	168
100	114.6	101.6	101.5	132.5	105	11.8	215

# DUCT Cuffs

material : soft-PVC, EPDM (only Ø175)

Item No.92104-  Gray

Item No.92214-  Ivory

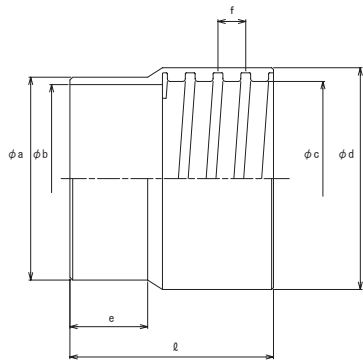

(mm)

Nominal diameter	Applicable product No.	a	b	c	d	e	f	ℓ
32	①	36.0	32.0	33.8	42.0	35	7.5	70
38	①	43.0	38.0	40.0	48.0	35	7.9	80
50	①	56.3	50.8	54.0	65.5	35	10.5	82
65	①	69.0	63.0	66.0	78.5	33	11.5	86
75	①	83.2	76.2	79.5	92.5	37	12.3	94
90	①	96.9	89.2	92.5	106.5	40	12.8	99
100A	③	108.6	101.6	104.0	120.3	42	12.0	100
100B	②	109.6	101.6	105.0	119.8	42	15.0	110
125A	③	134.0	128.0	129.0	143.5	49	12.4	120
125B	②	135.0	128.0	131.0	146.3	50	21.0	142
150A	③	160.0	152.0	150.5	171.0	65	13.5	160
150B	②	160.0	152.0	156.5	173.3	70	20.0	160
175A	③	185.8	177.8	180.3	198.7	70	13.7	180
175B	④	185.8	177.8	181.0	198.7	70	20.0	180
200A	③	215.0	204.0	208.0	224.5	110	14.3	233
200B	②	215.0	204.0	208.0	224.5	110	22.5	233

Note.①...TOTAKU DUCT-D, TOTAKU DUCT-EE, TOTAKU CLEAR DUCT, TOTAKU DUCT-FR

②...TOTAKU DUCT-EE, TOTAKU CLEAR DUCT, TOTAKU DUCT-FR

③...TOTAKU DUCT-D

④...TOTAKU DUCT-EE

Both Gray and Ivory colors are available for Applicable Hose Group ①, ② and ④.


In particular, Ivory colored cuffs are recommended for TOTAKU DUCT FR of which color tone is also Ivory.

Only gray colored cuffs are available for Applicable Hose Group ③.

# Non-PVC DUCT Cuffs

material : Elastmer (olefin) (Color tone : Natural)

Item No.92315-

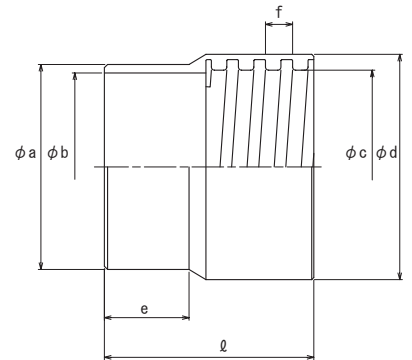


(mm)

Nominal diameter	a	b	c	d	e	f	ℓ
32	36.3	32.0	33.8	42.0	35	7.5	70
38	43.0	38.0	40.0	48.0	35	7.9	80
50	56.3	50.8	54.0	65.5	35	10.5	82
65	69.0	63.0	66.0	78.5	33	11.0	86
75	83.2	76.2	79.5	92.5	37	12.3	94
90	96.9	89.2	92.5	106.5	40	12.8	99
100B	108.6	101.6	105.0	119.0	42	15.0	110
125B	135.0	128.0	131.0	146.3	50	21.0	142
150B	160.0	152.0	156.0	173.3	70	20.0	159
200B	214.0	204.0	208.0	224.5	110	22.5	233

# Cuffs for TOTAKU HERAN DUCT

material : EPDM (Black)

Item No.92103-

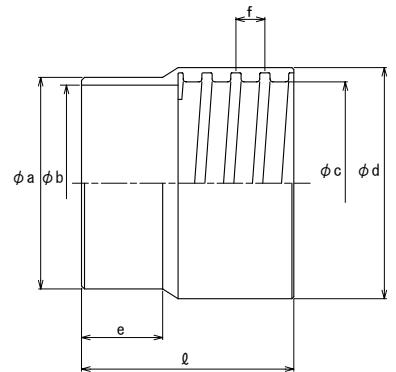

(mm)

Nominal diameter	a	b	c	d	e	f	ℓ
38	43.0	38.0	40.5	52.0	30	9.5	75
50	56.0	51.0	53.6	66.3	23	10.0	81
65	69.0	63.0	65.4	78.1	31	12.0	87
75	84.0	77.0	79.8	92.5	38	13.0	98
90	97.0	89.0	92.3	105.8	46	13.5	107
100	110.0	102.0	105.0	118.3	43	15.0	111
125	134.0	126.0	129.3	144.8	52	21.0	146
150	161.0	153.0	155.8	172.3	78	20.0	162
200	214.0	204.0	207.1	223.6	112	22.5	235