

サニタリー管用継手



Order
注文例


Type - No.
2WCLA - 10

■溶接タイプ90°ショートエルボ



CAD #2D

Type	材質
2WCLA	SUS304
2WCLAS	SUS316L

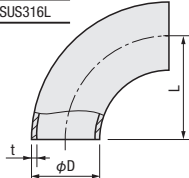


型式		適用管呼び径 (インチ)	D	L	t
Type	No.				
2WCLA 2WCLAS	05	1/2	12.7	19.1	1.65
	08	3/4	19.05	28.6	
	10	1.0	25.4	38.1	
	15	1 1/2	38.1	57.2	
	20	2.0	50.8	76.2	
	25	2 1/2	63.5	95.3	
	30	3.0	76.2	114.3	
	40	4.0	101.6	152.4	

■90°ロングエルボ 3A規格




Type	材質
L2SA	SUS304
L2SAS	SUS316L

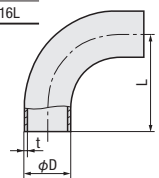


型式		適用管呼び径 (インチ)	D	L	t
Type	No.				
L2SA L2SAS	10	1	25.4	52.4	1.65
	15	1 1/2	38.1	74.6	
	20	2	50.8	103.2	
	25	2 1/2	63.5	131.8	
	30	3	76.2	160.3	
	40	4	101.6	211.1	

 ■フラットショートチーズ



Type	材質
7WWEA	SUS304

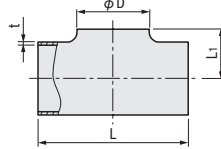


型式		適用管呼び径 (インチ)	D	L	L1	t
Type	No.					
7WWEA	10	1	25.4	57.2	16	1.65
	15	1 1/2	38.1	84.2	22	
	20	2	50.8	104.8	29	
	25	2 1/2	63.5	119.0	35	
	30	3	76.2	131.8	41	
	40	4	101.6	174.6	54	

■等径ショートチーズ



Type	材質
7WWWA	SUS304
7WWWAS	SUS316L

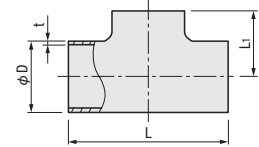


型式		適用管呼び径 (インチ)	D	L	L1	t
Type	No.					
7WWWA 7WWWAS	10	1	25.4	57.2	28.6	1.65
	15	1 1/2	38.1	84.2	42.1	
	20	2	50.8	104.8	52.4	
	25	2 1/2	63.5	119.0	59.5	
	30	3	76.2	131.8	65.9	
	40	4	101.6	174.6	87.3	

■溶接タイプロングチーズ



CAD #2D

Type	材質
7WA	SUS304
7WAS	SUS316L

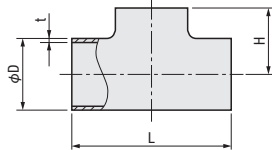


型式		適用管呼び径 (インチ)	D	L	H	t
Type	No.					
7WA 7WAS	10	1.0	25.4	95.2	47.6	1.65
	15	1 1/2	38.1	114.4	57.2	
	20	2.0	50.8	152.4	76.2	
	25	2 1/2	63.5			
	30	3.0	76.2	165.2	82.6	
	40	4.0	101.6	196.8	98.4	

■異径ロングチーズ



Type	材質
7RWAS	SUS316L

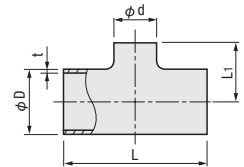

型式		適用管呼び径 (インチ)	D	d	L	L1	t
Type	No.						
7RWAS	1510	1.5×1	38.1	25.4	114.3	54.0	1.65
	2010	2×1	50.8			60.3	
	2015	2×1.5				63.5	
	2515	2.5×1.5	63.5		152.4	69.9	
	2520	2.5×2				82.6	
	3015	3×1.5	76.2		165.1	76.2	
	3020	3×2				88.9	
	3025	3×2.5	76.2		196.8	82.6	
	4020	4×2				101.6	
	4025	4×2.5	101.6		196.8	101.6	
	4030	4×3				76.2	