


# MSI series - Mini compact cylinder

Operating specification and Ordering expression

CHELIC PNEUMATIC


## Internal structure

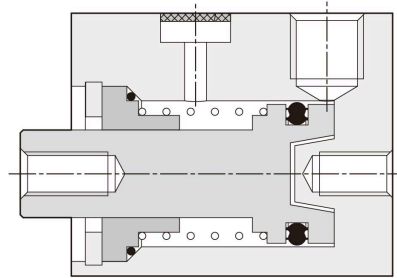

## Specification

Model	Bore size	Ø10
Operation		Single acting
Fluid		Air
Pressure range	kgf/cm <sup>2</sup> (kpa)	2 ~ 7 (200 ~ 700)
Max. service pressure	kgf/cm <sup>2</sup> (kpa)	9.5 ( 950 )
Range of service temperature	°C	0 ~ 60
Operated speed	mm/sec	50 ~ 500
Connection port		M5x0.8

## How to order

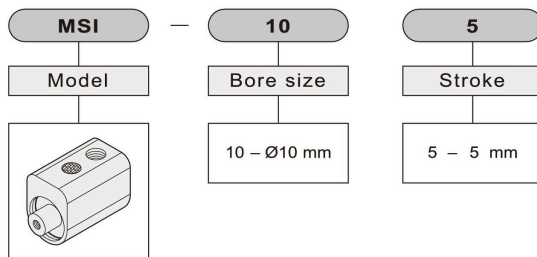

**MSI :**  
Mini compact cylinder

**NA**  
Cartridge  
Cylinder

**NA2**  
Cartridge  
Cylinder

**NB**  
Cartridge  
Cylinder

**NU**  
Free Mount  
Cylinder

**ND**  
Free Mount  
Cylinder

**NQ**  
Free Mount  
Cylinder

**MSI**  
Mini  
Compact  
Cylinder

**JD**  
Compact  
Cylinder

**JG**  
Compact  
Cylinder

**JTD**  
Twin-Guide  
Cylinder

**JTF**  
Twin-Guide  
Cylinder

**JCB**  
Twin-Guide  
Cylinder

**JCF**  
Twin-Guide  
Cylinder

**JE**  
Compact  
Cylinder