




Fitting series

SQC series

CHELIC PNEUMATIC

◯ SQC series Straight (Male)

Metric specification

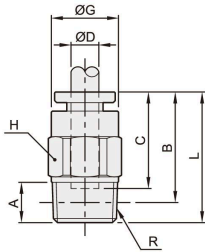

Port size ØD	Thread size Rc (PT)	Model	A	B	C	ØG	L	Opposite dim H	Effective area mm ²	Weight (g)
Ø4	M5	SQC 4 - M5	3.2	17.7	14.1	10	19.3	10	4	5
	1/8"	SQC 4 - 01	5.5	16	14.1	10	18.7	10	5.5	6
	1/4"	SQC 4 - 02	8	12.9	14.1	10	16.9	14	5.5	13
Ø6	M5	SQC 6 - M5	2.9	20.3	16.3	12	21.7	12	4	8
	1/8"	SQC 6 - 01	5.5	18.2	17.1	12	20.9	12	12.5	7.5
	1/4"	SQC 6 - 02	8	18.2	17.1	12.4	22.2	14	12.5	15
Ø8	3/8"	SQC 6 - 03	8	15	17.1	12.4	19	17	12.5	23
	1/8"	SQC 8 - 01	5.5	23	18.7	14	25.7	14	20	12.5
	1/4"	SQC 8 - 02	8	20	18.7	14	24	14	20	15
Ø10	3/8"	SQC 8 - 03	7.8	15.4	18.3	14.3	19.3	17	20	19
	1/8"	SQC 10 - 01	5.5	25.6	20.6	17	28.3	17	22	21
	1/4"	SQC 10 - 02	8	25.9	20.4	17	29.9	17	35	23
	3/8"	SQC 10 - 03	8	21.9	20.9	17	25.9	17	35	25
Ø12	1/2"	SQC 10 - 04	10.5	19.7	20.9	17.5	24.9	21	35	40
	1/4"	SQC 12 - 02	8	30.5	23.8	20.4	34.5	21	35	36
	3/8"	SQC 12 - 03	8	26.6	23.8	20.4	30.6	21	58	27
Ø12	1/2"	SQC 12 - 04	10	25.8	23.8	20.4	30.8	21	58	29

SQ
Fitting

MSQ
Mini type
Fitting

SP
Plug
Nipple

SQ J
Nipple
Fitting

SQR
Check
Fitting

SQ G
Pressure
Gauge
Fitting

**Brass
Fitting**

Inch specification

Port size ØD	Thread size NPT	Model	A	B	C	ØG	L	Opposite dim H	Effective area mm ²	Weight (g)
5/32"	NR10/32"	SQC 5/32 - 10/32	3.2	17.7	14.1	10	19.3	10	4	5
	1/8"	SQC 5/32 - 01	6	16.5	14.1	10	19.5	10	5.5	6
	1/4"	SQC 5/32 - 02	9	14.3	14.1	10	18.8	14	5.5	13
1/4"	NR10/32"	SQC 1/4 - 10/32	3.2	20.8	17	12	22.4	12	4	8
	1/8"	SQC 1/4 - 01	6	19	17.5	12	22	12	12.5	7.5
	1/4"	SQC 1/4 - 02	9	19.6	17.5	12.4	24.1	14	12.5	15
	3/8"	SQC 1/4 - 03	9	17.4	17.5	12.4	21.9	17	12.5	23
5/16"	1/8"	SQC 5/16 - 01	6	23.7	18.7	14	26.7	14	20	12.5
	1/4"	SQC 5/16 - 02	9	21.5	18.7	14	26	14	20	15
	3/8"	SQC 5/16 - 03	9	17.1	18.7	14.3	21.6	17	20	19
3/8"	1/8"	SQC 3/8 - 01	6	25.8	20.8	17	28.8	17	22	21
	1/4"	SQC 3/8 - 02	9	25.3	18.8	17	29.8	17	35	23
	3/8"	SQC 3/8 - 03	9	23.3	20.8	17	27.8	17	35	25
	1/2"	SQC 3/8 - 04	11	22.2	20.7	17.5	27.7	21	35	40
1/2"	1/4"	SQC 1/2 - 02	9	30.9	23.7	21.5	25.4	22	35	38
	3/8"	SQC 1/2 - 03	9	29.2	23.7	21.5	33.7	22	58	27
	1/2"	SQC 1/2 - 04	11	26.2	23.7	21.5	31.7	22	58	29

SC
Speed
Controller

QS
Speed
Controller

QH
Hand
Valve

QV
Union
Straight

QST
Panel type
Speed
Controller

**PU
Tube**