




Fitting series

SQG series

CHELIC PNEUMATIC

◉ SQG series Straight (Female)

Metric specification

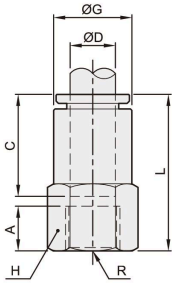

Port size ØD	Thread size Rc (PT)	Model	A	C	ØG	L	Opposite dim H	Effective area mm ²	Weight (g)
Ø4	1/8"	SQG 4 - 01	8.5	14.1	10	24.1	12	4	20.5
	1/4"	SQG 4 - 02	10.5	14.4	10	26.9	17	5.5	12
Ø6	1/8"	SQG 6 - 01	8	17	12	26.8	12	12.5	21
	1/4"	SQG 6 - 02	10	17	12	29.3	17	12.5	18
Ø8	1/8"	SQG 8 - 01	8.5	17.8	14	28	14	20	25
	1/4"	SQG 8 - 02	10.5	17.8	14	30.5	17	20	28
	3/8"	SQG 8 - 03	10.5	17.8	14	30.5	19	20	28
Ø10	1/4"	SQG 10 - 02	10.5	20.8	17	33.4	17	22	32
	3/8"	SQG 10 - 03	10.5	20.3	17	32.6	19	35	30
Ø12	1/4"	SQG 12 - 02	10.5	23.6	20.4	37.7	21	58	53
	3/8"	SQG 12 - 03	10.5	23.6	20.4	36.3	21	58	46
	1/2"	SQG 12 - 04	12.5	23.6	20.4	38.8	24	58	54.5

Inch specification

Port size ØD	Thread size NPT	Model	A	C	ØG	L	Opposite dim H	Effective area mm ²	Weight (g)
5/32"	1/8"	SQG 5/32 - 01	9	14.4	10	25.4	12	4	20.5
	1/4"	SQG 5/32 - 02	11	14.4	10	27.9	17	5.5	12
1/4"	1/8"	SQG 1/4 - 01	9	17.5	12	28.5	12	12.5	21
	1/4"	SQG 1/4 - 02	11	17.5	12	31	17	12.5	18
5/16"	1/8"	SQG 5/16 - 01	9	18.7	14	29.9	14	20	25
	1/4"	SQG 5/16 - 02	11	18.7	14	32.4	17	20	26
	3/8"	SQG 5/16 - 03	11	18.7	14	32.4	19	20	26
3/8"	1/4"	SQG 3/8 - 02	11	20.7	17	34.7	17	22	30
	3/8"	SQG 3/8 - 03	11	20.7	17	34.7	19	35	30
1/2"	1/4"	SQG 1/2 - 02	11	23.7	21.5	37.7	21	58	53
	3/8"	SQG 1/2 - 03	11	23.8	20.4	37.8	21	58	46
	1/2"	SQG 1/2 - 04	13	23.8	20.4	40.3	24	58	54.5