


# PU Tube series

## Specification and Order expression

CHELIC PNEUMATIC

### How to order

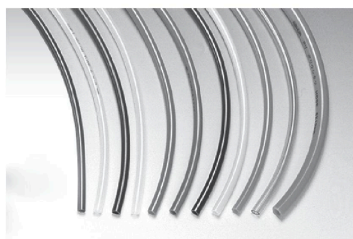

<b>PU</b>	<b>06</b>	<b>40</b>	<b>BK</b>																																																																																		
Model	Outer dimension	Inner dimension	Color																																																																																		
PU : PU tube PN : PN tube	<table border="1"> <thead> <tr> <th>Symbol</th> <th>Out-side diam (mm)</th> </tr> </thead> <tbody> <tr><td>03</td><td>Ø3</td></tr> <tr><td>04</td><td>Ø4</td></tr> <tr><td>06</td><td>Ø6</td></tr> <tr><td>08</td><td>Ø8</td></tr> <tr><td>10</td><td>Ø10</td></tr> <tr><td>12</td><td>Ø12</td></tr> </tbody> </table>	Symbol	Out-side diam (mm)	03	Ø3	04	Ø4	06	Ø6	08	Ø8	10	Ø10	12	Ø12	<table border="1"> <thead> <tr> <th rowspan="2">Symbol</th> <th rowspan="2">In-side diam</th> <th colspan="2">Model</th> </tr> <tr> <th>PU</th> <th>PN</th> </tr> </thead> <tbody> <tr><td>20</td><td>Ø2.0</td><td>●</td><td>-</td></tr> <tr><td>25</td><td>Ø2.5</td><td>●</td><td>●</td></tr> <tr><td>40</td><td>Ø4.0</td><td>●</td><td>●</td></tr> <tr><td>50</td><td>Ø5.0</td><td>-</td><td>●</td></tr> <tr><td>60</td><td>Ø6.0</td><td>-</td><td>●</td></tr> <tr><td>65</td><td>Ø6.5</td><td>-</td><td>●</td></tr> <tr><td>75</td><td>Ø7.5</td><td>-</td><td>●</td></tr> <tr><td>80</td><td>Ø8.0</td><td>●</td><td>-</td></tr> <tr><td>90</td><td>Ø9.0</td><td>-</td><td>●</td></tr> </tbody> </table>	Symbol	In-side diam	Model		PU	PN	20	Ø2.0	●	-	25	Ø2.5	●	●	40	Ø4.0	●	●	50	Ø5.0	-	●	60	Ø6.0	-	●	65	Ø6.5	-	●	75	Ø7.5	-	●	80	Ø8.0	●	-	90	Ø9.0	-	●	<table border="1"> <thead> <tr> <th rowspan="2">Symbol</th> <th rowspan="2">Color</th> <th colspan="2">Model</th> </tr> <tr> <th>PU</th> <th>PN</th> </tr> </thead> <tbody> <tr><td>BK</td><td>Black</td><td>●</td><td>-</td></tr> <tr><td>BU</td><td>Blue</td><td>●</td><td>-</td></tr> <tr><td>TR</td><td>Trans-parent</td><td>●</td><td>-</td></tr> <tr><td>OR</td><td>Orange</td><td>●</td><td>-</td></tr> <tr><td>WH</td><td>White</td><td>-</td><td>●</td></tr> </tbody> </table>	Symbol	Color	Model		PU	PN	BK	Black	●	-	BU	Blue	●	-	TR	Trans-parent	●	-	OR	Orange	●	-	WH	White	-	●
Symbol	Out-side diam (mm)																																																																																				
03	Ø3																																																																																				
04	Ø4																																																																																				
06	Ø6																																																																																				
08	Ø8																																																																																				
10	Ø10																																																																																				
12	Ø12																																																																																				
Symbol	In-side diam	Model																																																																																			
		PU	PN																																																																																		
20	Ø2.0	●	-																																																																																		
25	Ø2.5	●	●																																																																																		
40	Ø4.0	●	●																																																																																		
50	Ø5.0	-	●																																																																																		
60	Ø6.0	-	●																																																																																		
65	Ø6.5	-	●																																																																																		
75	Ø7.5	-	●																																																																																		
80	Ø8.0	●	-																																																																																		
90	Ø9.0	-	●																																																																																		
Symbol	Color	Model																																																																																			
		PU	PN																																																																																		
BK	Black	●	-																																																																																		
BU	Blue	●	-																																																																																		
TR	Trans-parent	●	-																																																																																		
OR	Orange	●	-																																																																																		
WH	White	-	●																																																																																		

Also available in other color.

### Specification

#### PU tube & water resistant PU tube & Polyethylene tube

Item No.	OD x ID (mm)	Burst pressure (kgf/cm <sup>2</sup> )	Working pressure (kgf/cm <sup>2</sup> )	Min bending raids (mm)	Standard length (m)	Temperature (°C)
PU0320	3 × 2	10	< 10	06	500	0 ~ 50
PU0425	4 × 2.5	32	< 10	10	200	0 ~ 50
PU0640	6 × 4	27	< 10	16	200	0 ~ 50
PU0850	8 × 5	32	< 10	22	100	0 ~ 50
PU1065	10 × 6.5	30	< 10	28	100	0 ~ 50
PU1280	12 × 8	28	< 10	37	100	0 ~ 50

※ Standard color : Black , Blue , Transparent (Also available in other color).

#### Nylon tube & Polyethylene tube

Item No.	OD x ID (mm)	Burst pressure (kgf/cm <sup>2</sup> )	Working pressure (kgf/cm <sup>2</sup> )	Min bending raids (mm)	Standard length (m)	Temperature (°C)
PN0425	4 × 2.5	99	< 20	17	200	0 ~ 50
PN0640	6 × 4	66	< 20	37	100	0 ~ 50
PN0860	8 × 6	63	< 20	48	100	0 ~ 50
PN1075	10 × 7.5	67	< 20	66	100	0 ~ 50
PN1290	12 × 9	64	< 20	76	100	0 ~ 50

※ Standard color : White.

### How to order



<b>PUL</b>	<b>08</b>	<b>50</b>	<b>6</b>	<b>BK</b>																																																	
Model	Outer dimension	Inner dimension	Length	Color																																																	
PUL : Spiral tube	<table border="1"> <thead> <tr> <th>Symbol</th> <th>Out-side diam (mm)</th> </tr> </thead> <tbody> <tr><td>08</td><td>Ø8</td></tr> <tr><td>10</td><td>Ø10</td></tr> <tr><td>12</td><td>Ø12</td></tr> </tbody> </table>	Symbol	Out-side diam (mm)	08	Ø8	10	Ø10	12	Ø12	<table border="1"> <thead> <tr> <th rowspan="2">Symbol</th> <th colspan="3">In-side diam (mm)</th> </tr> <tr> <th>Ø5</th> <th>Ø6.5</th> <th>Ø8</th> </tr> </thead> <tbody> <tr><td>50</td><td>●</td><td>-</td><td>-</td></tr> <tr><td>65</td><td>-</td><td>●</td><td>-</td></tr> <tr><td>80</td><td>-</td><td>-</td><td>●</td></tr> </tbody> </table>	Symbol	In-side diam (mm)			Ø5	Ø6.5	Ø8	50	●	-	-	65	-	●	-	80	-	-	●	<table border="1"> <thead> <tr> <th>Symbol</th> <th>Length (m)</th> </tr> </thead> <tbody> <tr><td>6</td><td>6</td></tr> <tr><td>9</td><td>9</td></tr> <tr><td>12</td><td>12</td></tr> <tr><td>15</td><td>15</td></tr> </tbody> </table>	Symbol	Length (m)	6	6	9	9	12	12	15	15	<table border="1"> <thead> <tr> <th>Symbol</th> <th>Color</th> <th>Note</th> </tr> </thead> <tbody> <tr><td>BK</td><td>Block</td><td>standard</td></tr> <tr><td>BU</td><td>Blue</td><td>custom</td></tr> <tr><td>OR</td><td>Orange</td><td>custom</td></tr> </tbody> </table>	Symbol	Color	Note	BK	Block	standard	BU	Blue	custom	OR	Orange	custom
Symbol	Out-side diam (mm)																																																				
08	Ø8																																																				
10	Ø10																																																				
12	Ø12																																																				
Symbol	In-side diam (mm)																																																				
	Ø5	Ø6.5	Ø8																																																		
50	●	-	-																																																		
65	-	●	-																																																		
80	-	-	●																																																		
Symbol	Length (m)																																																				
6	6																																																				
9	9																																																				
12	12																																																				
15	15																																																				
Symbol	Color	Note																																																			
BK	Block	standard																																																			
BU	Blue	custom																																																			
OR	Orange	custom																																																			

※ Also available in other color.

#### PU Spiral tube

Item No.	OD x ID (mm)	Burst pressure (kgf/cm <sup>2</sup> )	Working pressure (kgf/cm <sup>2</sup> )	Min bending raids (mm)	Standard length (m)	Temperature (°C)
PUL0850	8 × 5	32	< 10	22	6、9、12、15	0 ~ 50
PUL1065	10 × 6.5	30	< 10	28	6、9、12、15	0 ~ 50
PUL1280	12 × 8	28	< 10	37	6、9、12、15	0 ~ 50

※ Standard color : Orange. (Also available in other color).