


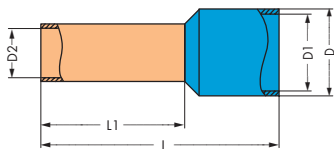








<p>Ferrule, insulated, tin plated, electrolytic copper, gastight crimped</p>	<p>Variocrimp 4 crimping tool for insulated and uninsulated ferrules 0.25 mm<sup>2</sup> ... 4 mm<sup>2</sup>/AWG 24 ... 12</p>	<p>Variocrimp 16 crimping tool for insulated and uninsulated ferrules 6 mm<sup>2</sup> ... 16 mm<sup>2</sup>/AWG 10 ... 6</p>
--	---	---



Item No.	Pack. Unit	Item No.	Pack. Unit	Item No.	Pack. Unit
Ferrule, insulated, according to DIN 46228, part 4/09.90		Variocrimp 4 crimping tool, 0.25 mm <sup>2</sup> ... 4 mm <sup>2</sup> /AWG 24 ... 12		Variocrimp 16 crimping tool, 6 mm <sup>2</sup> ... 16 mm <sup>2</sup> /AWG 10 ... 6	
● yellow 216-321	1000	206-204	1	206-216	1
● yellow 216-301	1000				
● green 216-322	1000				
● green 216-302	1000				
○ white 216-221	1000				
○ white 216-201	1000				
● gray 216-222	1000				
● gray 216-202	1000				
● red 216-223	1000				
● red 216-203	1000				
● black 216-224	1000				
● black 216-204	1000				
● yellow 216-205	1000				
● blue 216-206	1000				
● gray 216-207	1000				
● yellow 216-208	100				
● red 216-209	100				
● blue 216-210	100				

## Ferrules

### Technical Data

Ferrule, insulated,	Ferrule, insulated,	Ferrule, insulated,
 <p>sleeve for 0.25 mm<sup>2</sup>/AWG 24, 7 mm strip length, L: 10.5 mm, L1: 6 mm, D: 2.5 mm, D1: 2 mm, D2: 0.8 mm yellow 216-321</p>	 <p>sleeve for 0.34 mm<sup>2</sup>/AWG 24, 9 mm strip length, L: 12.5 mm, L1: 8 mm, D: 2.5 mm, D1: 2 mm, D2: 0.8 mm green 216-302</p>	 <p>sleeve for 0.75 mm<sup>2</sup>/AWG 20, 8 mm strip length, L: 12 mm, L1: 6 mm, D: 3.3 mm, D1: 2.8 mm, D2: 1.3 mm gray 216-222</p>
 <p>sleeve for 0.25 mm<sup>2</sup>/AWG 24, 9 mm strip length, L: 12.5 mm, L1: 8 mm, D: 2.5 mm, D1: 2 mm, D2: 0.8 mm yellow 216-301</p>	 <p>sleeve for 0.5 mm<sup>2</sup>/AWG 22, 7 mm strip length, L: 11.5 mm, L1: 6 mm, D: 3 mm, D1: 2.5 mm, D2: 1.1 mm white 216-221</p>	 <p>sleeve for 0.75 mm<sup>2</sup>/AWG 20, 10 mm strip length, L: 14 mm, L1: 8 mm, D: 3.3 mm, D1: 2.8 mm, D2: 1.3 mm gray 216-202</p>
 <p>sleeve for 0.34 mm<sup>2</sup>/AWG 24, 7 mm strip length, L: 10.5 mm, L1: 6 mm, D: 2.5 mm, D1: 2 mm, D2: 0.8 mm green 216-322</p>	 <p>sleeve for 0.5 mm<sup>2</sup>/AWG 22, 9 mm strip length, L: 13.5 mm, L1: 8 mm, D: 3 mm, D1: 2.5 mm, D2: 1.1 mm white 216-201</p>	 <p>sleeve for 1 mm<sup>2</sup>/AWG 18, 8 mm strip length, L: 12 mm, L1: 6 mm, D: 3.6 mm, D1: 3 mm, D2: 1.5 mm red 216-223</p>