

# Accessories


## Strain Relief Plates

### MCS MICRO

<p><b>Strain relief plates for insertion</b></p> <p>for male and female connectors equipped with CAGE CLAMP®</p>	<p><b>Strain relief plates factory-assembled</b></p> <p>for male and female connectors equipped with CAGE CLAMP®</p>
--	--




Width	Pole No.	Item No.	Pack. Unit	Width	Pole No.	Item no. suffix	Pack. Unit
<b>Strain relief plate light gray</b>				<b>Strain relief plate, pre-assembled</b>			
6 mm	2 ... 4	<b>734-127</b>	100 (4 x 25)	6 mm	2 ... 4	.../032-000	
12.5 mm	5 ... 9	<b>734-128</b>	100 (4 x 25)	12.5 mm	5 ... 9	.../033-000	
25 mm	10 ... 12	<b>734-129</b>	100 (4 x 25)	25 mm	10 ... 12	.../034-000	
				<b>Ordering example:</b>			
				Female connector with strain relief plate, 2.5 mm pin spacing, 2-pole, light gray:			
				<b>733-102/032-000</b>			
An "item no. suffix", referring to the width of the strain relief plate, is added to the "basic item no." and determines the type of male or female connector.							

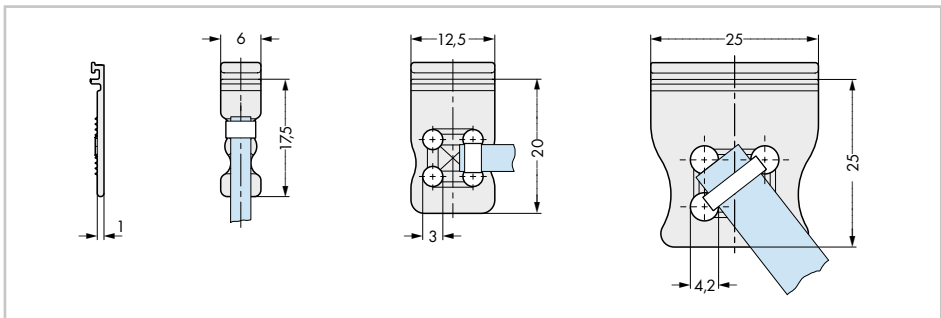

The arrangement of the attachments for cable ties allows single conductors or multi-core cables to be secured in different ways. The width of the cable ties must correspond to the hole dimensions of the strain relief plates shown above.

Cable ties and cable binding tools are not included in the WAGO scope of supply. Refer to the Hellemann company, for example, for these items.

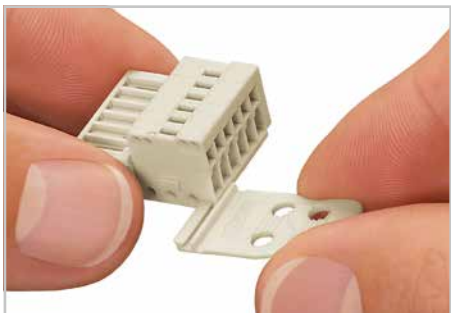

734-128 strain relief plate, for in-the-field assembly.



Strain relief plate, for factory assembly, female connector, 2.5 mm pin spacing, light gray, 2-pole, with 733-102/032-000 strain relief plate.



Strain relief plate, for factory assembly, female connector, 2.5 mm pin spacing, light gray, 12-pole, with 733-112/034-000 strain relief plate.