

RockStar® Housings IP66 / NEMA Type 4X

Side locking, lower side


Size 4

Hood

Plug housing, cable entry sideways




a	Version	Cover	b (mm)	Type	Order No.
M 20	w. threading		52	HDC 10B TSBU 1M20G	1787560000
M 25	w. threading		52	HDC 10B TSBU 1M25G	1787550000
M 25	w. threading		72	HDC 24D TSBU 1M25G	1787240000
M 32	w. threading		72	HDC 24D TSBU 1M32G	1787230000
PG 16	w. threading		52	HDC 10B TSBU 1PG16G	1654070000
PG 21	w. threading		52	HDC 10B TSBU 1PG21G	1654090000
PG 21	w. threading		72	HDC 24D TSBU 1PG21G	1654150000
PG 29	w. threading		72	HDC 24D TSBU 1PG29G	1654170000

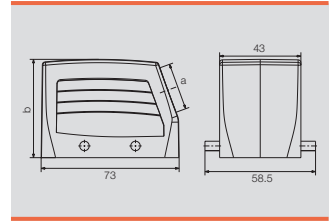

Plug housing, cable entry at top



a	Version	Cover	b (mm)	Type	Order No.
M 20	w. threading		52	HDC 10B TOBU 1M20G	1787600000
M 25	w. threading		52	HDC 10B TOBU 1M25G	1787590000
M 25	w. threading		72	HDC 24D TOBU 1M25G	1787300000
M 32	w. threading		72	HDC 24D TOBU 1M32G	1787290000
PG 16	w. threading		52	HDC 10B TOBU 1PG16G	1654220000
PG 21	w. threading		52	HDC 10B TOBU 1PG21G	1654240000
PG 29	w. threading		72	HDC 24D TOBU 1PG29G	1654320000

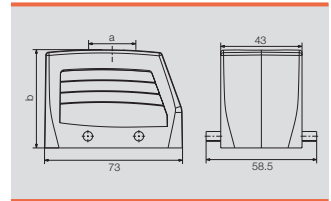

Cover



Version	Type	Order No.
For hoods	HDC 10B DMDQ 2QB	1665240000

