


### Crimping tools for wire end ferrules

- For wire-end ferrules with and without plastic collars in accordance with DIN 46228 Part 1 and Part 4
- Rotating crimp insert, lockable
- Insert the wire-end ferrules from the side or front
- Ratchet for precise crimping
- Release option if misused

#### PZ 6 Roto L

0.14–6 mm<sup>2</sup>

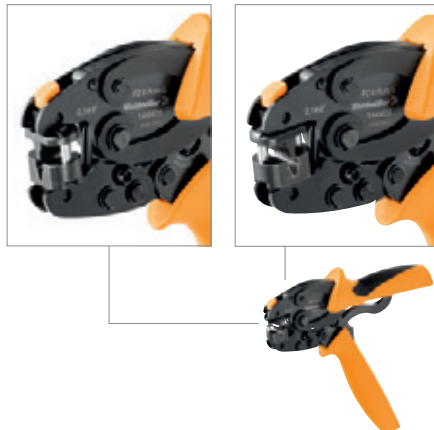

- ~AWG 26...10
- Only one crimp insert for the whole cross-section range
- A rotating crimp insert allows for wire-end ferrules to be inserted from the side or front
- Lockable die



#### PZ 6 Roto

0.14...6 mm<sup>2</sup>



- ~AWG 26...10
- Only one die for the whole cross-section range
- Rotating die enables wire-end ferrule insertion from the front or side



### Technical data

| Description of contact                              |                 |
|---|-----------------|
| Type of contact                                     |                 |
| Crimping range                                      | mm <sup>2</sup> |
| Crimping range 1 (with multiple crimping positions) | -               |
| Crimping range 2 (with multiple crimping positions) | -               |
| Crimping range 3 (with multiple crimping positions) | -               |
| Crimping range 4 (with multiple crimping positions) | -               |
| Crimping range 5 (with multiple crimping positions) | -               |
| Tool data   |                 |
| Length  | mm              |
| Weight  | g               |
| Note  |                 |

### Ordering data

| Version |
|---------|
|         |
| Note    |

| PZ 6 roto L   |          |  |
|---|----------|--|
| Wire-end ferrules with/without plastic collars      |          |  |
| Crimping range                                      | 0.14...6 |  |
| Crimping range 1 (with multiple crimping positions) | -        |  |
| Crimping range 2 (with multiple crimping positions) | -        |  |
| Crimping range 3 (with multiple crimping positions) | -        |  |
| Crimping range 4 (with multiple crimping positions) | -        |  |
| Crimping range 5 (with multiple crimping positions) | -        |  |
| Tool data   |          |  |
| Length  | 200      |  |
| Weight  | 428      |  |
| Note  |          |  |

| Type   | Qty. | Order No.  |
|--|------|------------|
| PZ 6 ROTO L                                      | 1    | 1444050000 |
| PZ 6 ROTO L ZERT                                 | 1    | 1527230000 |
| Additional accessories can be found in Chapter J |      |            |

| PZ 6 roto   |          |  |
|---|----------|--|
| Wire-end ferrules with/without plastic collars      |          |  |
| Crimping range                                      | 0.14...6 |  |
| Crimping range 1 (with multiple crimping positions) | -        |  |
| Crimping range 2 (with multiple crimping positions) | -        |  |
| Crimping range 3 (with multiple crimping positions) | -        |  |
| Crimping range 4 (with multiple crimping positions) | -        |  |
| Crimping range 5 (with multiple crimping positions) | -        |  |
| Tool data   |          |  |
| Length  | 200      |  |
| Weight  | 428      |  |
| Note  |          |  |

| Type   | Qty. | Order No.  |
|--|------|------------|
| PZ 6 Roto  | 1    | 9014350000 |
| PZ 6 ROTO ZERT                                   | 1    | 9017440000 |
| Additional accessories can be found in Chapter J |      |            |