



ステンレス鋼製ねじ込み管継手

径違いニップル RNI

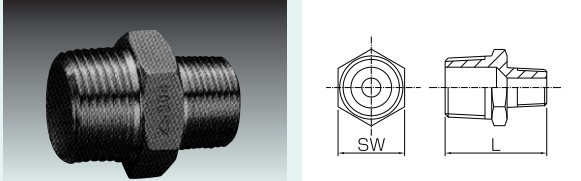

呼び(B)	L	SW	呼び(B)	L	SW
1/4x1/8	33.5	18	1 1/4x1/2	47.5	46
3/8x1/8	34	21	1 1/4x3/4	51.5	45.5
3/8x1/4	35.5	21	1 1/4x1	54	46
1/2x1/8	34.5	26	1 1/2x3/4	53	50
1/2x1/4	33.5	26	1 1/2x1	53	50
1/2x3/8	41	26	1 1/2x1 1/4	59.5	52
3/4x1/8	37	30	2x1/2	52.5	63
3/4x1/4	37.5	30	2x3/4	56.5	63
3/4x3/8	37	30	2x1	57.5	63
3/4x1/2	45	30	2x1 1/4	57.5	63
1x1/4	39	35	2x1 1/2	65.5	64
1x3/8	40	35			
1x1/2	44	35			
1x3/4	50	37			

プッシング BU

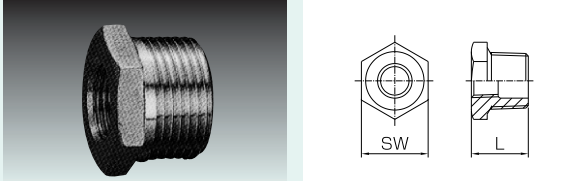

呼び(B)	L	SW	呼び(B)	L	SW
1/4x1/8	15	16	2x1/2	36	63
3/8x1/8	16.5	18	2x3/4	36	63
3/8x1/4	16.5	18	2x1	36	63
1/2x1/8	21.5	26	2x1 1/4	36	63
1/2x1/4	21.5	26	2x1 1/2	36	63
1/2x3/8	21.5	26	2 1/2x1	45	81
3/4x1/8	24	30	2 1/2x1 1/4	45	81
3/4x1/4	24	30	2 1/2x1 1/2	45	81
3/4x3/8	24	30	2 1/2x2	45	81
3/4x1/2	24	30	3x1	47	95
1x1/8	27	35	3x1 1/4	47	95
1x1/4	27	35	3x2 1/2	47	95
1x3/8	27	35	3x2	47	95
1x1/2	27	35	3x2 1/2	47	95
1x3/4	27.5	35	4x1 1/2	51.5	120
1 1/4x3/8	30	45	4x2	51.5	120
1 1/4x1/2	30	45	4x2 1/2	51.5	120
1 1/4x3/4	30	45	4x3	51.5	120
1 1/4x1	30	45.5			
1 1/2x3/8	38	52			
1 1/2x1/2	38	52			
1 1/2x3/4	38	52			
1 1/2x1	38	52			
1 1/2x1 1/4	38	52			

単位：mm

品種一覧

※ ホースニップル(丸)・パイプソケット類はSUS304加工品です。

寸法	品名										ホースニップル(丸)						パイプソケット		パイプソケット		パイプソケット		パイプソケット		パイプソケット	
	エルボ	45°エルボ	スリットエルボ	チーズ	クロス	プラグ	キャップ	ユニオン	エيونエルボ	ニップル	ホースニップル	CHNI	ストレートねじUS	ストレートねじUS	ストレートねじUSPT	ストレートHSS	HPT	HPT	HPT	HPT	HPT	HPT				
1/8	●★	●	●★	●★	●	●	●	●		●	●	●	●	●	●	○						●				
1/4	●★	●	●★	●★	●	●	●	●		●	●	●	●	●	●	○						●				
3/8	●★	●	●★	●★	●	●	●	●		●	●	●	●	●	●	○						●				
1/2	●★	●	●★	●★	●	●	●	●		●	●	●	●	●	●	○						●				
3/4	●★	●	●★	●★	●	●	●	●		●	●	●	●	●	●	○						●				
1	●★	●	●★	●★	●	●	●	●		●	●	●	●	●	●	○						●				
1 1/4	●★	●	●★	●★	●	●	●	●		●	●	●	●	●	●	○						●				
1 1/2	●★	●	●★	●★	●	●	●	●		●	●	●	●	●	●	○						●				
2	●★	●	●★	●★	●	●	●	●		●	●	●	●	●	●	○						●				
2 1/2	●	●	●	●	●	●	●	●		●	●	●	●	●	●	○						●				
3	●	●	●	●	●	●	●	●		●	●	●	●	●	●	○						●				
4	●	●	●	●	●	●	●	●		●	●	●	●	●	●	○						●				

寸法	品名	径違いエルボ	径違いチーズ	径違いソケット	径違いニップル	プッシング
		RL	RT	RS	RNI	BU
1/4x1/8		●		●	●	●
3/8x1/8			●	●	●	●
3/8x1/4		●	●	●	●	●
1/2x1/8			●	●	●	●
1/2x1/4		●	●	●	●	●
1/2x3/8		●	●	●	●	●
3/4x1/8			●	●	●	●
3/4x1/4			●	●	●	●
3/4x3/8		●	●	●	●	●
3/4x1/2		●	●	●	●	●
1x1/8			●	●	●	●
1x1/4			●	●	●	●
1x3/8			●	●	●	●
1x1/2		●	●	●	●	●
1x3/4		●	●	●	●	●
1 1/4x3/8			●	●	●	●
1 1/4x1/2			●	●	●	●
1 1/4x3/4		●	●	●	●	●
1 1/4x1		●	●	●	●	●
1 1/2x3/8			●	●	●	●
1 1/2x1/2			●	●	●	●

寸法	品名	径違いエルボ	径違いチーズ	径違いソケット	径違いニップル	プッシング
		RL	RT	RS	RNI	BU
1 1/2x3/4			●	●	●	●
1 1/2x1		●	●	●	●	●
1 1/2x1 1/4			●	●	●	●
2x1/2			●	●	●	●
2x3/4			●	●	●	●
2x1			●	●	●	●
2x1 1/4		●	●	●	●	●
2x1 1/2		●	●	●	●	●
2 1/2x1			●	●	●	●
2 1/2x1 1/4			●	●	●	●
2 1/2x1 1/2			●	●	●	●
2 1/2x2			●	●	●	●
3x1			●	●	●	●
3x1 1/4			●	●	●	●
3x1 1/2			●	●	●	●
3x2			●	●	●	●
3x2 1/2			●	●	●	●
4x1 1/2				●	●	●
4x2				●	●	●
4x2 1/2				●	●	●
4x3				●	●	●

★印：バンド無(平形)もございます。 ○印：受注生産品です。