



1050 オス プラグ Male plug (PF30° FCS plug)

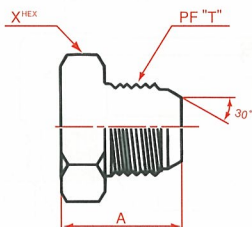

呼称サイズ	T	A	X
02	1/8	20.5	17
04	1/4	24	19
06	3/8	26	19
08	1/2	30	27
12	3/4	33.5	36
16	1	32.5	41

1035 オス45°エルボ Male 45° elbow (External pipe/PF30° FCS)

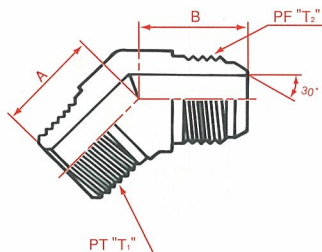

呼称サイズ	T ₁	T ₂	A	B
02	1/8	1/8	18	18
02-04	1/8	1/4	18	22
04	1/4	1/4	19	22
04-02	1/4	1/8	19	18
04-06	1/4	3/8	20	24.5
06	3/8	3/8	22	24.5
06-04	3/8	1/4	22	23
08	1/2	1/2	27	28
08-06	1/2	3/8	27	26.5
08-12	1/2	3/4	28	31.5
12	3/4	3/4	30	31.5
12-08	3/4	1/2	30	30
12-16	3/4	1	32	33.5
16	1	1	33.5	34
16-12	1	3/4	34	33
20	1 1/4	1 1/4	40	41
24	1 1/2	1 1/2	41	43
32	2	2	50	50