


1084

オス コネクター  
Male connector

JIS O-Ring boss/PF30° FCS

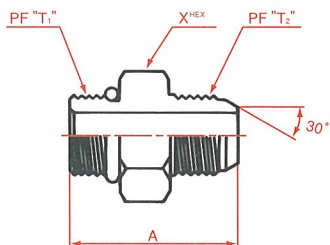


呼称サイズ	T <sub>1</sub>	T <sub>2</sub>	A	X
04	1/4	1/4	30	19
04-06	1/4	3/8	32	22
06-04	3/8	1/4	33	22
06	3/8	3/8	35	22
06-08	3/8	1/2	38	27
08-06	1/2	3/8	39	27
08-12	1/2	3/4	45	36
08	1/2	1/2	42	27
12-08	3/4	1/2	45	36
12	3/4	3/4	49	36
12-16	3/4	1	49	41
16-12	1	3/4	51	41
16	1	1	53	41

1086

オス 90° 座付エルボ  
Male 90° O-Ring boss(adj) elbow

JIS O-Ring boss(adj) /PF30° FCS

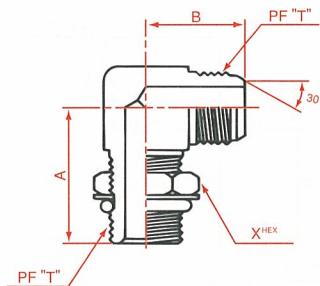

呼称サイズ	T	A	B	X
04	1/4	32	27	19
06	3/8	37	32	22
08	1/2	43	37	27
12	3/4	49	42	36
16	1	52	46	41