


CEQA

High Helix Center Drills-JIS Type A 90°

HSS

Segment : 51

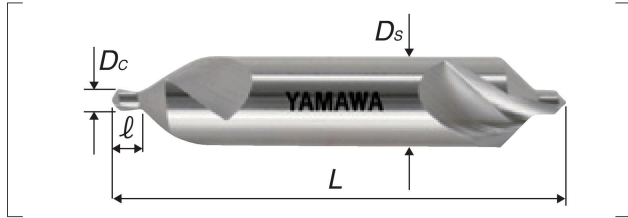


Size Dc x θ x Ds	Stock	Code	Ds (mm)	L (mm)	ℓ (mm)	Type
1×90°×4	◎	CEA1.0Q	4	35.5	1.1	Ca
1.25×90°×5	◎	CEA1.25Q	5	40	1.4	Ca
1.6×90°×6.3	◎	CEA1.6Q	6.3	45	1.8	Ca
2×90°×8	◎	CEA2.0Q	8	50	2.2	Ca
2.5×90°×10	◎	CEA2.5Q	10	56	2.8	Ca
3.15×90°×11.2	◎	CEA3.15Q	11.2	60	3.6	Ca
4×90°×12.5	◎	CEA4.0Q	12.5	63	4.5	Ca
5×90°×16	◎	CEA5.0Q	16	71	5.6	Ca
6.3×90°×20	◎	CEA6.3Q	20	80	7.1	Ca
8×90°×25	◎	CEA8.0Q	25	100	9	Ca
10×90°×31.5	◎	CEA10.0Q	31.5	125	11.2	Ca
12.5×90°×35.5	◎	CEA12.5Q	35.5	140	14	Ca

CE-Q

High Helix Center Drills-Type A 90°

HSS

Segment : 51

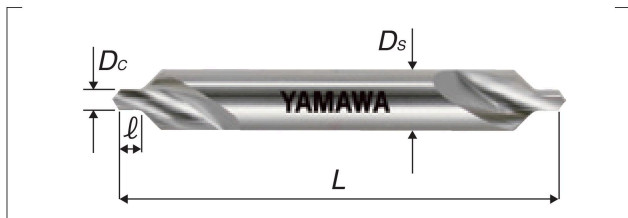

Size Dc x θ x Ds	Stock	Code	Ds (mm)	L (mm)	ℓ (mm)	Type
0.5×90°×3.5	△	CY0.5Z	3.5	35	0.5	Cf
0.6×90°×3.5	△	CY0.6Z	3.5	35	0.6	Cf
0.7×90°×3.5	○	CY0.7Z	3.5	35	0.7	Cf

CE-Q High Helix Center Drills-Type A 90°


Size Dc x θ x Ds	Stock	Code	Ds (mm)	L (mm)	ℓ (mm)	Type
0.8×90°×3.5	○	CY0.8Z	3.5	35	0.8	Cf
0.9×90°×4	△	CY0.9Z	4	35	0.9	Cf
1×90°×4	○	CY1.0Z	4	35	1	Cf
1.2×90°×5	△	CY1.2Z	5	40	1.2	Cf
1.5×90°×5	○	CY1.5Z	5	40	1.5	Cf
2×90°×6	○	CY2.0Z	6	45	2	Cf
2.5×90°×7.7	○	CY2.5Z	7.7	50	2.5	Cf
3×90°×7.7	○	CY3.0Z	7.7	55	3	Cf
4×90°×10	○	CY4.0Z	10	65	4.5	Cf
5×90°×11	○	CY5.0Z	11	78	5.5	Cf
6×90°×16	○	CY6.0Z-16	16	90	6.5	Cf
6×90°×18	○	CY6.0Z	18	90	6.5	Cf

CD-Q

Low Helix Center Drills-Type A 90°

HSS

Segment : 51

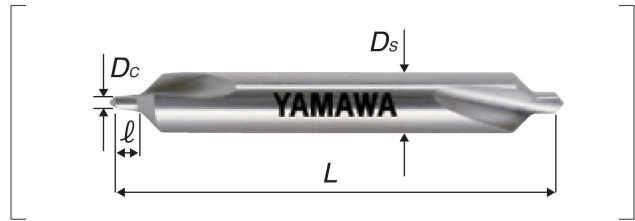

Size Dc x θ x Ds	Stock	Code	Ds (mm)	L (mm)	ℓ (mm)	Type
1×90°×4	○	CY1.0Q	4	35	1	Cf
1.5×90°×5	○	CY1.5Q	5	40	1.5	Cf
2×90°×6	○	CY2.0Q	6	45	2	Cf
2.5×90°×7.7	○	CY2.5Q	7.7	50	2.5	Cf
3×90°×7.7	○	CY3.0Q	7.7	55	3	Cf
4×90°×10	○	CY4.0Q	10	65	4.5	Cf
5×90°×11	○	CY5.0Q	11	78	5.5	Cf
6×90°×16	△	CY6.0Q-16	16	90	6.5	Cf
6×90°×18	△	CY6.0Q	18	90	6.5	Cf