
 
 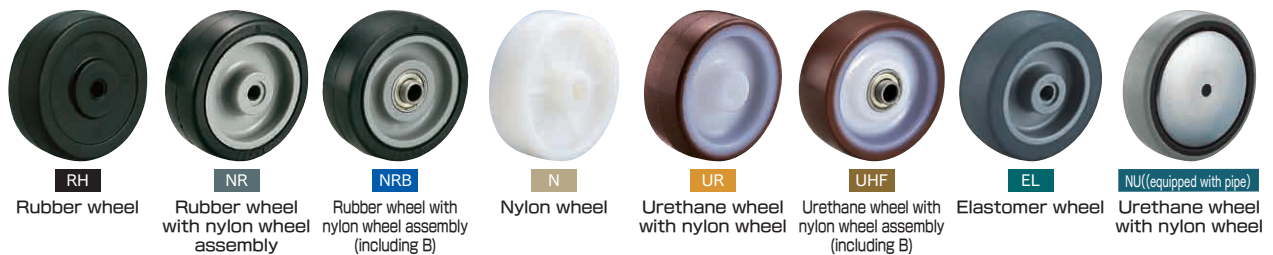
 




Wheels



Wheels used in S SERIES

Product number	Wheels					
		Wheel diameter (mm)	Boss width (mm)	Wheel width (mm)	Hole diameter (mm)	Allowance load daN(kgf)
S- 50 65 75 100	RH Rubber wheel	50	30	28	8.2	50(51.0)
		65	30	25	8.2	50(51.0)
		75	30	25	8.2	60(61.2)
		100	30	25	8.2	50(51.0)
AL- 75 100	NR-B Rubber wheel with nylon wheel assembly	75 100	30	27	8.2	60(61.2) 60(61.2)
AL- 75 100	NRB-B Rubber wheel with nylon wheel assembly (including B)	75 100	32	27	8.2	70(71.4) 70(71.4)
S- 50 65 75 100	N Nylon wheel	50	30	28	8.2	60(61.2)
		65	30	25	8.2	70(71.4)
		75	30	25	8.2	80(81.6)
		100	30	25	8.2	60(61.2)
S- 50 65 75 100	UR Urethane wheel with nylon wheel	50	30	25	8.2	60(61.2)
		65	30	25	8.2	60(61.2)
		75	30	26	8.2	70(71.4)
		100	30	28	8.2	60(61.2)
AL- 75 100	UHF Urethane wheel with nylon wheel assembly (including B)	75 100	32	26	8.2	70(71.4) 70(71.4)
S- 65 75 100	EL Elastomer wheel	65	30	27	8.1	40(40.8)
		75	30	27	8.2	50(51.0)
		100	30	27	8.2	50(51.0)
S- 75 100	NU (equipped with pipe) Urethane wheel with nylon wheel	75 100	32	25	8.2	70(71.4) 70(71.4)

* Allowable load indicates allowable load only for wheels.



Wheels used in E SERIES

Product number	Wheels	Wheel diameter	Boss width	Wheel width	Hole diameter	Allowance load
		(mm)	(mm)	(mm)	(mm)	daN(kgf)
L- 50	R Rubber wheel	50	24	20	6.2	30(30.6)
L- 65 75 100	RH Rubber wheel	65	24	21	6.2	30(30.6)
		75	24	21	6.2	40(40.8)
		100	30	25	8.2	50(51.0)
S- 125		125	30	25	8.2	50(51.0)
AL- 100	NR-B Rubber wheel with nylon wheel assembly	100	30	27	8.2	60(61.2)
AL- 100	NRB-B Rubber wheel with nylon wheel assembly (including B)	100	32	27	8.2	70(71.4)
L- 50 65 75	N Nylon wheel	50	24	21	6.2	40(40.8)
		65	24	21	6.2	40(40.8)
		75	24	21	6.2	50(51.0)
S- 100		100	30	25	8.2	60(61.2)
L- 50 65 75	UR Urethane wheel with nylon wheel	50	24	21	6.2	38(38.8)
		65	24	21	6.2	35(35.7)
		75	24	21	6.2	45(45.9)
S- 100		100	30	28	8.2	60(61.2)
AL- 100	UHF Urethane wheel with nylon wheel assembly (including B)	100	32	28	8.2	70(71.4)
L- 50 75	EL Elastomer wheel	50	24	20	6.2	25(25.5)
		75	24	21	6.1	30(30.6)
S- 100		100	30	27	8.2	50(51.0)

* Allowable load indicates allowable load only for wheels.

* (including B) indicates wheels equipped with bearing.