

Bearings with Housings

L-Shaped

☑ Suitable when crosswise space needs to be secured.




Type		Material		Surface Treatment		Accessory Retaining Ring
h Selectable	h Configurable	Bearing	Housing	Housing	Housing	
BGLKB	BGLFB	Steel	S45C Equivalent	Black Oxide	Electroless Nickel Plating	Spring Steel
BGLK	BGLF					
BGLKA	BGLFA	Stainless Steel	2000 Aluminum Alloy	Clear Anodize	-	SUS304 Equivalent
BGLKSA	BGLFSA					
BGLKS	BGLFS					

Bearing Accuracy: JIS B 1514 Class 0

☑ Bearings with Rubber Seals (VV and DD) are all made of steel.

6.3 / (1.6 /)

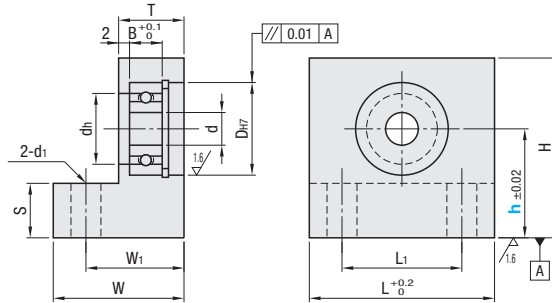

Part Number		h		d	D _{H7}	dh	B	H	L	L ₁	W	W ₁	T	S	d ₁	Unit Price															
Type	Bearing No.	Seal	Selectable													Configurable 1mm increment	Tolerance										h Selectable				
h Selectable	623	ZZ Double Shielded (x1.0)	15 20 25	15-30	3	10	^{+0.015}	7	4	h+9	20	10	20	15	10	5	4.5	BGLKB	BGLK	BGLKA	BGLKSA	BGLKS	BGLFB	BGLF	BGLFA	BGLFSA	BGLFS				
	624				4	13	9	5	h+11	22	12	20	15	10																	
	605				5	14	10	5	h+11	24	14	20	15	10																	
	625				5	16	12	5	h+12	28	16	22	16	10																	
	606				6	17	13	6	h+13	34	22	24	18	12																	
	626		6	19	15	6	h+14	36	24	24	18	12																			
	608		8	22	18	7	h+15	38	26	24	18	12																			
	628		8	24	20	8	h+16	34	22	27	21	15																			
	6900		10	22	19	6	h+15	32	20	24	18	12																			
	6000		10	26	22	8	h+17	38	26	27	21	15																			
6200	10	30	24	9	h+19	40	28	27	21	15																					
6901	12	24	21	6	h+16	36	24	24	18	12																					
6001	12	28	24	8	h+18	40	28	27	21	15																					
6201	12	32	26	10	h+20	42	30	28	22	16																					
6902	15	28	25	7	h+18	42	30	24	18	12																					
6002	15	32	28	9	h+20	50	36	29	22	15																					
6202	15	35	29	11	h+22	44	30	31	24	17																					
6903	17	30	27	7	h+19	42	30	26	20	13																					
6003	17	35	31	10	h+22	50	36	31	24	16																					
6203	17	40	34	12	h+24	48	36	33	26	20																					
6904	20	37	34	9	h+23	45	31	29	22	15																					
6004	20	42	36	12	h+25	54	38	35	27	19																					
6204	20	47	40	14	h+28	60	44	36	28	20																					
6005	25	47	41	12	h+28	62	46	35	27	19																					
6205	25	52	45	15	h+31	70	50	42	32	22																					
6006	30	55	48	13	h+32	74	54	40	30	20																					
6206	30	62	55	16	h+36	82	62	43	33	23																					

☑ The price of sealed VV and DD are the price shown in the table multiplied by 1.1.

☑ Check for available sizes in the price list.

☑ No. 623, 624, 605 and 606 are not available for VV (Non-contact Sealed).



Ordering Example

Part Number				h
Type	Bearing	Seal		
BGLK	6000	DD	-	30
BGLFA	6904	ZZ	-	45



Alterations



Part Number	h	(KCC, KCC, NA)
BGLF6000ZZ	30	KKC

Alterations	Bearings Retaining Rings Not Assembled		C2 Chamfer	C Chamfer								
	Code	NA			KCC	KKC						
Spec.		Bearings and retaining rings are shipped unassembled to the housing.	C2 chamfer is done on the top edge surface.	<p>C chamfer (45°) is done on both top edge corners.</p> <p>(Ordering Code) KKC</p> <table border="1"> <thead> <tr> <th>d</th> <th>KKC</th> </tr> </thead> <tbody> <tr> <td>3-8</td> <td>5</td> </tr> <tr> <td>10-20</td> <td>10</td> </tr> <tr> <td>25, 30</td> <td>12</td> </tr> </tbody> </table> <p>☑ Applicable to h Configurable Type only.</p>	d	KKC	3-8	5	10-20	10	25, 30	12
d	KKC											
3-8	5											
10-20	10											
25, 30	12											