


Urethane Rollers with Shafts

Urethane Thickness Configurable

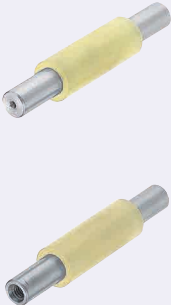


■ Straight

Type	Material		Hardness
	Shaft	Lining	
USRH	S45C	Urethane (Natural Color)	Shore A90
USRM	S45C	Urethane (Natural Color)	Shore A70
USSRH	SUS304	Urethane (Natural Color)	Shore A90

■ Both Ends Tapped

Type	Material		Hardness
	Shaft	Lining	
USRWH	S45C	Urethane (Natural Color)	Shore A90

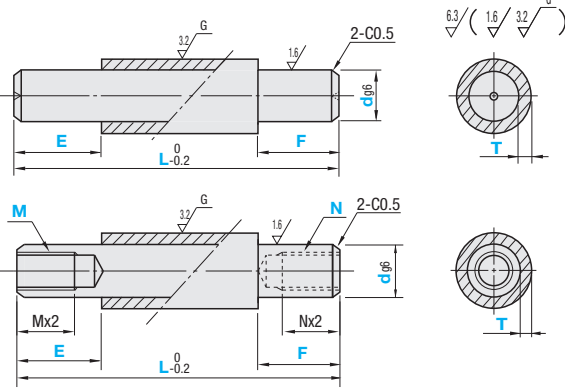

☞ Urethane is baked on the outer circumference of the core material.

Part Number		d	T 1mm Increment	L 1mm Increment	E, F 1mm Increment	Both Ends Tapped Only		
Type	Type					M (Coarse)	N (Coarse)	
Straight USRH USRM USSRH	Both Ends Tapped USRWH	8	2-5	50-200	5 ≤ E < L/2 5 ≤ F < L/2	3	4	5
		10				4	5	6
		12				5	6	8
		15				5	6	8 10



Ordering Example

Part Number	-	T	-	L	-	E	-	F	-	M	-	N
(Straight)		USRH10		2		195		E10		F10		
(Both Ends Tapped)		USRWH10		2		195		E10		F10		M5 - N6

■ Straight

d	Unit Price														
	USRH					USRM					USSRH				
	L50 ~100	L101 ~150	L151 ~200	L201 ~250	L251 ~300	L50 ~100	L101 ~150	L151 ~200	L201 ~250	L251 ~300	L50 ~100	L101 ~150	L151 ~200	L201 ~250	L251 ~300
8															
10															
12															
15															

■ Both Ends Tapped

d	Unit Price				
	USRWH				
	L50 ~100	L101 ~150	L151 ~200	L201 ~250	L251 ~300
8					
10					
12					
15					