


C-MPXSC-□ (Ultra-Mini Type)


C-MPXSC-□ (Standard Type)

Shield


C-MPXSC-4

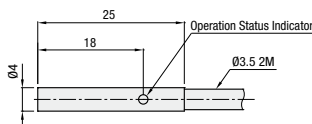


C-MPXSC-5

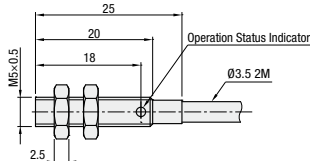


C-MPXSC-1-8S

 


C-MPXSC-2-12S

 

C-MPXSC-5-18S

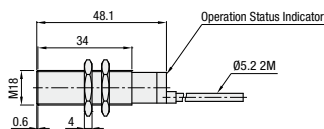


C-MPXSC-10-30S

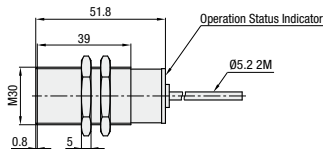


Non Shield

 C-MPXSC-4-12U



C-MPXSC-8-18U

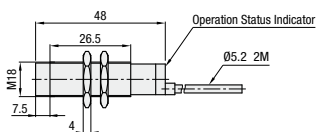

Shielded

Type	Part Number	Dia.	Detection Distance	Output	Connection Method	Unit Price 1 ~ 4 pc(s).	Volume Discount Rate 5 ~ 10 pcs.
Ultra-Mini Type	C-MPXSC-4	Ø4	0.8mm	NPN N.O.	Cable 2m		
	C-MPXSC-5	M5	0.8mm				
Standard	C-MPXSC-1-8S	M8	1mm				
	C-MPXSC-2-12S	M12	2mm				
	C-MPXSC-5-18S	M18	5mm				
	C-MPXSC-10-30S	M30	10mm				

Non-Shielded

Type	Part Number	Dia.	Detection Distance	Output	Connection Method	Unit Price 1 ~ 4 pc(s).	Volume Discount Rate 5 ~ 10 pcs.
Standard	C-MPXSC-4-12U	M12	4mm	NPN N.O.	Cable 2m		
	C-MPXSC-8-18U	M18	8mm				



Ordering
Example

Part Number

C-MPXSC-4