

# Limit Switch Flags

## With Slit

Proximity Sensor Flags **P2070**

**With Slit**






RoHS 10

Shape	Shaft Bore	Type	Material	Surface Treatment	Accessory
One End Cone Type	Through Hole	DGSA	S45C	Black Oxide	Hex Socket Head Cap Screw 1 pc.
Both Ends Cone Type		DGW			
One End Cone Type	Tapped Hole	DMSA	S45C	Black Oxide	
Both Ends Cone Type		DMW			

6.3





**DGSA** (One End Cone Type with Through Hole)

**DMSA** (One End Cone Type with Tapped Hole)

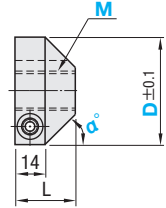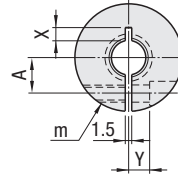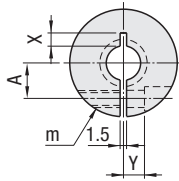

**DGW** (Both Ends Cone Type with Through Hole)

**DMW** (Both Ends Cone Type with Tapped Hole)

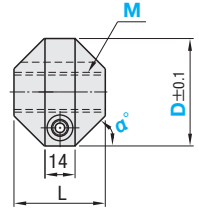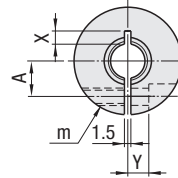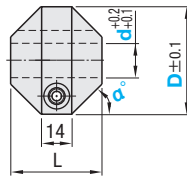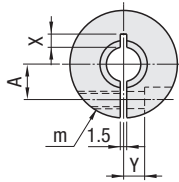

**One End Cone / Both Ends Cone Type with Through Hole and Slit**

Part Number		d	α°	L	M (Coarse)	A	X	Y	Unit Price	Volume Discount Rate
Type	D								1 ~ 9 pc(s).	10~50
DGSA	30	10	45	22	M5	9.0	6	6		
	40	12 16	30 45	24	M6	14.0	7	8		
	50			28	M8	16.5	10	10		
DGW	30	10	45	30	M5	9.0	6	6		
	40	12 16	30 45	34	M6	14.0	7	8		
	50			42	M8	16.5	10	10		

**One End Cone / Both Ends Cone Type with Tapped Hole and Slit**

Part Number		M (Coarse)	α°	L	M (Coarse)	A	X	Y	Unit Price	Volume Discount Rate
Type	D								1 ~ 9 pc(s).	10~50
DMSA	30	10	45	22	M5	9.0	6	6		
	40	12 16	30 45	24	M6	14.0	7	8		
	50			28	M8	16.5	10	10		
DMW	30	10	45	30	M5	9.0	6	6		
	40	12 16	30 45	34	M6	14.0	7	8		
	50			42	M8	16.5	10	10		



Ordering Example

Part Number - d, M - α°  
 Type D  
 DGSA 40 - 12 - 45



Example

