

 

# Positioning Switches

## Standard, L-Shaped



For Mechanical / Electrical Specifications and Precautions for Use, see **P2159**.





**MSTKD-ASL N-MSTKD-ASDL (with LEDs)**

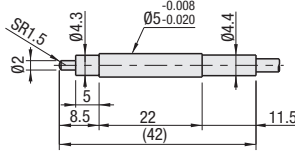



**MSTKD-A N-MSTKD-AD (with LEDs)**

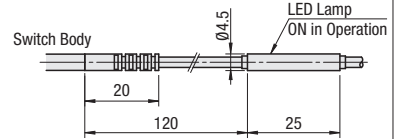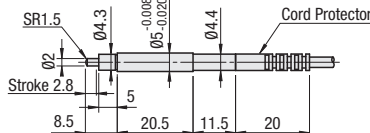


**MSTKD-C N-MSTKD-CD (with LEDs)**

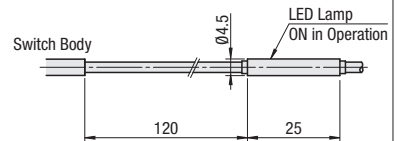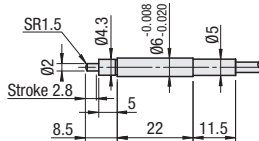

**MSTKD-H N-MSTKD-HD (with LEDs)**

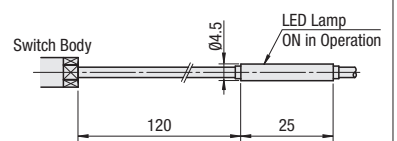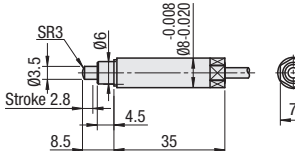

- ⚠ Straightly hold a detected object against the tip of switch. (Declination within  $\pm 3^\circ$ )
- ⚠ Use under DC24V/10mA or less.
- Use within the contact ratings.
- Do not pull or twist the cable with 30N or more.

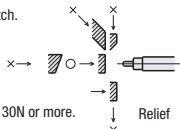


Type	Contact Part		Main Body	Cable
	Material	Hardness		
MSTKD-A N-MSTKD-AD	SUS420	45~50HRC	ABS Resin	2-Conductor Cable 3m, Ø3, Oil Resistant Min. Bending Radius R7
MSTKD-ASL N-MSTKD-ASDL			SUS303	
MSTKD-C N-MSTKD-CD				
MSTKD-H N-MSTKD-HD				


Part Number	Stroke	Operating Point	Contact Force N	Contact Logic	MSTKD-ASL, A, C, H		N-MSTKD-ASDL, AD, CD, HD	
					Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
MSTKD-ASL N-MSTKD-ASDL	2.8	0.3 from Tip (Repeatability 0.005)	1	NO (Normally Open)	1-9 pc(s).	10-20	1-9 pc(s).	10-20
MSTKD-A N-MSTKD-AD								
MSTKD-C N-MSTKD-CD								
MSTKD-H N-MSTKD-HD								

⚠ For orders larger than indicated quantity, please check with WOS.

For Mechanical / Electrical Specifications and Precautions for Use, see **P2159**.

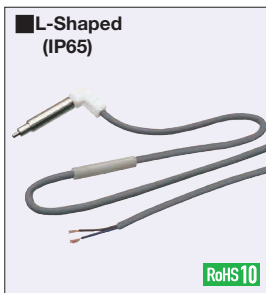

**N-MSTKG-A (with LEDs)**  
**N-MSTKG-C (with LEDs)**

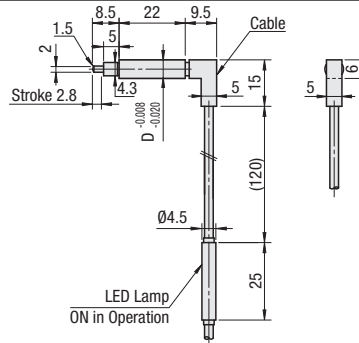

- Use within the contact ratings.
- Do not pull or twist the cable with 30N or more.
- Be careful not to apply bending or twisting force to the cable inlet.

Type	Contact Part		Main Body	Cable
	Material	Hardness		
N-MSTKG-A	SUS420	45~50HRC	ABS Resin	2-Conductor Cable 3m, Ø3, Oil Resistant Min. Bending Radius R7
N-MSTKG-C			SUS303	

Part Number	D	Stroke	Operating Point	Contact Force N	Contact Logic	Unit Price	Volume Discount Rate
N-MSTKG-A	5	2.8	0.3 from Tip (Repeatability 0.005)	1	NO (Normally Open)	1-9 pc(s)	10-20
N-MSTKG-C	6						

⚠ For orders larger than indicated quantity, please check with WOS.

