


Cover Screws


Phillips / Long Knurled Head / Knurled Head



Phillips

RoHS10

GUTBJ

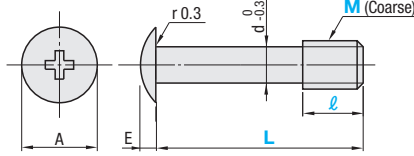


Reference	Tensile Breaking Load (N)
M3	1390
M5	4300

* The above data are for reference, not guaranteed.

M Material: SUS304 Equivalent

Part Number Type		M	ℓ	L	A	E	d	Unit Price	Volume Discount Rate
								1 ~ 29 pc(s).	30 ~ 300 pcs.
GUTBJ	3		2	5 8 10	6.9	1.9	2.2		
			3.5	6 8 10					
			4	8 10 12					
	4		3	6 8 10 12 16	9.4	2.5	3		
			5	10 16					
	5		3	8 10 12	11.8	3.1	3.9		
			6	12 16 20					
	6		4	10 12 16 20	14	3.7	4.5		
			8	12 16 20 25 30					
	8		5	16	17.8	4.8	6.3		
			10	40					


For orders larger than indicated quantity, please check with WOS.



Long Knurled Head

RoHS10


GUTBR

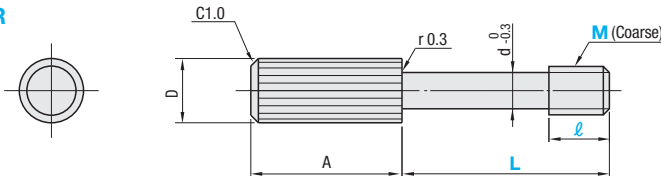

M Material: SUS303

Part Number Type		M	ℓ	L	D	A	d	Unit Price	Volume Discount Rate
								1 ~ 29 pc(s).	30 ~ 300 pcs.
GUTBR	3		2	6 8 10 12	5.5	10	2.2		
			3.5	6 8 10 12					
			4	8 10 12					
	4		3	6 8 10 12 16	7	16	3		
			5	10 12 16					
	5		3	8 10 12 16 20	8.5	20	3.9		
			6	12 16 20					
	6		4	8 10 12 16 20	10	30	4.5		
			8	12 16 20 25					
	8		5	10 12 16 20	13	36	6.3		
			10	20 25 30					


For orders larger than indicated quantity, please check with WOS.



Knurled Head

RoHS10

RNCB

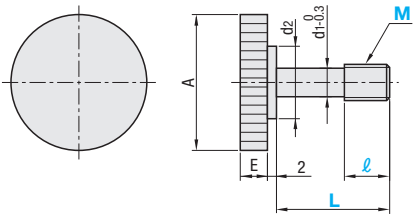

M Material: SUS303

Part Number Type		M	ℓ	L	A	d1	d2	E	Unit Price	Volume Discount Rate
									1 ~ 29 pc(s).	30 ~ 50 pcs.
RNCB	3		2	4 6 8 10	12	2.2	6	2.5		
			3.5	6 8 10 12 15						
			4	8 10 12 15 20						
	4		3	6 8 10 12 15	16	3	8	3.5		
			5	10 12 15 20						
	5		3	8 10 12 15	20	3.9	10	4		
		6	12 15 20 25							
6		8	12 15	24	4.5	12	5			
		10	15 20							30

For orders larger than indicated quantity, please check with WOS.

Ordering Example

Part Number	ℓ	L
GUTBJ3	4	8
GUTBR4	5	16
RNCB4	5	16