


Phillips Flat Head Screws / Phillips Low Flat Head Screws

Single Item Sale

Phillips Flat Head Screws



Type	Material	Surface Treatment
BFBJ	SWCH Equivalent	Trivalent Chromate
SFBJ	SUS304 Equivalent	-

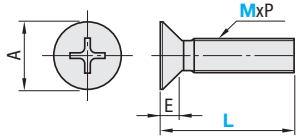

MxP (Coarse)	A	E	Phillips No.
2x0.4	4	1.2	1
2.5x0.45	5	1.45	1
2.6x0.45	5.2	1.5	1
3x0.5	6	1.75	2
4x0.7	8	2.3	2
5x0.8	10	2.8	2
6x1.0	12	3.4	3

BFBJ (Trivalent Chromate)

Part Number	Unit Price	Volume Discount Rate			
		1 - 29 pc(s).	30 - 99 pcs.	100 - 299 pcs.	300 - 500 pcs.
Type	M - L				
BFBJ	2 - 3				
	4				
	5				
	6				
	8				
	3 - 4				
	5				
	6				
	8				
	10				
	12				
	4 - 5				
	6				
	8				
	10				
	12				
	15				
	20				
	5 - 6				
	8				
10					
12					
15					
20					
6 - 8					
10					
12					
15					
20					

SFBJ (Stainless Steel)

Part Number	Unit Price	Volume Discount Rate			
		1 - 29 pc(s).	30 - 99 pcs.	100 - 149 pcs.	150 - 500 pcs.
Type	M - L				
SFBJ	2 - 3				
	4				
	5				
	6				
	8				
	2.5 - 3				
	4				
	5				
	6				
	8				
	10				
	2.6 - 3				
	4				
	5				
	6				
	8				
	10				
	3 - 4				
	5				
	6				
8					
10					
12					
4 - 5					
6					
8					
10					
12					
15					
20					
5 - 6					
8					
10					
12					
15					
20					
6 - 8					
10					
12					
15					
20					


Ordering Example Part Number
SFBJ4-10

Phillips Low Flat Head Screws



RoHS 10

Type	Material	Surface Treatment
TSARA	SWCH Equivalent	Trivalent Chromate
TSARAS	SUS304 Equivalent	-

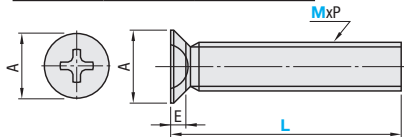

MxP (Coarse)	A	E	Phillips No.
3x0.5	5	1.3	1
4x0.7	6	1.4	2
5x0.8	8	1.9	2
6x1.0	10	2.4	3

TSARA (Trivalent Chromate)

Part Number	Unit Price	Volume Discount Rate			
		1 - 19 pc(s).	20 - 99 pcs.	100 - 199 pcs.	200 - 500 pcs.
Type	M - L				
TSARA	3 - 5				
	6				
	8				
	10				
	12				
	15				
	30				
	4 - 6				
	8				
	10				
	12				
	15				
	20				
	25				
	30				
	5 - 8				
	10				
	12				
	15				
	20				
25					
30					
6 - 10					
12					
15					
20					
25					
30					

TSARAS (Stainless Steel)

Part Number	Unit Price	Volume Discount Rate			
		1 - 19 pc(s).	20 - 99 pcs.	100 - 199 pcs.	200 - 500 pcs.
Type	M - L				
TSARAS	4 - 6				
	8				
	10				
	12				
	15				
	20				
	25				
	30				
	5 - 8				
	10				
	12				
	15				
	20				
	25				
	30				
	6 - 10				
	12				
	15				
	20				
	25				
30					

Ordering Example Part Number
TSARAS5-10