 


# Tabbed Brackets - For 1 Slot

## For 6 Series (Slot Width 8mm) Aluminum Extrusions



**Features:** Tabbed Brackets to be connected by both L and Cross-Connections.



### Tabbed Reversal Brackets



**HBLFSN6**  
**HBLFSN6-5** (For M5 Screw)  
**HBLFSNB6** (Black Anodize)  
**HBLFSNM6** (Electroless Nickel Plating)  
**CHBLFSN6** (Baked Paint, Silver)

Type	M Material	S Surface Treatment
① HBLFSN6	-	-
② HBLFSN6-5	-	-
③ HBLFSNB6	ADC12	Black Anodize
④ HBLFSNM6	-	Electroless Nickel Plating
⑤ CHBLFSN6	-	Baked Paint (Silver)

\* Baked Paint (Silver) is color coordinated with Clear Coating Extrusions.

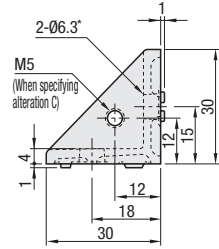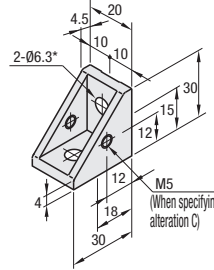

\* 05.2 when HBLFSN6-5 is specified.


Part Number	Mass (g)	Applicable Screw, T Nut		Allowable Load (N)	Unit Price (1-99 pc(s))	Volume Discount Rate (100-200)
		Screw	T Nut			
HBLFSN6	15	CBM6-12	HNTT6-6	2	1176	
HBLFSN6-5 (For M5 Screw)			HNTT6-5			
HBLFSNB6* (Black Anodize)		CBM6-12	HNTT6-6			
HBLFSNM6 (Electroless Nickel Plating)						
CHBLFSN6 (Baked Paint, Silver)						

\* For repairing black anodizing, refer to P846.




Example

Can be installed in either direction.

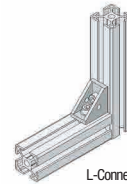

L-Connection

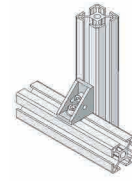

Cross-Connection



**Features:** Brackets with tabs to fit in slots of extrusions and stop rotating when tightening.

### Tabbed Brackets



**HBLFS6**  
**HBLFSB6** (Cathodic Electrodeposition Paint: Black)

Type	M Material	S Surface Treatment
HBLFS6	-	-
HBLFSB6	ADC12	Cathodic Electrodeposition Coating Black

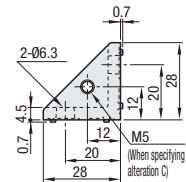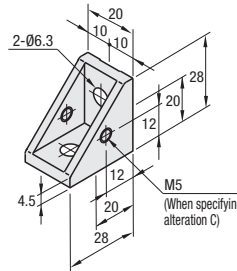


Part Number	Mass (g)	Applicable Screw, T Nut		Allowable Load (N)	Unit Price (1-99 pc(s))	Volume Discount Rate (100-200)
		Screw	T Nut			
HBLFS6	13	CBM6-12	HNTT6-6	2	1176	
HBLFSB6 (Cathodic Electrodeposition Paint: Black)						



Example

Used for L-connections.

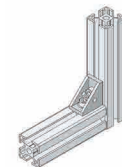



**Features:** One-Sided Tabbed Rib Brackets. Easy to work with wrenches.

### One-Side Rib Brackets



**HBLFSL6**

M Material: ADC12

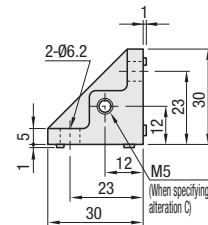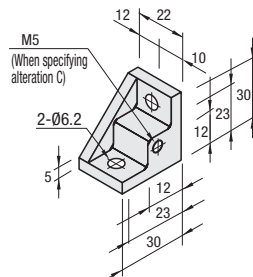

Part Number	Mass (g)	Applicable Screw, T Nut		Allowable Load (N)	Unit Price (1-99 pc(s))	Volume Discount Rate (100-200)
		Screw	T Nut			
HBLFSL6	17	CBM6-12	HNTT6-6	2	1176	



Example

Can be combined with both cover plates of 5mm and 3mm thickness.

